



CHATSWORTH
PRODUCTS


Panel Adapter with Cable Management

Panel Adapter with Cable Management

CPI offers a solution for those who have 7'H (2.1 m) x 23"W racks and need to mount 19" equipment along the entire length of the rack. Existing panel adapters are typically composed of two side panels which reduce the mounting width and center the equipment. CPI's unique design performs the reduction on one side. Not only can you mount 19" equipment, but you also have room for cable management on the wide adapter panel.

Eight 2.25" (57.2 mm) oval pass-through ports with edge protectors provide cable access from front to rear of the panel. In addition, there are seven threaded holes along the front surface of the panels for mounting optional Center Grommet Buckle Saf-T-Grip Cable Management Straps to provide strain relief and vertical cable management.

- Includes (50) pilot point #12-24 mounting screws with combination Phillips/Straight heads
- Saf-T-Grip straps are optional
- Split design allows you to adapt half or all of a 7'H (2.1 m) relay rack
- Adapter panels mount on right or left side of rack
- Panels are joggled to maintain uniform mounting surface plane
- For lightweight applications (patch panels & cable management)

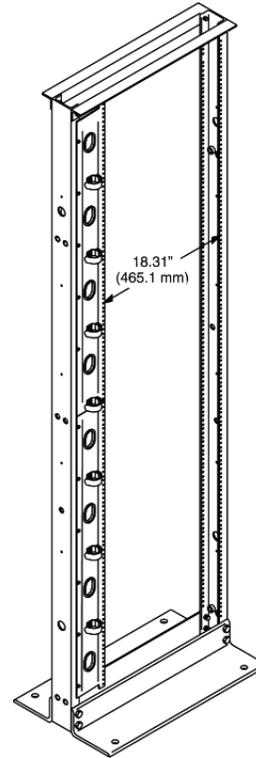

ORDERING INFORMATION

Part Number	Description	Shipping Weight lb (kg)
13044-X03	7' (2.1m) Panel Adapters	5 (2.3)

X=color: 1=Gray,5=Clear, 7=Black, E=Glacier White

United States & Canada
Simi Valley, CA
800-834-4969
Toronto, Ontario, Canada
+905-850-7770
chatsworth.com
techsupport@chatsworth.com

Latin America
Mexico City, Mexico
+52-55-5203-7525
Toll Free within Mexico
800-201-7592
chatsworth.com.co

Europe
Buckinghamshire
England, UK
+44-1628-524-834

Middle East & Africa
Dubai, UAE
+971-4-2602125
Doha, Qatar
+974-4-267422

Asia Pacific
Jing'an District,
Shanghai, China
+86 21 6880-0266
chatsworth.com.cn