


PRODUCT APPLICATION

Cable Management Solutions

Proper cable management is critical to attaining optimum cable performance and data transmission. Managing and maintaining cables provides the critical support, reliability and flexibility needed to sustain and grow network capabilities. Chatsworth Products, Inc. (CPI) provides a comprehensive line of cost effective Cable Management Products to protect and support the latest cabling technologies such as Cat 6a and fiber.

Your cable keeps getting faster.
Trust CPI to help you keep up.

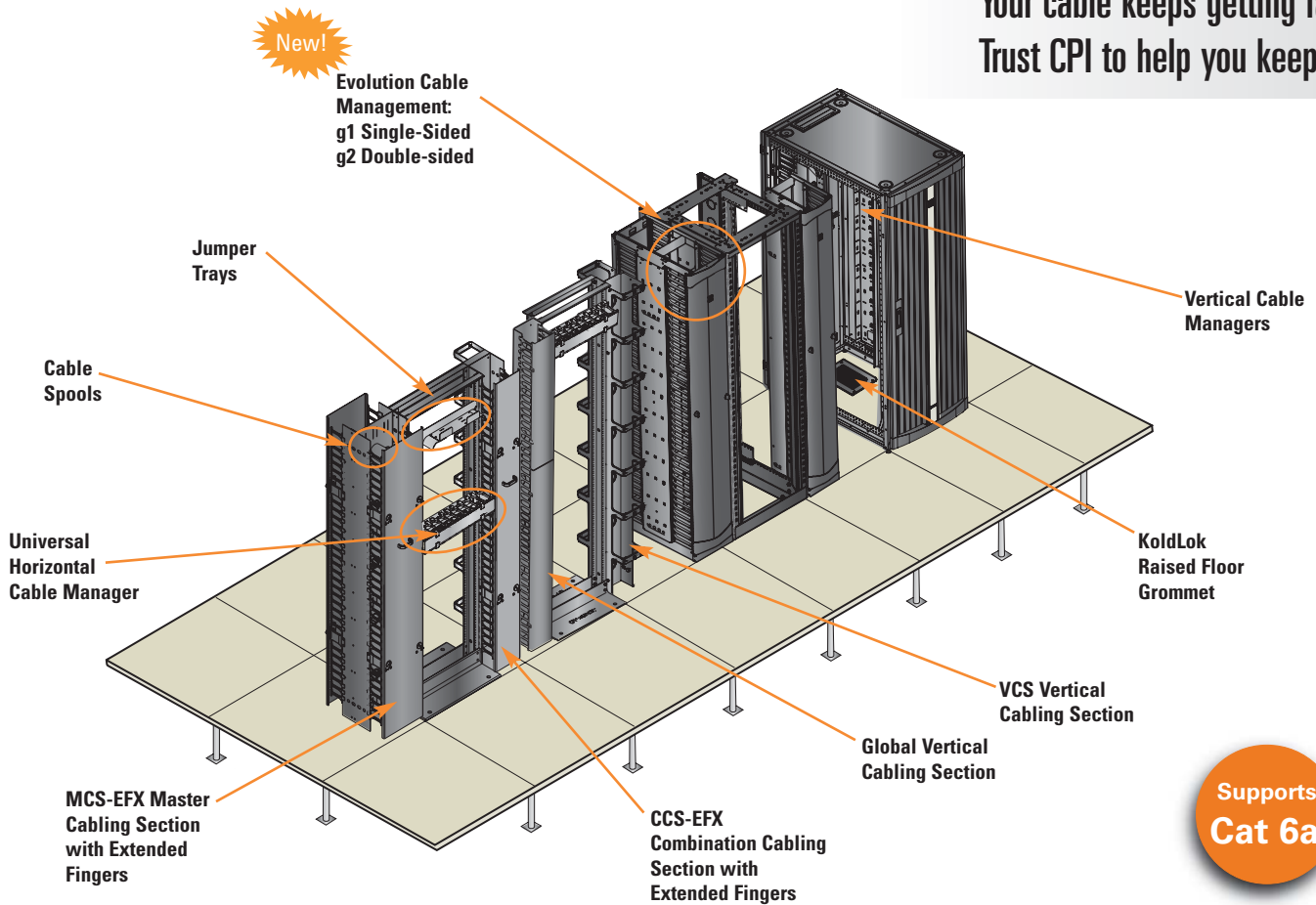

Supports
Cat 6a

Jumper Trays – Creates side-to-side pathways for patch cords.

Cable Spools – Controls bends while reducing cable slack inside vertical cabling sections and cable managers. Particularly beneficial when managing fiber-optic cables.

Universal Horizontal Cable Manager – Presents highly functional pathway with extra-wide and contoured cable guide fingers to organize cables and offer quick and easy moves, adds and changes.

MCS-EFX Master Cabling Section with Extended Fingers – Arranges cables by rack-mount space with T-shaped finger guides. Available in closed front and rear double-sided or single-sided cable managers with hinged covers.

Vertical Cable Managers – Organizes cables with T-shaped guides and openings that align with each rack-mount space. Available for the F-Series TeraFrame™ Cabinet and for the MegaFrame® Cabinet Systems.

CCS-EFX Combination Cabling Section with Extended Fingers – Arranges cables by rack-mount space with T-shaped finger guides. Available in combination open rear and closed front double-sided cable managers with hinged front covers.

Evolution™ Cable Management – Provides an engineered solution for managing high-density cabling applications on open two-post and for-post rack systems delivering increased performance to match demands of data center applications.

KoldLok® Raised Floor Grommet – Protects cables and prevents cool air from escaping through holes in access floors using brush sealed grommets as cables pass through openings in access floor tiles.

VCS Vertical Cabling Section – Manages large cable bundles by providing an open cable trough with easy-to-use flip-open latches. Available in single- and double-sided versions.

Global Vertical Cabling Section – Offers T-shaped cable management fingers that align with each RMU space to organize cables. Available in single- and double-sided versions with snap-on hinged covers.



CHATSWORTH PRODUCTS, INC.

800-834-4969

techsupport@chatsworth.com
www.chatsworth.com

PRODUCT APPLICATION SHEET

ORDERING INFORMATION

Jumper Trays

Part Number	Description
12183-X19	Upper Jumper Tray, 19"EIA x 2 RMU x 3.5"D (89 mm)
13183-X19	Upper Jumper Tray, 19"EIA x 2 RMU x 6.0"D (150 mm)
12185-X19	Lower Jumper Tray, 19"EIA x 2 RMU x 3.5"D (89 mm)
12187-X19	Lower Jumper Tray, 19"EIA x 3 RMU x 3.5"D (89 mm)

X=Color; 1=Gray, 2=Computer White, 5=Brushed Aluminum, 7=Black

Cable Spools

Part Number	Description
15008-001	4 Spools, 2.75" Ø x 5.9"L (70 mm x 150 mm)
12766-702	2 Spools, 2" Ø x 3"L (50 mm x 80 mm)
12766-707	7 Spools, 2" Ø x 3"L (50 mm x 80 mm)

Color is black. Attaches to 6"W (150 mm) or wider cabling sections.

Universal Horizontal Cable Manager

Part Number	Description
30339-719	Single-Sided, 19"EIA x 1 RMU x 6.2"D (157 mm)
30330-719	Single-Sided, 19"EIA x 2 RMU x 6.4"D (163 mm)
30331-719	Single-Sided, 19"EIA x 3 RMU x 6.4"D (163 mm)

Color is black. Double-sided versions are also available.

MCS-EFX Master Cabling Section with Extended Fingers

Part Number	Description
40092-703	Single-sided, 6"W x 7"H x 10.6"D (150 mm x 2.1 m x 269 mm)
40093-703	Single-sided, 10"W x 7"H x 10.6"D (250 mm x 2.1 m x 269 mm)
40094-703	Single-sided, 12"W x 7"H x 10.6"D (300 mm x 2.1 m x 269 mm)
40095-703	Double-sided, 6"W x 7"H x 21.2"D (150 mm x 2.1 m x 539 mm)
40096-703	Double-sided, 10"W x 7"H x 21.2"D (250 mm x 2.1 m x 539 mm)
40097-703	Double-sided, 12"W x 7"H x 21.2"D (300 mm x 2.1 m x 539 mm)

Color is black. Match to rack height. Other heights are available.

Vertical Cable Managers

Part Number	Description
34441-C01	Single-sided, 2.7"W x 12.6"D (70 mm x 320 mm) for 27.6"W (700 mm) x 45 RMU F-Series TeraFrame
34441-C02	Single-sided, 4.6"W x 12.6"D (117 mm x 320 mm) for 31.5"W (800 mm) x 45 RMU F-Series TeraFrame

Color is black. Other sizes are available.

CCS-EFX Combination Cabling Section with Extended Fingers

Part Number	Description
40098-703	Double-sided, 6"W x 7"H x 14.9"D (150 mm x 2.1 m x 380 mm)
40099-703	Double-sided, 10"W x 7"H x 14.9"D (250 mm x 2.1 m x 380 mm)
40100-703	Double-sided, 12"W x 7"H x 14.9"D (300 mm x 2.1 m x 380 mm)

Color is black. Match to rack height. Other heights are available.

Evolution™ Cable Management

Part Number	Description
35513-703	g1 Single-Sided, Vertical, 10"W x 7"H x 13.2"D (250 mm x 2.1 m x 335 mm)
35523-703	g2 Double-Sided, Vertical, 10"W x 7"H x 24.5"D (250 mm x 2.1 m x 622 mm)
35441-702	Single-Sided, Horizontal, 19"EIA x 2 RMU x 8.2"D (208 mm)

Color is black. Other sizes are available.

KoldLok® Raised Floor Grommet

Part Number	Description
13571-001	Integral Grommet, 11"W x 8.25"D (280 mm x 210 mm)
13671-001	Split Integral Grommet, 11"W x 8.25"D (280 mm x 210 mm)

Color is black. Grommets have an 8"W x 4"D (200 mm x 100 mm) cable space. Other sizes are available.

VCS Vertical Cabling Section

Part Number	Description
11374-X03	Single-sided, 6"W x 7"H x 6.3"D (150 mm x 2.1 m x 160 mm)
11729-X03	Double-sided, 6"W x 7"H x 12.7"D (150 mm x 2.1 m x 323 mm)

X=Color; 1=Gray, 2=Computer White, 5=Brushed Aluminum, 7=Black. Match to rack height. Other sizes are available.

Global Vertical Cabling Section

Part Number	Description
12831-703	Single-sided, 6"W x 7"H x 6.7"D (150 mm x 2.1 m x 170 mm)
12833-703	Single-sided, 6"W x 7"H x 9.3"D (150 mm x 2.1 m x 236 mm)

Color is Black. Other sizes are available.

Not exactly what you need? This product application sheet features a portion of CPI Cable Management Products. Additional products, sizes and configurations are available from CPI. Visit www.chatsworth.com.



CHATSWORTH PRODUCTS, INC.