

# Product Cut Sheet


## AISLE CONTAINMENT CABINET SUPPORTED CEILING PANEL KIT

Aisle Containment Ceiling Panel Kit is used over two adjacent rows of cabinets. The ceiling panel kit is part of a complete Cabinet Supported Cold Aisle Containment (CAC) Solution that captures cold air in an enclosed aisle.

- Encloses the top of an aisle between adjacent cabinet rows
- Cabinet-supported, compatible with F-Series TeraFrame® Cabinets, N-Series TeraFrame® Network Cabinets and GF-Series GlobalFrame® Cabinets
- Supported by the cabinets; fits snug against the cabinet top panels
- Large, translucent, full-width ceiling panels allow light to enter the contained aisle
- Side supports raise ceiling panels 4" (100 mm), 8" (200 mm) or 12" (300 mm) above the cabinets to increase headroom within the contained aisle
- Spans across 48" (1200 mm) or 72" (1800 mm) wide aisles (2 to 3 tiles)
- Available 144" (3600 mm) to 630" (16 000 mm) long in 8" (200 mm) increments
- Adjustable ends allow up to 8" (200 mm) of length adjustment, each end adjusts up to 4" (100 mm)
- Side supports and end panels are steel, cross supports are anodized aluminum and ceiling panels are polycarbonate
- Side and end panels are painted glacier white or black
- Sold as a single part number; select aisle width, ceiling height and length



Sold as a single part number. Select to match cabinet row length, each end extends up to 4" (100 mm).

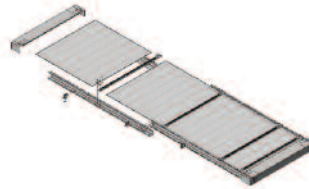

Cabinet Supported Ceiling Panel Kit shown removed (partially disassembled) and installed. Ceiling kit is sold under a single part number and includes all components needed to cover the contained aisle.

Estimated Additional Weight On Each Cabinet From Ceiling Panel Kit				
Cabinet Width	100 mm H Ceiling Panel Kit		300 mm H Ceiling Panel Kit	
	End Of Row	Mid Row	End Of Row	Mid Row
in (mm)	lb (kg)	lb (kg)	lb (kg)	lb (kg)
23.6 (600)	21 (9.5)	11 (4.9)	37 (16.8)	15 (6.8)
40.0 (1016)	26 (11.8)	15 (6.9)	43 (19.5)	21 (9.5)

800-834-4969 in US & Canada • [www.chatsworth.com](http://www.chatsworth.com)



CHATSWORTH PRODUCTS, INC.

# Product Cut Sheet

## AISLE CONTAINMENT CABINET SUPPORTED CEILING PANEL KIT

Part Number & Finish		Description	Shipping Weight lb (kg)
Black	Glacier White		
<b>For 2 Tile, 48" (1200 mm) Wide Aisles</b>			
<b>4" (100 mm) Height</b>			
32710-700	32710-E00	141.7"L (3600 mm) 11'-10" (3.6 m)	121 (55.0)
32710-709	32710-E09	212.6"L (5400 mm) 17'-9" (5.4 m)	162 (73.4)
32710-718	32710-E18	283.5"L (7200 mm) 23'-8" (7.2 m)	203 (92.2)
32710-727	32710-E27	354.3"L (9000 mm) 29'-7" (9.0 m)	244 (110.8)
32710-736	32710-E36	425.2"L (10 800 mm) 35'-6" (10.8 m)	280 (127.0)
32710-745	32710-E45	496.1"L (12 600 mm) 41'-5" (12.6 m)	321 (145.9)
32710-754	32710-E54	566.9"L (14 400 mm) 47'-3" (14.4 m)	362 (164.2)
32710-762	32710-E62	629.9"L (16 000 mm) 52'-6" (16.0 m)	397 (180.0)
<b>8" (200 mm) Height</b>			
32710-763	32710-E63	141.7"L (3600 mm) 11'-10" (3.6 m)	140 (63.7)
32710-772	32710-E72	212.6"L (5400 mm) 17'-9" (5.4 m)	191 (86.5)
32710-781	32710-E81	283.5"L (7200 mm) 23'-8" (7.2 m)	242 (109.6)
32710-790	32710-E90	354.3"L (9000 mm) 29'-7" (9.0 m)	292 (132.6)
32710-799	32710-E99	425.2"L (10 800 mm) 35'-6" (10.8 m)	337 (153.0)
32710-7AJ	32710-EAJ	496.1"L (12 600 mm) 41'-5" (12.6 m)	388 (176.2)
32710-7AV	32710-EAV	566.9"L (14 400 mm) 47'-3" (14.4 m)	439 (199.0)
32710-7BF	32710-EBF	629.9"L (16 000 mm) 52'-6" (16.0 m)	482 (218.7)
<b>12" (300 mm) Height</b>			
32710-7BG	32710-EBG	141.7"L (3600 mm) 11'-10" (3.6 m)	159 (72.3)
32710-7BT	32710-EBT	212.6"L (5400 mm) 17'-9" (5.4 m)	219 (99.3)
32710-7CE	32710-ECE	283.5"L (7200 mm) 23'-8" (7.2 m)	279 (126.7)
32710-7CP	32710-ECP	354.3"L (9000 mm) 29'-7" (9.0 m)	340 (154.1)
32710-7DC	32710-EDC	425.2"L (10 800 mm) 35'-6" (10.8 m)	394 (178.8)
32710-7DM	32710-EDM	496.1"L (12 600 mm) 41'-5" (12.6 m)	455 (206.6)
32710-7EA	32710-EEA	566.9"L (14 400 mm) 47'-3" (14.4 m)	514 (233.4)
32710-7EJ	32710-EEJ	629.9"L (16 000 mm) 52'-6" (16.0 m)	566 (256.9)

Note: Other sizes are available. Contact CPI Technical Support for configuration assistance.

Part Number & Finish		Description	Shipping Weight lb (kg)
Black	Glacier White		
<b>For 3 Tile, 72" (1800 mm) Wide Aisles</b>			
<b>4" (100 mm) Height</b>			
32711-700	32711-E00	141.7"L (3600 mm) 11'-10" (3.6 m)	145 (65.7)
32711-709	32711-E09	212.6"L (5400 mm) 17'-9" (5.4 m)	190 (86.3)
32711-718	32711-E18	283.5"L (7200 mm) 23'-8" (7.2 m)	237 (107.3)
32711-727	32711-E27	354.3"L (9000 mm) 29'-7" (9.0 m)	283 (128.2)
32711-736	32711-E36	425.2"L (10 800 mm) 35'-6" (10.8 m)	321 (145.8)
32711-745	32711-E45	496.1"L (12 600 mm) 41'-5" (12.6 m)	368 (166.8)
32711-754	32711-E54	566.9"L (14 400 mm) 47'-3" (14.4 m)	413 (187.6)
32711-762	32711-E62	629.9"L (16 000 mm) 52'-6" (16.0 m)	451 (204.8)
<b>8" (200 mm) Height</b>			
32711-763	32711-E63	141.7"L (3600 mm) 11'-10" (3.6 m)	164 (74.4)
32711-772	32711-E72	212.6"L (5400 mm) 17'-9" (5.4 m)	219 (99.4)
32711-781	32711-E81	283.5"L (7200 mm) 23'-8" (7.2 m)	275 (124.7)
32711-790	32711-E90	354.3"L (9000 mm) 29'-7" (9.0 m)	331 (150.0)
32711-799	32711-E99	425.2"L (10 800 mm) 35'-6" (10.8 m)	378 (171.7)
32711-7AJ	32711-EAJ	496.1"L (12 600 mm) 41'-5" (12.6 m)	434 (197.1)
32711-7AV	32711-EAV	566.9"L (14 400 mm) 47'-3" (14.4 m)	490 (222.2)
32711-7BF	32711-EBF	629.9"L (16 000 mm) 52'-6" (16.0 m)	537 (243.5)
<b>12" (300 mm) Height</b>			
32711-7BG	32711-EBG	141.7"L (3600 mm) 11'-10" (3.6 m)	183 (83.0)
32711-7BT	32711-EBT	212.6"L (5400 mm) 17'-9" (5.4 m)	247 (112.3)
32711-7CE	32711-ECE	283.5"L (7200 mm) 23'-8" (7.2 m)	313 (141.9)
32711-7CP	32711-ECP	354.3"L (9000 mm) 29'-7" (9.0 m)	378 (171.5)
32711-7DC	32711-EDC	425.2"L (10 800 mm) 35'-6" (10.8 m)	435 (197.6)
32711-7DM	32711-EDM	496.1"L (12 600 mm) 41'-5" (12.6 m)	501 (227.5)
32711-7EA	32711-EEA	566.9"L (14 400 mm) 47'-3" (14.4 m)	566 (256.6)
32711-7EJ	32711-EEJ	629.9"L (16 000 mm) 52'-6" (16.0 m)	621 (281.8)

Note: Other sizes are available. Contact CPI Technical Support for configuration assistance.

800-834-4969 in US & Canada • [www.chatsworth.com](http://www.chatsworth.com)



CHATSWORTH PRODUCTS, INC.

©2012 Chatsworth Products, Inc. All rights reserved. CPI, CPI Passive Cooling, MegaFrame, Saf-T-Grip, Seismic Frame, SlimFrame, TeraFrame, GlobalFrame, Cube-iT Plus, Evolution, OnTrac, QuadraRack and Velocity are federally registered trademarks of Chatsworth Products, Inc. eConnect and Simply Efficient are trademarks of Chatsworth Products, Inc. All other trademarks belong to their respective companies.