

Installation Instructions


SIDE PANEL ASSEMBLY, FOR 6 SLIDE CABINET

Included Hardware
M6 Hex Nut, 2 ea.

Tools Required
10mm Socket Wrench

Assembly Sequence

1. Assemble the grounding wires to the studs available on the frame vertical members using M6 nuts (Fig. 1). The grounding wire can be assembled either at the front or rear of the frame.

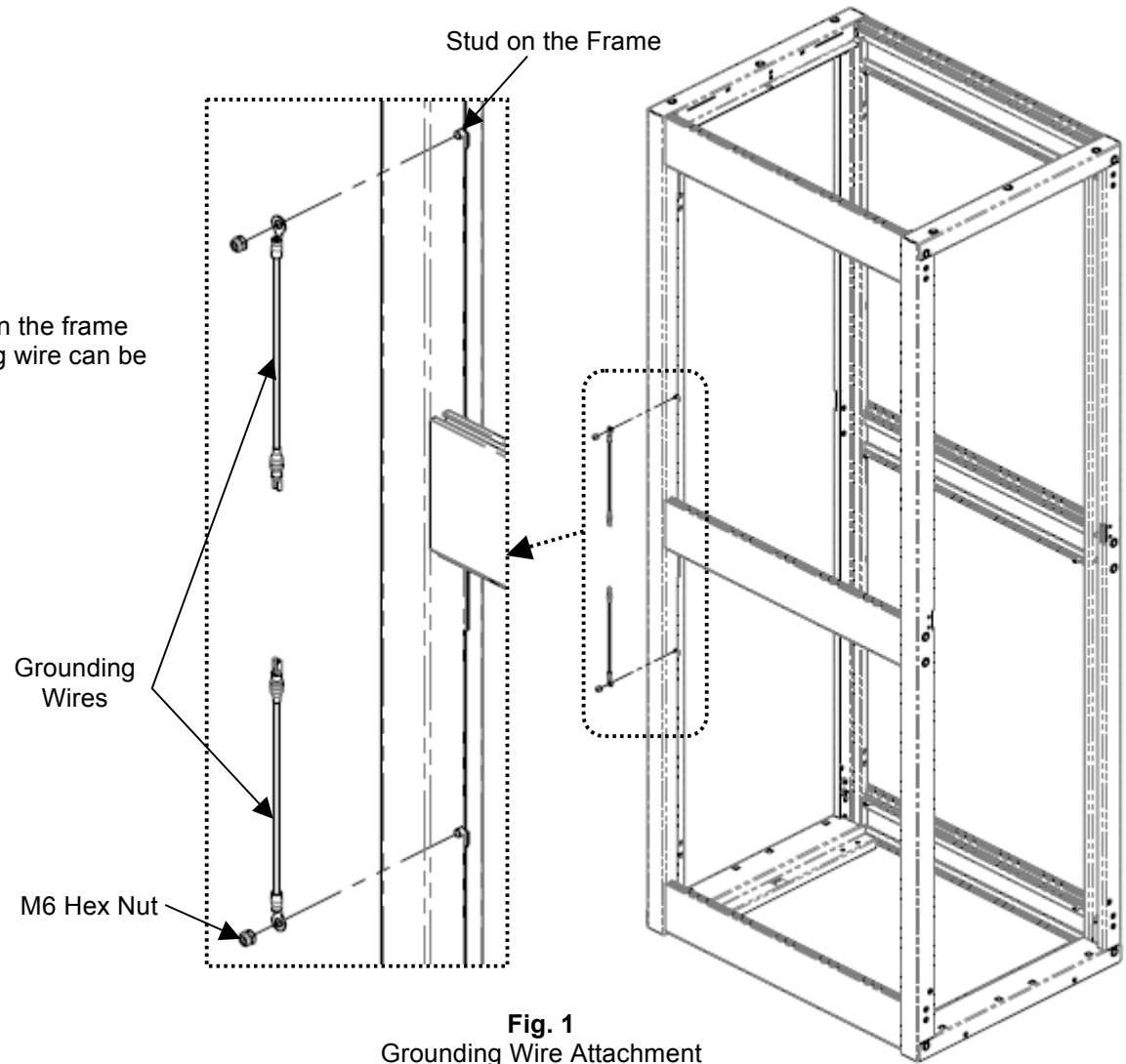

IIS-739046, 02/18/13, Rev. 1, CPI/JAG
800-834-4969 (USA & Canada) • www.chatsworth.com • techsupport@chatsworth.com
For international phone numbers, see our website or contact CPI Tech Support.

This drawing contains proprietary and confidential information and is protected by U.S. and international law. Unauthorized reproduction, disclosure or use of the drawing the information therein is expressly forbidden except as agreed to in writing by Chatsworth Products, Inc.

Installation Instructions

SIDE PANEL ASSEMBLY, FOR 6 SLIDE CABINET

2. Rest the side panel on the top surface of the lower or middle slides (Fig.2).
3. Attach the grounding wire using the quick connect on the side panel (Fig. 2).
4. Rotate side panel to close.
5. Push up on latch to ensure side panel engagement (Fig. 3).
6. Use key to secure side panel when not in use.

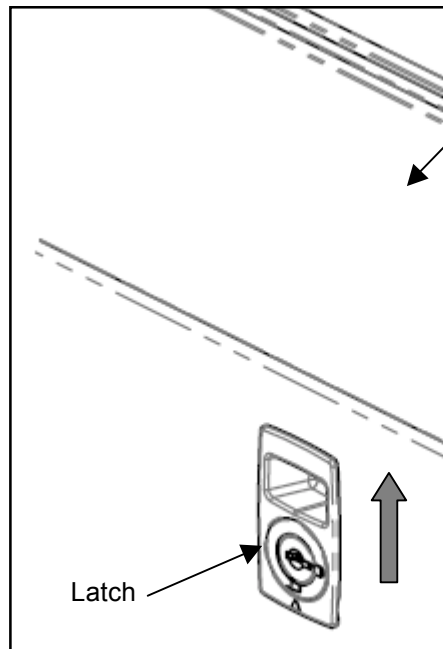


Fig. 3
Side Panel Engagement

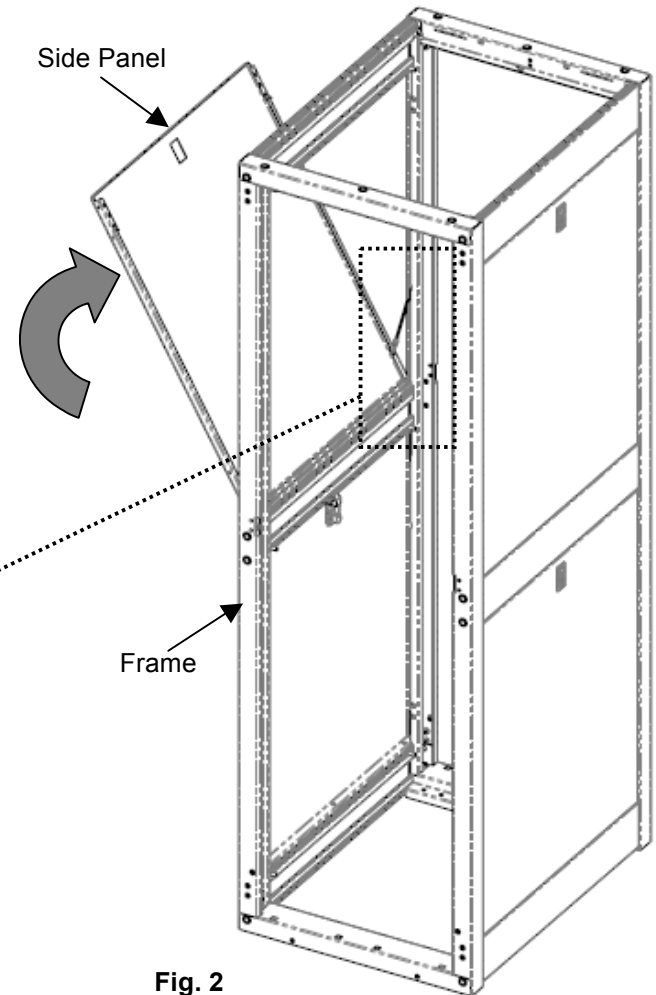
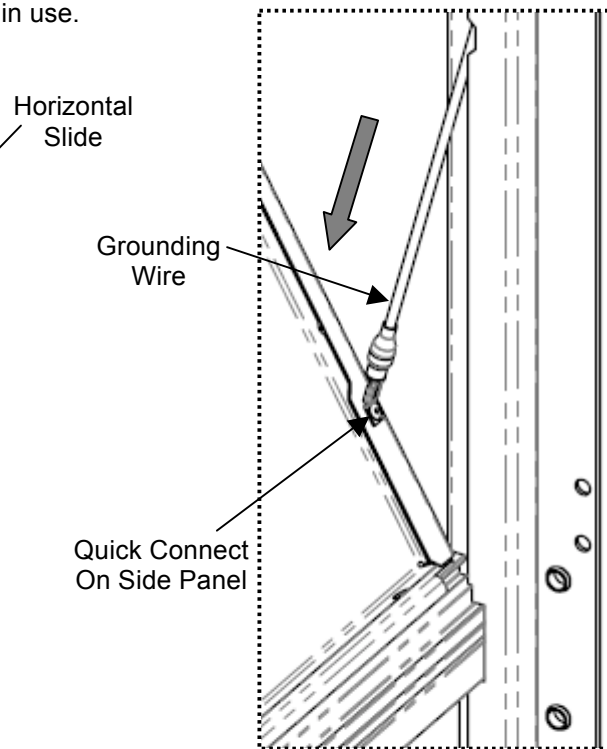


Fig. 2
Side Panel Attachment