

# Featured Product



## NEW Two-Post Standard Rack

Saves time, labor and space.

- Bonded assembly – paint cutting assembly hardware added to bond components.
- Integrated ground studs – prepared grounding location added to the rack channel (one side) with two 1/4" studs, spaced 5/8" apart for quick and easy attachment of standard ground lugs.
- 52U on 8'H racks – was 51U, an additional U space for equipment.
- Available in Glacier White finish – now a standard color, matches CPI Cabinets.
- Rack Ground Jumper Kit (ordered separately) – allows easy attachment to Telecommunications Grounding System, new kit includes: 9'L (2.7 m) Ground Jumper with attached ground lug, Antioxidant Joint Compound and hardware for attaching the jumper to the rack

55053 The Rack  
Customers Ask  
for by Number!

Compare It					
Manufacturer	Chatsworth Products (CPI)	Panduit	Pentair - Hoffman	Cooper B-Line	
Model	Standard Rack	2 Post Cable Management Rack System	2-Post Open Frame Racks	Two-Post Network Equipment Rack	
52U on 8'H Racks	✓	✓	No	No	
Integrated Ground	✓	✓	No	No	
Part Number Cross Reference					
Rack 19" EIA Black	45U	55053-703	R2P	EDR19FM45H	SB556084XUFB
	52U/51U*	55053-715	R2P96	EDR19FM51U	SB556096XUFB
	58U	55053-708	N/A	EDR19FM58U	SB556108XUFB
Rack 19" EIA Gray	45U	55053-103	N/A	N/A	SB556084XUTG
	52U/51U*	55053-115	N/A	N/A	SB556096XUTG
	58U	55053-108	N/A	N/A	SB556108XUTG
Rack 19" EIA Clear	45U	55053-503	R2P	EVR19FM45U	SB556084XUAL
	52U/51U*	55053-515	R2P96	EVR19FM51U	SB556096XUAL
	58U	55053-508	N/A	EVR19FM58U	SB556108XUAL

Notes: \*CPI and Panduit racks are 52U. Pentair-Hoffman and Cooper B-Line Racks are 51U.




Integrated Ground Studs



Rack Ground Jumper Kit (Ordered Separately)



Bonded Assembly

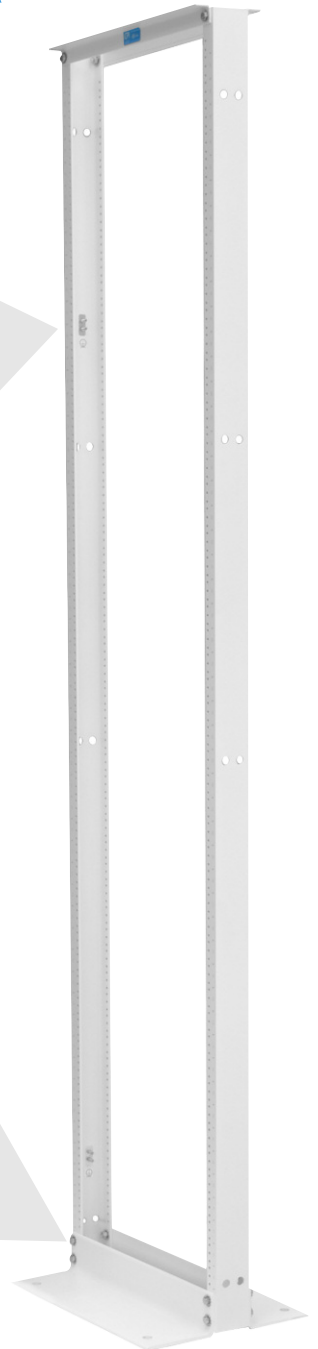

# Standard Rack 3"D (80 mm)

CPI's popular Standard Rack, which provides sturdy, heavy-duty support for a variety of IT equipment, now includes the following features:


**Features:**

- 19" EIA, Universal Rail Spacing
  - 1-3/4"H (44.45 mm) U spaces
  - #12-24 threaded mounting holes
  - Marked and numbered U spaces
- Three heights:
  - 45U, 7'H (2.1 m)
  - 52U, 8'H (2.4 m)
  - 58U, 9'H (2.7 m)
- Made from lightweight, aluminum extrusion
- Ships unassembled in a compact carton
- Bonded assembly with integrated ground studs
- Strong, 1000 lb (453.6 kg) weight capacity
- UL Listed, DUXR.E140851, Communications Circuit Accessory
- Five finishes:
  - Clear, grained aluminum
  - Painted, Black
  - Painted, Gray
  - Painted, Computer Beige
  - Painted, Glacier White
- Full range of matching accessory vertical and horizontal cable managers and shelves to match site, cabling and equipment requirements

Part Number	Description H x W Height - ft (m)	Shipping Weight lb (kg)
<b>Standard Rack, 3"D (80 mm)</b>		
55053-X03	7 (2.1) x 19", 45U	31 (14.1)
55053-X15	8 (2.4) x 19", 52U	37 (16.8)
55053-X08	9 (2.7) x 19", 58U	40 (18.1)
<b>Rack Ground Jumper Kit</b>		
40159-008	9'L (2.7 m) Ground Jumper and Antioxidant	2 (0.9)
<b>Global Vertical Cabling Section, Single-Sided</b>		
12831-X03	7 (2.1) H x 6"W (150 mm) x 6.76"D (171.7 mm)	19 (8.6)
<b>Global Standard Pack</b>		
57004-X03	Standard Rack and (2) Single-Sided Global Vertical Cabling Sections	67 (30.4)

X=Color: 5=Clear, 7=Black, E=Glacier White

**For more information about the Standard Rack, visit [www.chatsworth.com](http://www.chatsworth.com), call 800-834-4969 or email [techsupport@chatsworth.com](mailto:techsupport@chatsworth.com).**

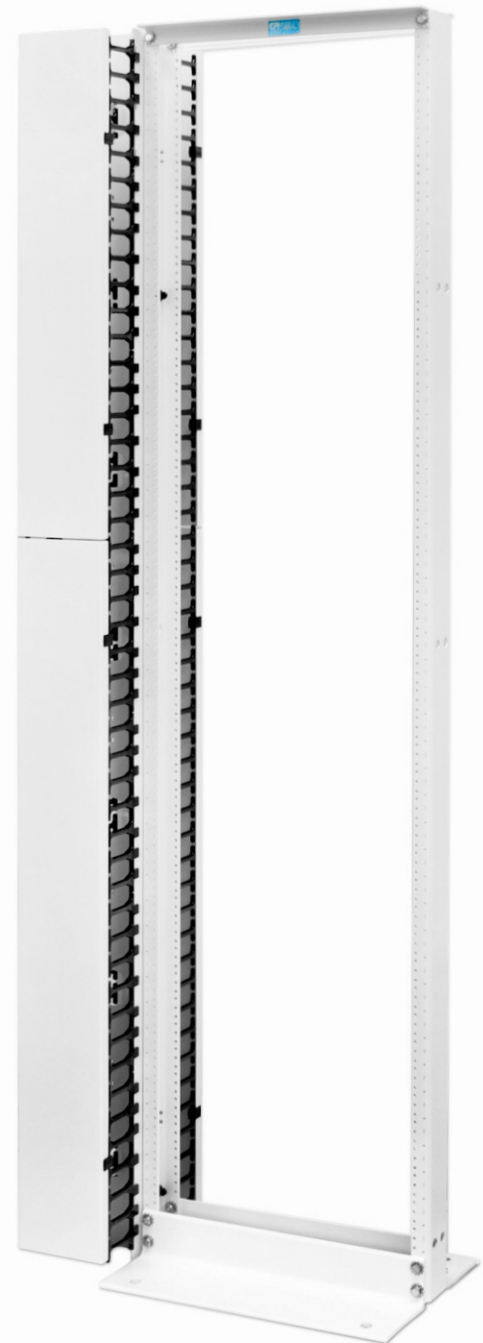

Standard Rack 3"D (80 mm) shown with (2) Single-Sided 6"W Global Vertical Cabling Sections

**Fast Fact**

- NEW Integrated grounding features also available for the Universal Rack.