

Service Parts for RMR Modular Enclosure


Door Kits

Doors for RMR Modular Enclosures are reversible to open from the right or left and can be attached to the front or rear of the enclosure. To reverse doors, you must move the hinges, and rotate the latch. Doors include hinges. Order latch separately.

Several options are available:

- Solid Metal Door
- Metal Door with Window
- Intake Door Assembly, which has a cutout near the bottom of the door for a filter or filter fan
- Exhaust Door Assembly, which has a cutout near the top of the door for a filter or filter fan
- AC Door Assembly, which has a cutout near the middle for a cooling unit
- Use Fixed Rear Metal Panel as an alternative to door in order to seal one side of the enclosure
- Order filters, filter fans and cooling units separately

Single Solid Metal Door For RMR Modular Enclosure

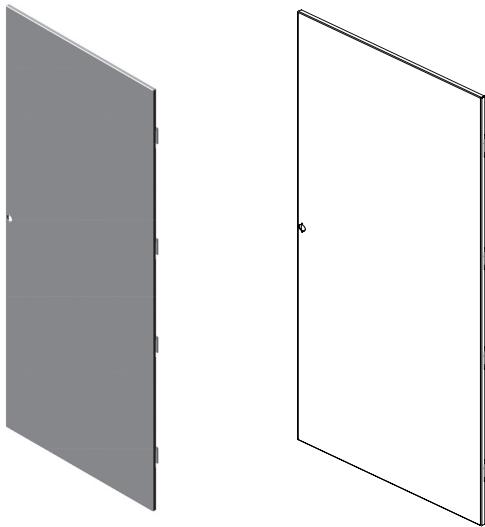

Part Number Enclosure Width in (mm)		Enclosure Height in (mm)	Shipping Weight lb (kg)
23.6 (600)	31.5 (800)		
37720-X01	37720-X07	47.2 (1200)	45 (20.5)
37720-X02	37720-X08	70.9 (1800)	63 (28.6)
37720-X03	37720-X09	78.7 (2000)	69 (31.3)
37720-X04	37720-X10	82.7 (2100)	72 (32.7)
37720-X05	37720-X11	86.6 (2200)	75 (34.1)
37720-X06	37720-X12	94.5 (2400)	80 (36.3)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 800 mm wide models.

For more information on RMR Industrial Enclosures, visit www.chatsworth.com/industrial-enclosures

US & Canada

+1-800-834-4969
Toronto, Ontario, Canada
+905-850-7770
chatsworth.com
techsupport@chatsworth.com

Latin America

+52-55-5203-7525
Toll Free within Mexico
01-800-01-7592
chatsworth.com.co

Europe

+44-1628-524-834
chatsworthproducts.co.uk

Middle East & Africa

Dubai, UAE
+971-4-2602125
chatsworth.ae


Asia Pacific

+86 21 6880-0266
chatsworth.com.cn



CHATSWORTH
PRODUCTS


Single Metal Door with Window for RMR Modular Enclosure

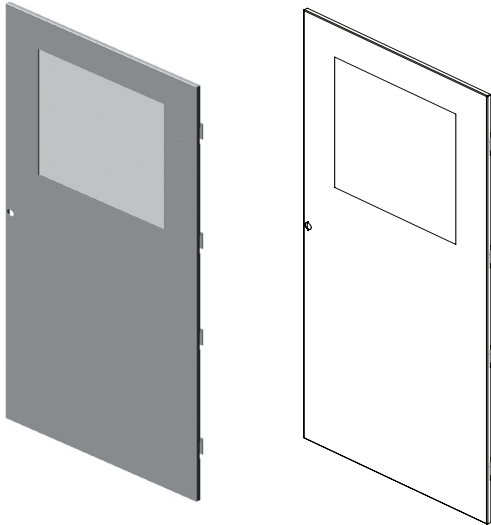

Part Number Enclosure Width in (mm)		Enclosure Height in (mm)	Shipping Weight lb (kg)
23.6 (600)	31.5 (800)		
37810-X01	37810-X07	47.2 (1200)	51 (23.2)
37810-X02	37810-X08	70.9 (1800)	70 (31.8)
37810-X03	37810-X09	78.7 (2000)	76 (34.5)
37810-X04	37810-X10	82.7 (2100)	80 (36.3)
37810-X05	37810-X11	86.6 (2200)	83 (37.7)
37810-X06	37810-X12	94.5 (2400)	89 (40.4)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 800 mm wide models.


Intake Door Assembly for RMR Modular Enclosure for 7" (177 mm) Filter Fan or Filter Kit

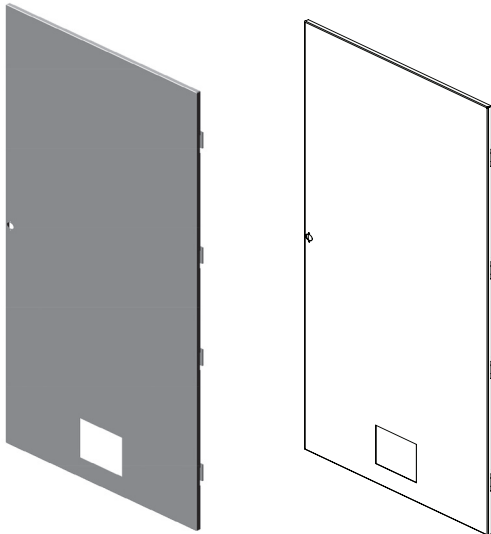

Part Number Enclosure Width in (mm)		Enclosure Height in (mm)	Shipping Weight lb (kg)
23.6 (600)	31.5 (800)		
37870-X01	37870-X07	47.2 (1200)	44 (20.0)
37870-X02	37870-X08	70.9 (1800)	61 (27.7)
37870-X03	37870-X09	78.7 (2000)	67 (30.4)
37870-X04	37870-X10	82.7 (2100)	70 (31.8)
37870-X05	37870-X11	86.6 (2200)	73 (33.2)
37870-X06	37870-X12	94.5 (2400)	79 (35.9)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 800 mm wide models.


Intake Door Assembly for RMR Modular Enclosure for 11.5" (291 mm) Filter Fan or Filter Kit

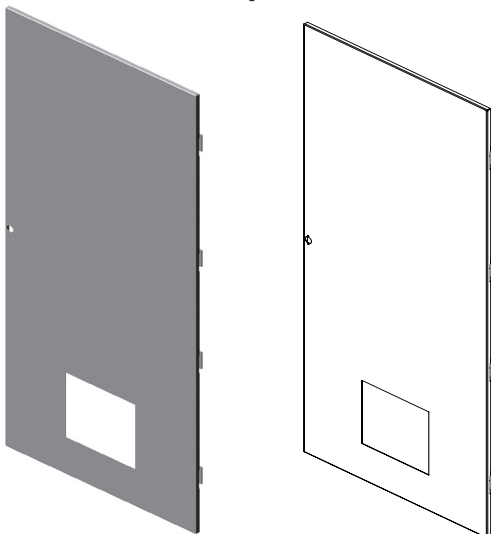

Part Number Enclosure Width in (mm)		Enclosure Height in (mm)	Shipping Weight lb (kg)
23.6 (600)	31.5 (800)		
37890-X01	37890-X07	47.2 (1200)	42 (19.1)
37890-X02	37890-X08	70.9 (1800)	60 (27.3)
37890-X03	37890-X09	78.7 (2000)	66 (30.0)
37890-X04	37890-X10	82.7 (2100)	69 (31.3)
37890-X05	37890-X11	86.6 (2200)	71 (32.3)
37890-X06	37890-X12	94.5 (2400)	77 (35.0)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 800 mm wide models.


Exhaust Door Assembly for RMR Modular Enclosure for 7" (177 mm) Filter Fan or Filter Kit

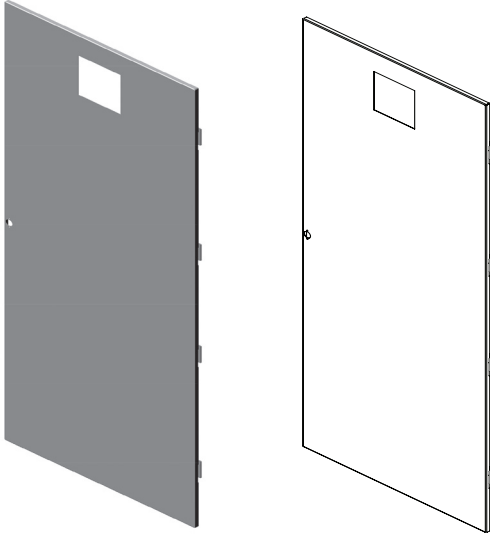

Part Number Enclosure Width in (mm)		Enclosure Height in (mm)	Shipping Weight lb (kg)
23.6 (600)	31.5 (800)		
37892-X01	37892-X07	47.2 (1200)	44 (20.0)
37892-X02	37892-X08	70.9 (1800)	61 (27.7)
37892-X03	37892-X09	78.7 (2000)	67 (30.4)
37892-X04	37892-X10	82.7 (2100)	70 (31.8)
37892-X05	37892-X11	86.6 (2200)	73 (33.2)
37892-X06	37892-X12	94.5 (2400)	79 (35.9)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 800 mm wide models.


Exhaust Door Assembly for RMR Modular Enclosure for 11.5" (291 mm) Filter Fan or Filter Kit

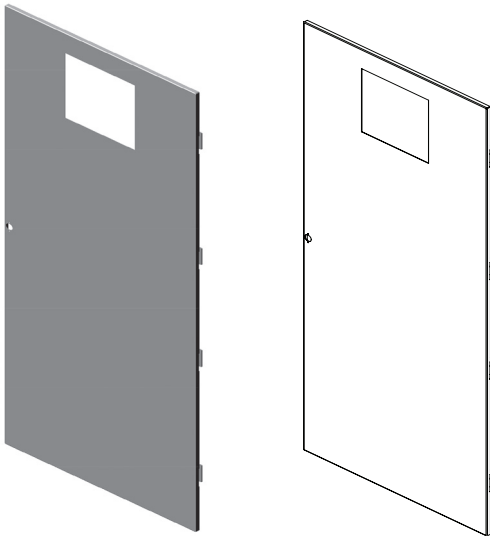

Part Number Enclosure Width in (mm)		Enclosure Height in (mm)	Shipping Weight lb (kg)
23.6 (600)	31.5 (800)		
37894-X01	37894-X07	47.2 (1200)	42 (19.1)
37894-X02	37894-X08	70.9 (1800)	60 (27.3)
37894-X03	37894-X09	78.7 (2000)	66 (30.0)
37894-X04	37894-X10	82.7 (2100)	69 (31.3)
37894-X05	37894-X11	86.6 (2200)	71 (32.3)
37894-X06	37894-X12	94.5 (2400)	77 (35.0)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 800 mm wide models.


AC Door Assembly for RMR Modular Enclosure for 3000-4000 BTU/hr (879-1172 W) Cooling Unit – Right-Hand Hinged

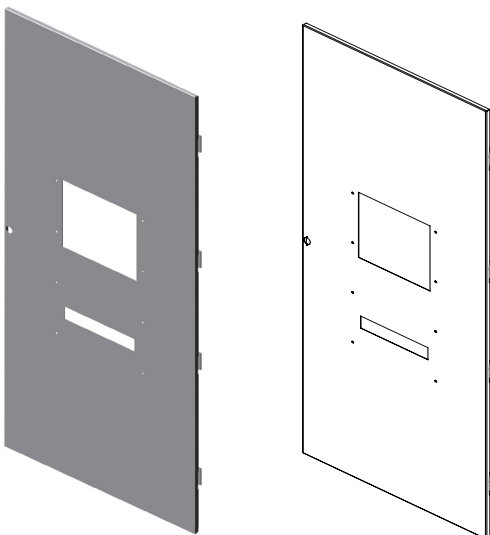

Part Number Enclosure Width in (mm)		Enclosure Height in (mm)	Shipping Weight lb (kg)
23.6 (600)	31.5 (800)		
37872-X01	37872-X07	47.2 (1200)	34 (15.5)
37872-X02	37872-X08	70.9 (1800)	41 (18.6)
37872-X03	37872-X09	78.7 (2000)	53 (24.1)
37872-X04	37872-X10	82.7 (2100)	56 (25.5)
37872-X05	37872-X11	86.6 (2200)	58 (26.4)
37872-X06	37872-X12	94.5 (2400)	63 (28.6)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 800 mm wide models.

AC Door Assembly for RMR Modular Enclosure for 3000-4000 BTU/hr (879-1172 W) Cooling Unit – Left-Hand Hinged

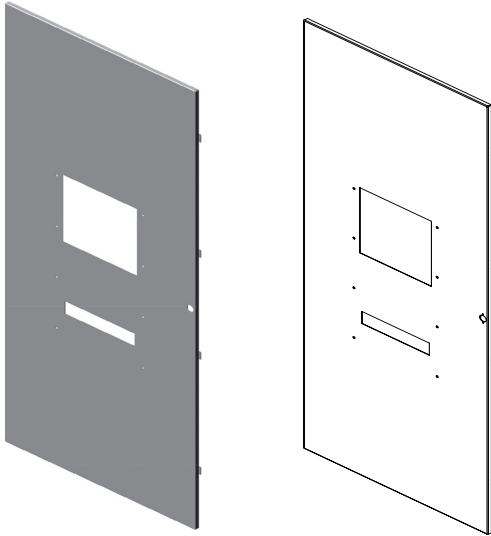

Part Number Enclosure Width in (mm)		Enclosure Height in (mm)	Shipping Weight lb (kg)
23.6 (600)	31.5 (800)		
37896-X01	37896-X07	47.2 (1200)	41 (18.6)
37896-X02	37896-X08	70.9 (1800)	59 (26.8)
37896-X03	37896-X09	78.7 (2000)	65 (29.5)
37896-X04	37896-X10	82.7 (2100)	68 (30.9)
37896-X05	37896-X11	86.6 (2200)	71 (32.3)
37896-X06	37896-X12	94.5 (2400)	76 (34.5)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 800 mm wide models.

Latch Assembly Double Bit for RMR Modular Enclosure




Part Number	Height in (mm)	Shipping Weight lb (kg)
37730-001	47.2 (1200)	4 (1.9)
37730-002	70.9 (1800)	4 (1.9)
37730-003	78.7 (2000)	5 (2.3)
37730-004	82.7 (2100)	5 (2.3)
37730-005	86.6 (2200)	5 (2.3)
37730-006	94.5 (2400)	5 (2.3)

Latch Assembly T Handle for RMR Modular Enclosure



Part Number	Height in (mm)	Shipping Weight lb (kg)
37740-001	47.2 (1200)	4 (1.9)
37740-002	70.9 (1800)	5 (2.3)
37740-003	78.7 (2000)	5 (2.3)
37740-004	82.7 (2100)	5 (2.3)
37740-005	86.6 (2200)	5 (2.3)
37740-006	94.5 (2400)	5 (2.3)

Fixed Rear Metal Panel for RMR Modular Enclosure (Alternative to a Door)
 Use as an alternative to a door to seal one side of the enclosure; no latch kit required.

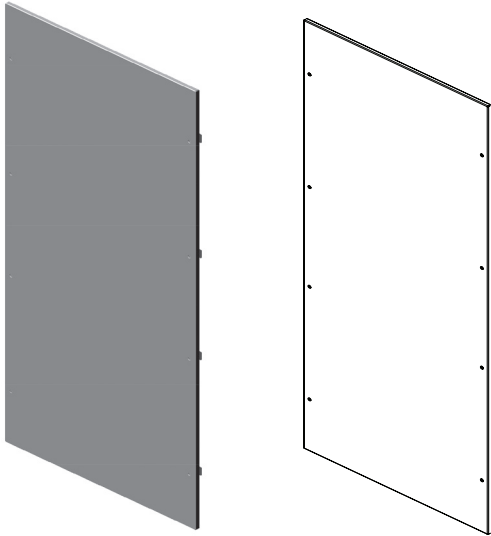


Part Number Enclosure Width in (mm)		Enclosure Height in (mm)	Shipping Weight lb (kg)
23.6 (600)	31.5 (800)		
37880-X01	37880-X07	47.2 (1200)	39 (17.7)
37880-X02	37880-X08	70.9 (1800)	54 (24.5)
37880-X03	37880-X09	78.7 (2000)	59 (26.8)
37880-X04	37880-X10	82.7 (2100)	62 (28.2)
37880-X05	37880-X11	86.6 (2200)	64 (29.1)
37880-X06	37880-X12	94.5 (2400)	69 (31.1)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 800 mm wide models.

RMR Modular Enclosure Panels

All CPI panels are fully sealed with formed-in-place foam gaskets to maintain NEMA Type 12 and IP 55 protection ratings.


Solid Metal Top Panel Assembly for RMR Modular Enclosure

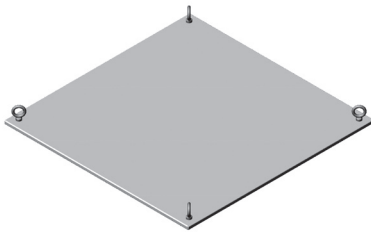

Part Number Enclosure Width in (mm)		Enclosure Depth in (mm)	Shipping Weight lb (kg)
23.6 (600)	31.5 (800)		
37760-X01	37760-X10	15.8 (400)	17 (7.8)
37760-X02	37760-X11	19.7 (500)	19 (8.7)
37760-X03	37760-X12	23.6 (600)	21 (9.6)
37760-X04	37760-X13	27.6 (700)	24 (10.9)
37760-X05	37760-X14	31.5 (800)	26 (11.8)
37760-X06	37760-X15	35.4 (900)	29 (13.2)
37760-X07	37760-X16	39.4 (1000)	31 (14.1)
37760-X08	37760-X17	43.3 (1100)	33 (15.0)
37760-X09	37760-X18	47.2 (1200)	36 (16.4)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 800 mm wide models.

Gland Top Panel Assembly for RMR Modular Enclosure

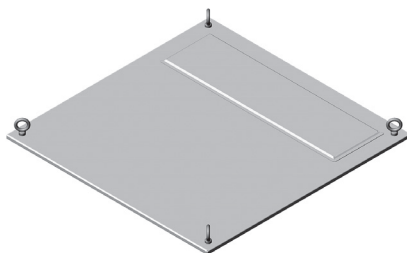


Part Number Enclosure Width in (mm)		Enclosure Depth in (mm)	Shipping Weight lb (kg)
23.6 (600)	31.5 (800)		
37929-X01	37929-X10	15.8 (400)	14 (6.4)
37929-X02	37929-X11	19.7 (500)	17 (7.8)
37929-X03	37929-X12	23.6 (600)	19 (8.7)
37929-X04	37929-X13	27.6 (700)	22 (10.0)
37929-X05	37929-X14	31.5 (800)	24 (10.9)
37929-X06	37929-X15	35.4 (900)	26 (11.8)
37929-X07	37929-X16	39.4 (1000)	29 (13.2)
37929-X08	37929-X17	43.3 (1100)	31 (14.1)
37929-X09	37929-X18	47.2 (1200)	34 (15.5)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 800 mm wide models.

Exhaust Metal Top Panel Assembly for RMR Modular Enclosure for 11.5" (291 mm) Filter Fan Kit


Includes opening at the center to accommodate a 11.5 in (291 mm) Filter Fan Kit (ordered separately). Use with side panels or doors that have 11.5 in (291 mm) Intake Filter Kits.

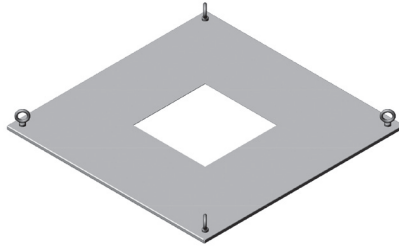

Part Number Enclosure Width in (mm)		Enclosure Depth in (mm)	Shipping Weight lb (kg)
23.6 (600)	31.5 (800)		
37884-X01	37884-X10	15.8 (400)	14 (6.4)
37884-X02	37884-X11	19.7 (500)	17 (7.8)
37884-X03	37884-X12	23.6 (600)	19 (8.7)
37884-X04	37884-X13	27.6 (700)	22 (10)
37884-X05	37884-X14	31.5 (800)	24 (10.9)
37884-X06	37884-X15	35.4 (900)	26 (11.8)
37884-X07	37884-X16	39.4 (1000)	29 (13.2)
37884-X08	37884-X17	43.3 (1100)	31 (14.1)
37884-X09	37884-X18	47.2 (1200)	34 (15.5)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 800 mm wide models.


Bottom Panel Assembly With Removable Gland Plates for RMR Modular Enclosure

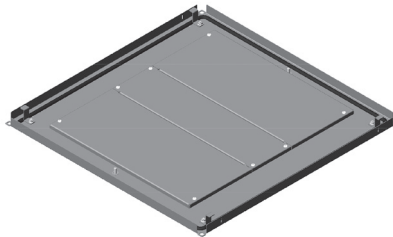

Part Number Enclosure Width in (mm)		Enclosure Depth in (mm)	Shipping Weight lb (kg)
23.6 (600)	31.5 (800)		
37790-X01	37790-X10	15.8 (400)	19 (8.7)
37790-X02	37790-X11	19.7 (500)	22 (10.0)
37790-X03	37790-X12	23.6 (600)	25 (11.4)
37790-X04	37790-X13	27.6 (700)	28 (12.8)
37790-X05	37790-X14	31.5 (800)	30 (13.7)
37790-X06	37790-X15	35.4 (900)	33 (15.0)
37790-X07	37790-X16	39.4 (1000)	36 (16.4)
37790-X08	37790-X17	43.3 (1100)	39 (17.7)
37790-X09	37790-X18	47.2 (1200)	42 (19.1)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 800 mm wide models.

Solid Bottom Panel Assembly for RMR Modular Enclosure

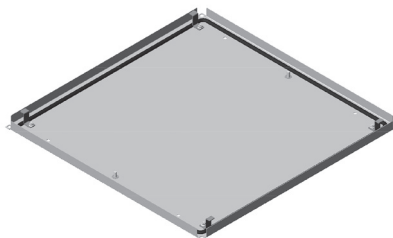

Part Number Enclosure Width in (mm)		Enclosure Depth in (mm)	Shipping Weight lb (kg)
23.6 (600)	31.5 (800)		
37798-X01	37798-X10	15.8 (400)	19 (8.7)
37798-X02	37798-X11	19.7 (500)	22 (10.0)
37798-X03	37798-X12	23.6 (600)	25 (11.4)
37798-X04	37798-X13	27.6 (700)	28 (12.8)
37798-X05	37798-X14	31.5 (800)	30 (13.7)
37798-X06	37798-X15	35.4 (900)	33 (15.0)
37798-X07	37798-X16	39.4 (1000)	36 (16.4)
37798-X08	37798-X17	43.3 (1100)	39 (17.7)
37798-X09	37798-X18	47.2 (1200)	42 (19.1)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 800 mm wide models.

Single Metal Side Panel Assembly for RMR Modular Enclosure



Part Number Cabinet Depth – in (mm)									Cabinet Height in (mm)	Shipping Weight lb (kg)
15.8 (400)	19.7 (500)	23.6 (600)	27.6 (700)	31.5 (800)	35.4 (900)	39.4 (1000)	43.3 (1100)	47.2 (1200)		
37750-X01	37750-X07	37750-X13	37750-X19	37750-X25	37750-X31	37750-X37	37750-X43	37750-X49	47.2 (1200)	50 (22.7)
37750-X02	37750-X08	37750-X14	37750-X20	37750-X26	37750-X32	37750-X38	37750-X44	37750-X50	70.9 (1800)	72 (32.7)
37750-X03	37750-X09	37750-X15	37750-X21	37750-X27	37750-X33	37750-X39	37750-X45	37750-X52	78.7 (2000)	79 (35.9)
37750-X04	37750-X10	37750-X16	37750-X22	37750-X28	37750-X34	37750-X40	37750-X46	37750-X52	82.7 (2100)	82 (37.2)
37750-X05	37750-X11	37750-X17	37750-X23	37750-X29	37750-X35	37750-X41	37750-X47	37750-X53	86.6 (2200)	86 (39.1)
37750-X06	37750-X12	37750-X18	37750-X24	37750-X30	37750-X36	37750-X42	37750-X48	37750-X54	94.5 (2400)	93 (42.2)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 1200 mm deep models.

Intake Side Panel Assembly for RMR Modular Enclosure for 7" (177 mm) Filter Fan or Filter Kit

Intake Side Panel Assembly includes opening at the bottom to accommodate either 7 in (177 mm) Filter Fan or Filter Kit (ordered separately).



Part Number Cabinet Depth – in (mm)									Cabinet Height in (mm)	Shipping Weight lb (kg)
15.8 (400)	19.7 (500)	23.6 (600)	27.6 (700)	31.5 (800)	35.4 (900)	39.4 (1000)	43.3 (1100)	47.2 (1200)		
37875-X01	37875-X07	37875-X13	37875-X19	37875-X25	37875-X31	37875-X37	37875-X43	37875-X49	47.2 (1200)	49 (22.3)
37875-X02	37875-X08	37875-X14	37875-X20	37875-X26	37875-X32	37875-X38	37875-X44	37875-X50	70.9 (1800)	71 (32.3)
37875-X03	37875-X09	37875-X15	37875-X21	37875-X27	37875-X33	37875-X39	37875-X45	37875-X52	78.7 (2000)	78 (35.4)
37875-X04	37875-X10	37875-X16	37875-X22	37875-X28	37875-X34	37875-X40	37875-X46	37875-X52	82.7 (2100)	81 (36.8)
37875-X05	37875-X11	37875-X17	37875-X23	37875-X29	37875-X35	37875-X41	37875-X47	37875-X53	86.6 (2200)	85 (38.6)
37875-X06	37875-X12	37875-X18	37875-X24	37875-X30	37875-X36	37875-X42	37875-X48	37875-X54	94.5 (2400)	92 (41.8)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 1200 mm deep models.

Intake Side Panel Assembly for RMR Modular Enclosure for 11.5" (291 mm) Filter Fan or Filter Kit

Intake Side Panel Assembly includes opening at the bottom to accommodate either 11.5 in (291 mm) Filter Fan or Filter Kit (ordered separately).



Part Number Cabinet Depth – in (mm)									Cabinet Height in (mm)	Shipping Weight lb (kg)
15.8 (400)	19.7 (500)	23.6 (600)	27.6 (700)	31.5 (800)	35.4 (900)	39.4 (1000)	43.3 (1100)	47.2 (1200)		
37876-X01	37876-X07	37876-X13	37876-X19	37876-X25	37876-X31	37876-X37	37876-X43	37876-X49	47.2 (1200)	48 (21.8)
37876-X02	37876-X08	37876-X14	37876-X20	37876-X26	37876-X32	37876-X38	37876-X44	37876-X50	70.9 (1800)	69 (31.3)
37876-X03	37876-X09	37876-X15	37876-X21	37876-X27	37876-X33	37876-X39	37876-X45	37876-X52	78.7 (2000)	76 (34.5)
37876-X04	37876-X10	37876-X16	37876-X22	37876-X28	37876-X34	37876-X40	37876-X46	37876-X52	82.7 (2100)	79 (35.9)
37876-X05	37876-X11	37876-X17	37876-X23	37876-X29	37876-X35	37876-X41	37876-X47	37876-X53	86.6 (2200)	83 (37.7)
37876-X06	37876-X12	37876-X18	37876-X24	37876-X30	37876-X36	37876-X42	37876-X48	37876-X54	94.5 (2400)	90 (40.9)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 1200 mm deep models.

Exhaust Side Panel Assembly for RMR Modular Enclosure for 7" (177 mm) Filter Fan or Filter Kit

Exhaust Side Panel Assembly includes opening at the top to accommodate either 7 in (177 mm) Filter Fan or Filter Kit (ordered separately).



Part Number Cabinet Depth – in (mm)									Cabinet Height in (mm)	Shipping Weight lb (kg)
15.8 (400)	19.7 (500)	23.6 (600)	27.6 (700)	31.5 (800)	35.4 (900)	39.4 (1000)	43.3 (1100)	47.2 (1200)		
37877-X01	37877-X07	37877-X13	37877-X19	37877-X25	37877-X31	37877-X37	37877-X43	37877-X49	47.2 (1200)	49 (22.3)
37877-X02	37877-X08	37877-X14	37877-X20	37877-X26	37877-X32	37877-X38	37877-X44	37877-X50	70.9 (1800)	71 (32.3)
37877-X03	37877-X09	37877-X15	37877-X21	37877-X27	37877-X33	37877-X39	37877-X45	37877-X52	78.7 (2000)	78 (35.4)
37877-X04	37877-X10	37877-X16	37877-X22	37877-X28	37877-X34	37877-X40	37877-X46	37877-X52	82.7 (2100)	81 (36.8)
37877-X05	37877-X11	37877-X17	37877-X23	37877-X29	37877-X35	37877-X41	37877-X47	37877-X53	86.6 (2200)	85 (38.6)
37877-X06	37877-X12	37877-X18	37877-X24	37877-X30	37877-X36	37877-X42	37877-X48	37877-X54	94.5 (2400)	92 (41.8)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 1200 mm deep models.

Exhaust Side Panel Assembly for RMR Modular Enclosure for 11.5" (291 mm) Filter Fan or Filter Kit

Exhaust Side Panel Assembly includes opening at the top to accommodate either 11.5 in (291 mm) Filter Fan or Filter Kit (ordered separately).



Part Number Cabinet Depth – in (mm)									Cabinet Height in (mm)	Shipping Weight lb (kg)
15.8 (400)	19.7 (500)	23.6 (600)	27.6 (700)	31.5 (800)	35.4 (900)	39.4 (1000)	43.3 (1100)	47.2 (1200)		
37878-X01	37878-X07	37878-X13	37878-X19	37878-X25	37878-X31	37878-X37	37878-X43	37878-X49	47.2 (1200)	48 (21.8)
37878-X02	37878-X08	37878-X14	37878-X20	37878-X26	37878-X32	37878-X38	37878-X44	37878-X50	70.9 (1800)	69 (31.3)
37878-X03	37878-X09	37878-X15	37878-X21	37878-X27	37878-X33	37878-X39	37878-X45	37878-X52	78.7 (2000)	76 (34.5)
37878-X04	37878-X10	37878-X16	37878-X22	37878-X28	37878-X34	37878-X40	37878-X46	37878-X52	82.7 (2100)	79 (35.9)
37878-X05	37878-X11	37878-X17	37878-X23	37878-X29	37878-X35	37878-X41	37878-X47	37878-X53	86.6 (2200)	83 (37.7)
37878-X06	37878-X12	37878-X18	37878-X24	37878-X30	37878-X36	37878-X42	37878-X48	37878-X54	94.5 (2400)	90 (40.9)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 1200 mm deep models.


AC Side Panel Assembly for RMR Modular Enclosure for a 5000-7000 Btu/hr (1465-2051 W) Cooling Unit

AC Side Panel Assembly includes openings at the middle to accommodate the Cooling Units inlet, outlet and attachment points.



Part Number Cabinet Depth – in (mm)									Cabinet Height in (mm)	Shipping Weight lb (kg)
15.8 (400)	19.7 (500)	23.6 (600)	27.6 (700)	31.5 (800)	35.4 (900)	39.4 (1000)	43.3 (1100)	47.2 (1200)		
37879-X01	37879-X07	37879-X13	37879-X19	37879-X25	37879-X31	37879-X37	37879-X43	37879-X49	47.2 (1200)	46 (20.9)
37879-X02	37879-X08	37879-X14	37879-X20	37879-X26	37879-X32	37879-X38	37879-X44	37879-X50	70.9 (1800)	66 (30.0)
37879-X03	37879-X09	37879-X15	37879-X21	37879-X27	37879-X33	37879-X39	37879-X45	37879-X52	78.7 (2000)	72 (32.7)
37879-X04	37879-X10	37879-X16	37879-X22	37879-X28	37879-X34	37879-X40	37879-X46	37879-X52	82.7 (2100)	76 (34.5)
37879-X05	37879-X11	37879-X17	37879-X23	37879-X29	37879-X35	37879-X41	37879-X47	37879-X53	86.6 (2200)	79 (35.9)
37879-X06	37879-X12	37879-X18	37879-X24	37879-X30	37879-X36	37879-X42	37879-X48	37879-X54	94.5 (2400)	86 (39.1)

 X= Color; C=Black, G= Hammer Gray. Shipping weights are for 1200 mm deep models.



RMR Modular Enclosure External Baying Brackets
Includes 8 external baying brackets.

Part Number	Shipping Weight lb (kg)
37821-X01	5 (2.3)



RMR Modular Enclosure Flat Internal Baying Brackets
Includes 4 flat baying brackets.

Part Number	Shipping Weight lb (kg)
37822-X01	5 (2.3)



RMR Modular Enclosure Corner Internal Baying Brackets
Includes 8 external baying brackets.

Part Number	Shipping Weight lb (kg)
37824-X01	5 (2.3)




RMR Modular Enclosure Leveler Kit
Leveler Kit attaches to the bottom of the enclosure if not using a plinth base. Includes four levelers with M10 threaded stems and swivel pads to help compensate for height differences in floor irregularities and jam nuts.

Part Number	Shipping Weight lb (kg)
37925-001	3 (1.4)

Grounding and Bonding

Ground Wire Kit includes jumpers and hardware to bond the enclosure frame, panels and doors.

- Enclosures ordered from the matrix include Kit P/N 37922-001 with #12, 6"L (153 mm) jumpers to connect the top panel, side panels and doors to the enclosure frame
- Kit P/Ns 37922-00X have quick disconnect fittings; other models have ring terminals

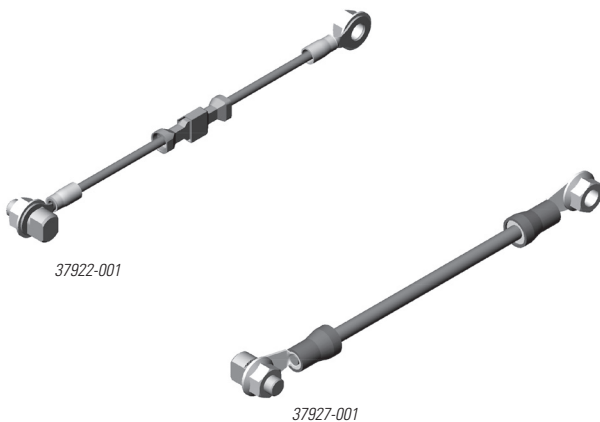

RMR Modular Enclosure Grounding Wire Kit			
Part Number	Length in (mm)	Gauge (AWG)	Shipping Weight lb (kg)
37922-003	8 (204)	12	3 (1.4)
37926-002	12 (305)	6	4 (1.9)
37927-002	12 (305)	2	5 (2.3)



Scan or click here to visit our CPI Online Catalog.

For more information on RMR Industrial Enclosures, visit www.chatsworth.com/industrial-enclosures