

Service Parts for RMR Wall-Mount Enclosures


Door Kits for RMR Wall-Mount Enclosures

Replacement doors for RMR Wall-Mount Enclosures are removable and can be easily replaced if a door is damaged. Order latch separately.

Several options are available:

- Solid Metal Door
- Metal Door with Window

Single Tempered Glass Door for RMR Wall-Mount Enclosures

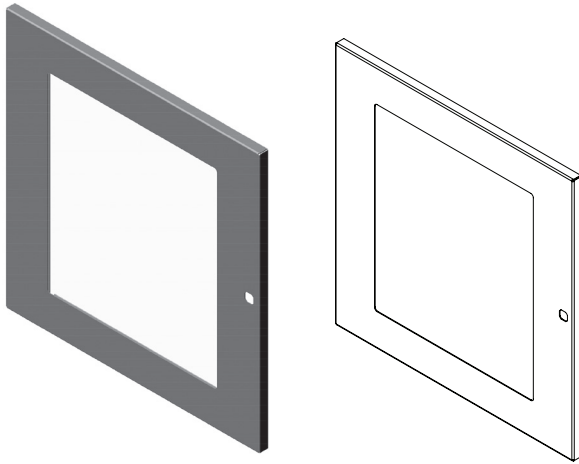

Part Number Enclosure Width in (mm)		Enclosure Height in (mm)	U	Shipping Weight lb (kg)
23.6 (600)	27.6 (700)			
37060-X01	37060-X31	19.1 (486)	9	19 (8.7)
37060-X02	37060-X32	20.9 (530)	10	20 (9.1)
37060-X03	37060-X33	22.6 (575)	11	22 (10.0)
37060-X04	37060-X34	24.4 (619)	12	23 (10.5)
37060-X05	37060-X35	26.1 (664)	13	24 (10.9)
37060-X06	37060-X36	27.9 (708)	14	25 (11.4)
37060-X07	37060-X37	29.7 (753)	15	26 (11.8)
37060-X08	37060-X38	31.4 (797)	16	27 (12.3)
37060-X09	37060-X39	33.1 (841)	17	29 (13.2)
37060-X10	37060-X40	34.9 (886)	18	30 (13.7)
37060-X11	37060-X41	36.6 (930)	19	31 (14.1)
37060-X12	37060-X42	38.4 (975)	20	32 (14.6)
37060-X13	37060-X43	40.1 (1019)	21	33 (15.0)
37060-X14	37060-X44	41.9 (1064)	22	34 (15.5)
37060-X15	37060-X45	43.6 (1108)	23	36 (16.4)
37060-X16	37060-X46	45.4 (1153)	24	37 (16.8)
37060-X17	37060-X47	47.1 (1197)	25	38 (17.3)
37060-X18	37060-X48	48.9 (1241)	26	39 (17.7)

X= Color; C=Black, G= Hammer Gray. Shipping weights are for 27.6 in (700 mm) wide models.

For more information on RMR Industrial Enclosures, visit www.chatsworth.com/industrial-enclosures

US & Canada

+1-800-834-4969
 Toronto, Ontario, Canada
 +905-850-7770
 chatsworth.com
 techsupport@chatsworth.com

Latin America

+52-55-5203-7525
 Toll Free within Mexico
 01-800-01-7592
 chatsworth.com.co

Europe

+44-1628-524-834
 chatsworthproducts.co.uk

Middle East & Africa

Dubai, UAE
 +971-4-2602125
 chatsworth.ae

Asia Pacific

+86 21 6880-0266
 chatsworth.com.cn



CHATSWORTH
 PRODUCTS

Service Parts for RMR Wall-Mount Enclosures


Door Kits for RMR Wall-Mount Enclosures

Replacement doors for RMR Wall-Mount Enclosures are removable and can be easily replaced if a door is damaged. Order latch separately.

Several options are available:

- Solid Metal Door
- Metal Door with Window

Single Solid Metal Door for RMR Wall-Mount Enclosures

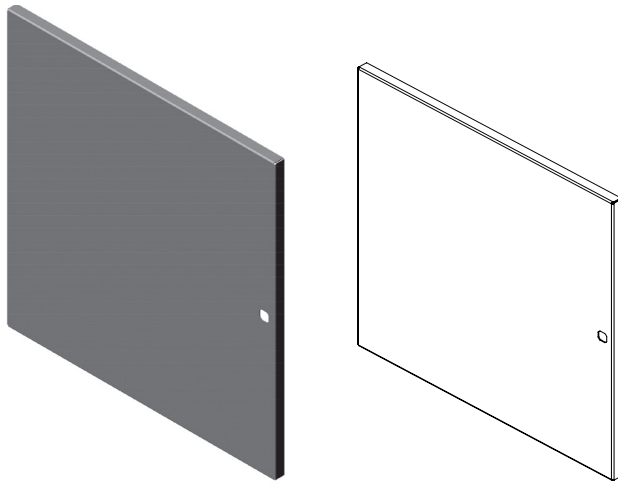

Part Number Enclosure Width in (mm)		Enclosure Height in (mm)	U	Shipping Weight lb (kg)
23.6 (600)	27.6 (700)			
37070-X01	37070-X31	19.1 (486)	9	15 (6.9)
37070-X02	37070-X32	20.9 (530)	10	16 (7.3)
37070-X03	37070-X33	22.6 (575)	11	17 (7.8)
37070-X04	37070-X34	24.4 (619)	12	17 (7.8)
37070-X05	37070-X35	26.1 (664)	13	18 (8.2)
37070-X06	37070-X36	27.9 (708)	14	19 (8.7)
37070-X07	37070-X37	29.7 (753)	15	20 (9.1)
37070-X08	37070-X38	31.4 (797)	16	22 (10)
37070-X09	37070-X39	33.1 (841)	17	23 (10.5)
37070-X10	37070-X40	34.9 (886)	18	24 (10.9)
37070-X11	37070-X41	36.6 (930)	19	24 (10.9)
37070-X12	37070-X42	38.4 (975)	20	25 (11.4)
37070-X13	37070-X43	40.1 (1019)	21	26 (11.8)
37070-X14	37070-X44	41.9 (1064)	22	27 (12.3)
37070-X15	37070-X45	43.6 (1108)	23	28 (12.8)
37070-X16	37070-X46	45.4 (1153)	24	29 (13.2)
37070-X17	37070-X47	47.1 (1197)	25	30 (13.7)
37070-X18	37070-X48	48.9 (1241)	26	31 (14.1)

X= Color; C=Black; G= Hammer Gray. Shipping weights are for 27.6 in (700 mm) wide models.

For more information on RMR Industrial Enclosures, visit www.chatsworth.com/industrial-enclosures

US & Canada

+1-800-834-4969
 Toronto, Ontario, Canada
 +905-850-7770
 chatsworth.com
 techsupport@chatsworth.com

Latin America

+52-55-5203-7525
 Toll Free within Mexico
 01-800-01-7592
 chatsworth.com.co

Europe

+44-1628-524-834
 chatsworthproducts.co.uk

Middle East & Africa

Dubai, UAE
 +971-4-2602125
 chatsworth.ae

Asia Pacific

+86 21 6880-0266
 chatsworth.com.cn



CHATSWORTH
 PRODUCTS

Service Parts for RMR Wall-Mount Enclosures

Door Latch Kit for RMR Wall-Mount Enclosures

Replacement Door Latch Kit for RMR Wall-Mount Enclosures. Order latch separately.



Door Latch Kit for RMR Wall-Mount Enclosure		
Part Number	Enclosure Depth – in (mm)	Shipping Weight lb (kg)
37043-001	20.0 (510)	2 (0.9)
37043-002	24.0 (610)	2 (0.9)
37043-003	29.9 (760)	2 (0.9)

For more information on RMR Industrial Enclosures, visit www.chatsworth.com/industrial-enclosures

US & Canada

+1-800-834-4969
 Toronto, Ontario, Canada
 +905-850-7770
 chatsworth.com
 techsupport@chatsworth.com

Latin America

+52-55-5203-7525
 Toll Free within Mexico
 01-800-01-7592
 chatsworth.com.co

Europe

+44-1628-524-834
 chatsworthproducts.co.uk

Middle East & Africa

Dubai, UAE
 +971-4-2602125
 chatsworth.ae

Asia Pacific

+86 21 6880-0266
 chatsworth.com.cn




CHATSWORTH
 PRODUCTS

Service Parts for RMR Wall-Mount Enclosures

Filter Fans

Replacement Filter Fans for wall-mount enclosures. Use Filter Fans in nonhazardous environments with outside temperature range that is lower than the temperature required in the enclosure.

- Side-mounting
 - Supports side-to-side airflow
 - Easy, tool-less installation
 - Maintains NEMA Type 12 protection ratings
 - Hinged grill for easy filter replacement
 - Optimized airflow and reduced energy consumption
 - Fluted filter mat allows 300% longer service time
- Standard size is:
- Side mounted, 38 CFM (65 CMH) unimpeded airflow, 115V, with filter for 6" x 6" (153 mm x 153 mm) cutout

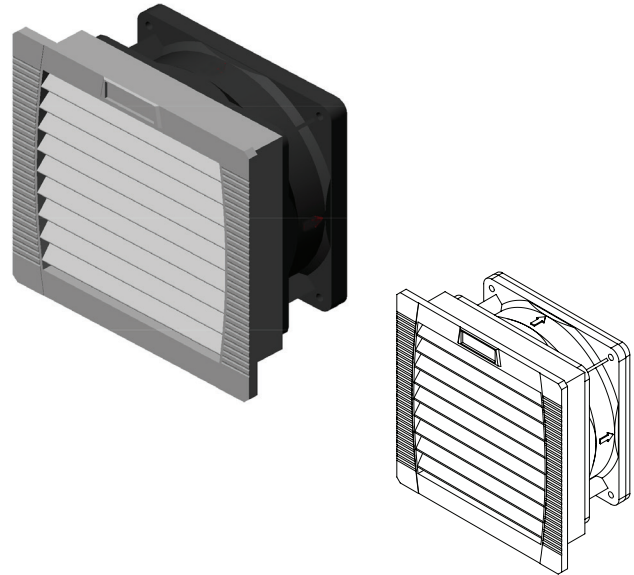

Part Number Fan Configuration		Cutout Size	Airflow	Voltage	Color	Shipping Weight lb (kg)
Intake	Exhaust	in (mm)	CFM (CMH)			
37101-001	37101-002	6 (153)	38 (65)	115	Hammer Gray	5 (2.3)
37101-003	37101-004	6 (153)	38 (65)	230	Hammer Gray	5 (2.3)
37101-005	37101-006	6 (153)	38 (65)	115	Black	5 (2.3)
37101-007	37101-008	6 (153)	38 (65)	230	Black	5 (2.3)

Consult Thermal Management Accessories for RMR Enclosure Systems data sheet for more detailed specifications. [RMR Thermal Accessories](#)

RMR Enclosure Power Cord for Filer Fan			
Part Number	Voltage	Cord Type	Shipping Weight lb (kg)
37902-001	125	NEMA 5-15P	2 (0.9)
37902-002	250	NEMA 6-15P	2 (0.9)
37902-003	250	IEC C14	2 (0.9)

Color is Black.

RMR Wall-Mount Enclosure Filter Kit		
Part Number	Filter Cutout in (mm)	Shipping Weight lb (kg)
37102-00X	6 (153)	4 (1.9)

X= Color; C=Black, G= Hammer Gray.

For more information on RMR Industrial Enclosures, visit www.chatsworth.com/industrial-enclosures

US & Canada

+1-800-834-4969
Toronto, Ontario, Canada
+905-850-7770
chatsworth.com
techsupport@chatsworth.com

Latin America

+52-55-5203-7525
Toll Free within Mexico
01-800-01-7592
chatsworth.com.co

Europe

+44-1628-524-834
chatsworthproducts.co.uk

Middle East & Africa

Dubai, UAE
+971-4-2602125
chatsworth.ae

Asia Pacific

+86 21 6880-0266
chatsworth.com.cn




CHATSWORTH
PRODUCTS

Service Parts for RMR Wall-Mount Enclosures

Cooling Unit by Pfannenberg for RMR Wall-Mount Enclosure Systems

Replacement cooling unit for RMR Wall-Mount Enclosures. Closed-loop cooling is required when the ambient temperature is greater than the target internal temperature of the enclosure, or when higher ingress protection (NEMA Type 12 rating) is necessary.

- Side-mounting
- Able to perform efficiently in high temperature areas
- Uses environmentally friendly HFC-free R134a refrigerant
- Backward curve impeller fan optimizes airflow and extends service life
- Condenser coils are coated with corrosion protection to extend service life
- Wide condenser fin spacing reduces particulate clogging while balancing performance
- Hermetically sealed compressors prevent refrigerant loss
- Condensate drain port to remove moisture
- Closed-Loop Cooling isolates the external ambient air from the internally conditioned air, eliminating the risk of contaminants entering the enclosure
- Standard size is:
 - Side mounted, 900-1,300 Btu/hr (263-381 W), 115V

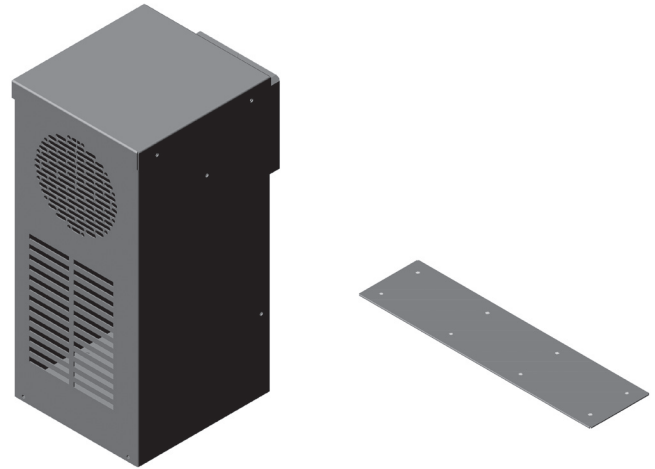

RMR Wall-Mount Enclosure Indoor NEMA Type 12 Cooling Units (900-1300 Btu/hr (263-381 W) Capacity)			
Part Number	Voltage	Color	Shipping Weight lb (kg)
37103-001	115	Hammer Gray	35 (15.9)
37103-002	230	Hammer Gray	35 (15.9)
37103-003	115	Black	35 (15.9)
37103-004	230	Black	35 (15.9)

Gland Plates for RMR Wall-Mount Enclosure Systems

Replacement gland plates feature allows pre-existing wiring or equipment to be installed in the cabinet.

RMR Wall-Mount Enclosure Gland Plates		
Part Number	Enclosure Width in (m)	Shipping Weight lb (kg)
37080-X01	23.7 (600)	6 (2.8)
37080-X02	24.7 (625)	7 (3.2)
37080-X03	25.6 (650)	7 (3.2)
37080-X04	26.6 (675)	7 (3.2)
37080-X05	27.6 (700)	7 (3.2)

X= Color; C=Black, G= Hammer Gray.

For more information on RMR Industrial Enclosures, visit www.chatsworth.com/industrial-enclosures

US & Canada

+1-800-834-4969
 Toronto, Ontario, Canada
 +905-850-7770
chatsworth.com
techsupport@chatsworth.com

Latin America

+52-55-5203-7525
 Toll Free within Mexico
 01-800-01-7592
chatsworth.com.co

Europe

+44-1628-524-834
chatsworthproducts.co.uk

Middle East & Africa

Dubai, UAE
 +971-4-2602125
chatsworth.ae

Asia Pacific

+86 21 6880-0266
chatsworth.com.cn



CHATSWORTH
 PRODUCTS