

# Installation Instructions

## EF-Series EuroFrame™ Gen 2 Cable Lashing Bracket

### Safety Information



**WARNING:** Improper use of this product may lead to serious injury. Read and understand all instructions for proper installation and use of this product.

### Intended Use

Install rack only in a restricted service environment, such as a data center. Use indoors only, in environmentally controlled areas; do not use outdoors, in harsh environments or in air-handling spaces. Use rack for computer equipment, including servers and peripherals. Allow only qualified service personnel to use this rack.

### Included Hardware

4 each M4 x 6mm  
Phillips head screw

### Tools Required

Phillips screwdriver

### Installation Instructions

The Cable Lashing Bracket mounts to the accessory holes on the inside of the cabinet's slides. See Figure 1.

1. Vertically hang the brackets on the cabinet's slides using the end hook and align with mounting holes.
2. Fasten the Cable Lashing Bracket using M5X8mm screws to the lower accessory holes on the top slide and upper accessory holes on the bottom slide.
3. Torque screws to 18 in-lbs [200 N-CM].

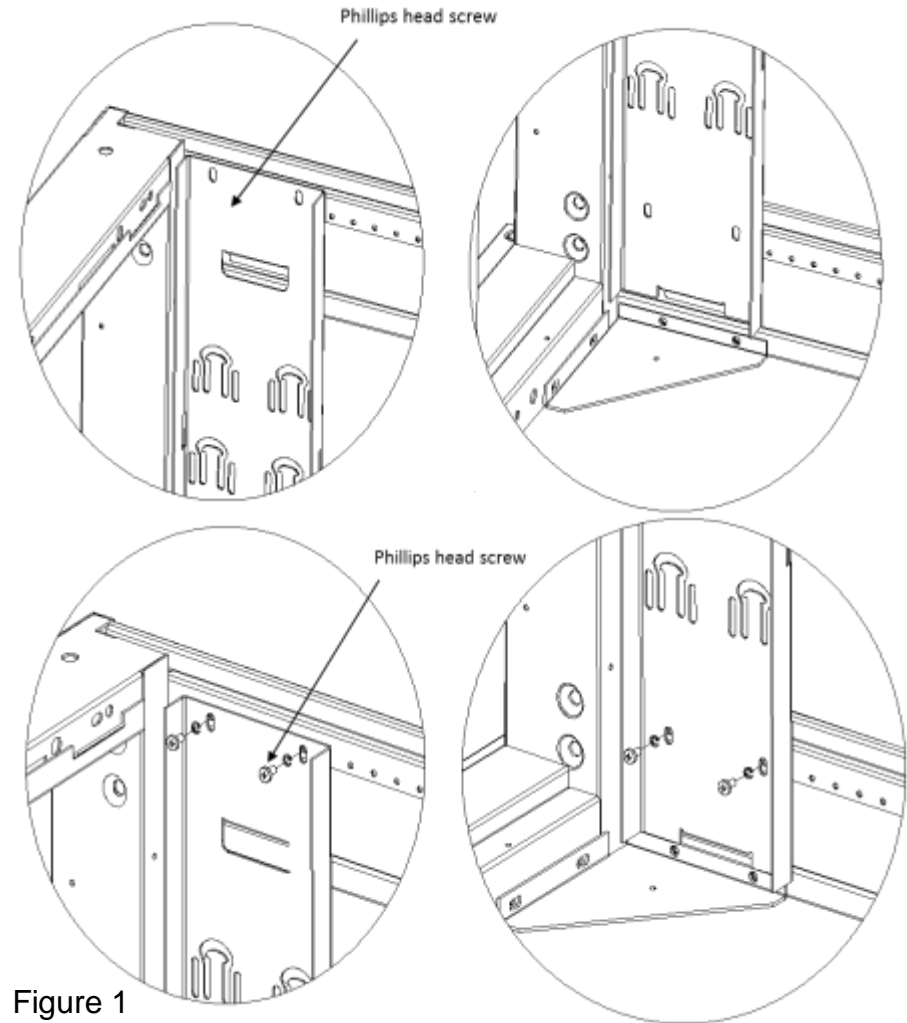


Figure 1