

Service Parts for EF-Series EuroFrame™ Gen 2 Cabinet System

SERVICE PARTS:

Replace cabinet components, or upgrade new applications using the following service parts. These are available as replacement parts or to add additional versatility to meet application requirements.

Square-Punched Equipment Mounting Rails

Kit includes one pair of 19" EIA square-punched equipment mounting rails and installation hardware.

- Punched with the industry-standard EIA/ECA-310-E Universal hole pattern with 44.45 mm (1.75"H) rack-mount spaces/units (U), which supports most rack-mount equipment
- Each U is marked and numbered on the rails, so you can quickly locate equipment
- Square-punched attachment points allow mounting hardware (cage nuts) with different threads at each U, so you can change mounting hardware to match equipment mounting requirements
- All rails have attachment points for accessory snap-on, plastic cable D-rings (Cable Ring Kits) to create a separate vertical pathway for managing cables
- The 800 mm wide models have cable pass-through ports
- Select Equipment Mounting Rails to match cabinet width



Part Number Cabinet Width		Description	Shipping Weight kg (lb)
600 mm	800 mm		
68325-X00	68326-X00	For 42U Cabinets	12.7 (28)
68325-X01	68326-X01	For 45U Cabinets	13.6 (30)
68325-X02	68326-X02	For 47U Cabinets	13.6 (30)

X=Color: 7=Black; E=Glacier White. Shipping Weights are for 800 mm part number.


Side Panels

Includes two half-height interlocking solid side panels to cover one side of the cabinet. The side panel has a single recessed lock located at the top center of the panel.

- Select to match the depth of the cabinet

Part Number Cabinet Height		Description	Shipping Weight kg (lb)
600 mm	800 mm		
68330-X00	68300-X04	For 829 mm (32.6"D) Cabinets	14.9 (33)
68300-X01	68300-X05	For 1029 mm (40.5"D) Cabinets	17.4 (38)
68300-X03	68300-X07	For 1229 mm (48.4"D) Cabinets	20.0 (44)

X=Color: 7=Black; E=Glacier White.

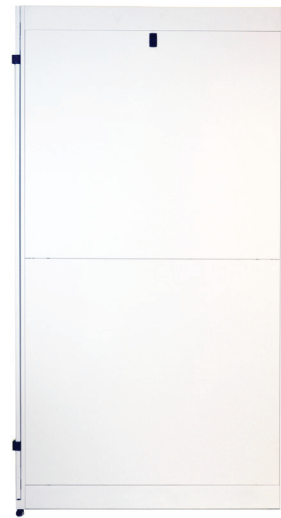

Transport Caster Kit

Includes four transport casters for moving an empty cabinet. One Transport Caster Kit is included with each EF-Series EuroFrame Gen 2 Cabinet.

Part Number	Description	Shipping Weight kg (lb)
68313-E01	Transport Caster Kit, Glacier White	3.3 (7)



Availability: Europe

US & Canada

+1-800-834-4969
Toronto, Ontario, Canada
+905-850-7770
chatsworth.com
techsupport@chatsworth.com

Latin America

+52-55-5203-7525
Toll Free within Mexico
01-800-01-7592
chatsworth.com.co

Europe

+44-1628-524-834
chatsworth.com

Middle East & Africa

Dubai, UAE
+971-4-2602125
chatsworth.ae

Asia Pacific

+86 21 6880-0266
chatsworth.com.cn



Service Parts for EF-Series EuroFrame™ Gen 2 Cabinet System

Single Perforated Metal Front Door

Includes one perforated metal front door with hinges, a swing handle, a single-point latch and keyed lock.

- Select to match the width of the cabinet

Part Number		Description	Shipping Weight kg (lb)
600 mm	800 mm		
68340-X00	68340-X06	For 42U Cabinets	19.9 (44)
68340-X01	68340-X07	For 45U Cabinets	20.5 (45)
68340-X02	68340-X08	For 47U Cabinets	20.5 (45)

X=Color: 7=Black; E=Glacier White. Shipping Weights are for 800 mm part number.



Double Perforated Metal Rear Door

Includes one double perforated metal (vertically split) rear door with hinges, a swing handle, a two-point latch and keyed lock.

- Select to match the width of the cabinet

Part Number		Description	Shipping Weight kg (lb)
600 mm	800 mm		
68350-X00	68350-X06	For 42U Cabinets	20.0 (44)
68350-X01	68350-X07	For 45U Cabinets	20.8 (46)
68350-X02	68350-X08	For 47U Cabinets	20.8 (46)

X=Color: 7=Black; E=Glacier White. Shipping Weights are for 800 mm part number.



Top Panel

Includes one solid top panel with four brush-covered cable openings (one per corner).

- Dual spring button attachment to frame allows tool-less installation and removal
- Includes four rectangular 99 mm x 226 mm (3.9"W x 8.9"D), brush-covered cable openings (one per corner)
- Use accessory Cable Port Cover Kit

Part Number		Description	Shipping Weight kg (lb)
600 mm	800 mm		
68380-X01	68380-X09	For 829 mm (32.6"D) Cabinets	11.2 (25)
68380-X02	68680-X10	For 1029 mm (40.5"D) Cabinets	12.2 (27)
68380-X03	68380-X11	For 1229 mm (48.4"D) Cabinets	13.1 (29)

X=Color: 7=Black; E=Glacier White. Shipping Weights are for 800 mm part number.



Availability: Europe



CHATSWORTH
PRODUCTS

techsupport@chatsworth.com

While every effort has been made to ensure the accuracy of all information, CPI does not accept liability for any errors or omissions and reserves the right to change information and descriptions of listed services and products.

©2017 Chatsworth Products, Inc. All rights reserved. Chatsworth Products, Clik-Nut, CPI, CPI Passive Cooling, CUBE-IT PLUS, eConnect, Evolution, GlobalFrame, MegaFrame, OnTrac, QuadraRack, RMR, Saf-T-Grip, Seismic Frame, SlimFrame, TeraFrame and Velocity are federally registered trademarks of Chatsworth Products, Inc. EuroFrame, Motive, Secure Array and Simply Efficient are trademarks of Chatsworth Products, Inc. All other trademarks belong to their respective companies. 10/17 EF2 Service Part Cut.en-GB