

# VELOCITY® STANDARD PACK

## KEY FEATURES

- Velocity® Standard Pack includes a 45U x 19" EIA Standard Rack, a single or double-sided Velocity vertical cable manager and concrete floor installation hardware.
- Numbered rack-mount spaces on Standard Rack are printed on the equipment mounting channels, providing the installer an easy way of positioning equipment in planned spaces.
- Includes bonded assembly and a built-in attachment point for a ground (earthing) connection on Standard Rack for easy attachment to the Telecommunications Ground.
- Cable openings in Velocity vertical cable managers align with rack-mount units on the rack, allowing cables to exit by rack-mount units.
- Cable openings have rounded edges to protect cable and will not deform or break.
- Cover snaps on and opens to the right or left for easy access to cables during moves, adds or changes.

## APPLICATIONS

- Use Velocity Standard Pack in small to medium size facilities in equipment rooms to support the security, voice and network equipment.
- Velocity Standard Pack is a cable management system that provides physical protection and pathway support for premise cable and patch cords while promoting loose bundling of cables.


## RELATED ACCESSORIES

- Standard Racks
- Velocity® Cable Management
- Fiber Management Spools
- Cable Runway Radius Drops
- Saf-T-Grip® Straps




**Standard Rack**

Rack-mount units (U) are printed on the rack

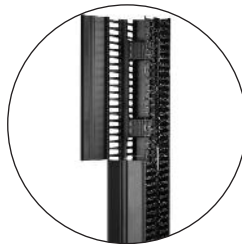

**Velocity® Cable Management**

Side cable openings align with rack-mount units on the rack

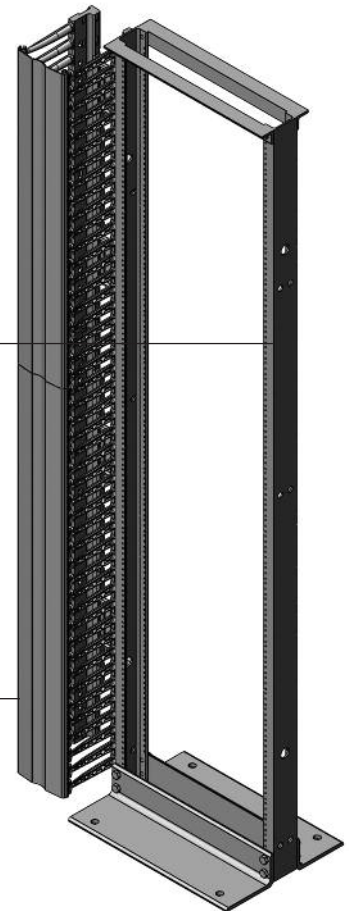

The Velocity® Standard Pack is an easy to use solution for managing equipment and cabling at the cross connect. It includes one CPI Standard Rack, a concrete floor installation kit and a single or double-sided Velocity Vertical Cable Manager packaged in a single carton.

CPI's Standard Rack supports patch panels, fiber enclosures and network switches, is UL® and cUL Listed, has integrated grounding and is easy to set up and use. Velocity Cable Managers are single and double-sided cable management troughs that control cable feed with a patented system of large cable openings that align with each equipment-mounting space on the rack. The snap-on cover provides easy access to cables and a clean, finished look for a complete cable management system.

The Velocity Standard Pack is offered in four variations with the single-sided or double-sided cable manager in either 3.6"W (91 mm) or 6"W (152 mm) versions. Cable managers can be mounted on either side of the Standard Rack.

See reverse for product specifications and ordering information. Please contact CPI Technical Support for configuration assistance.

**SPECIFICATIONS**

**Standard Rack**

- UL and cUL Listed, File E140851
- 1000 lb (453.6 kg) capacity
- 19" wide two-post rack
- EIA/ECA-310-E, Universal hole spacing
- 45U spaces
- Threaded, front and rear, #12-24
- Bonded assembly, integrated ground studs

• Footprint:  
20.3"W x 15"D (516 mm x 381 mm)

• Height:  
7' (2.1 m); 84" (2133 mm)

• Material:  
Aluminum

• Finish:  
Painted Black

• Weight:  
31 lb (14.1 kg)

**Velocity® Cable Management**

- Single or double-sided trough
- Snap on, 2 piece cover
- 1U high cable openings
- Available in two widths

• Estimated Cable Capacities:  
See Cable Fill table at  
[www.chatsworth.com/cablefill](http://www.chatsworth.com/cablefill)

• Footprints:  
Single-Sided:  
3.65"W x 9.7"D (91 mm x 246 mm)  
6.00"W x 9.8"D (152 mm x 249 mm)


Double-Sided:  
3.65"W x 16.4"D (91 mm x 417 mm)  
6.00"W x 16.6"D (152 mm x 422 mm)

• Height:  
80.5" (2045 mm)

• Materials:  
Steel  
UL 94V-0 compliant plastic

• Finish:  
Black finish

**DIMENSIONS**

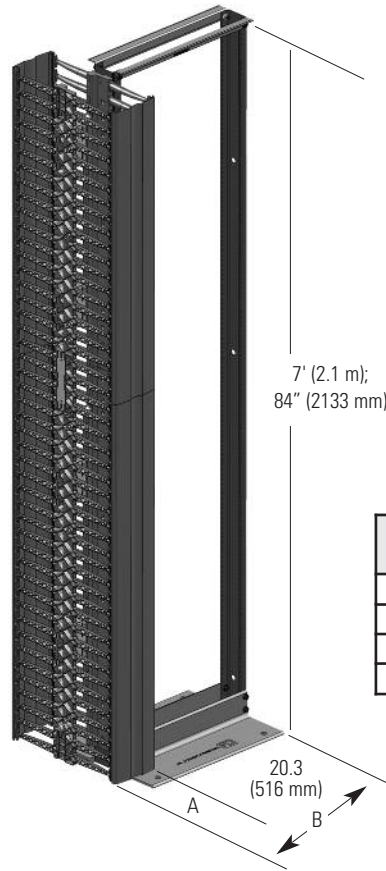

Part Number	Dimensions - in (mm)	
	A	B
57011-703	3.6" (91)	23.9" (607)
57012-703	3.6" (91)	23.9" (607)
57013-703	6.0" (152)	26.3" (668)
57014-703	6.0" (152)	26.3" (668)

**ORDERING INFORMATION**

Part Number	Description	Shipping Weight lb (kg)
57011-703	(1) Standard Rack, 45U x 19" EIA, UL Listed, Black (1) Velocity® Single-Sided Vertical Cable Manager, 3.6"W (91 mm), Black (1) Rack Installation Kit for concrete floor, 1/2" hardware, Zinc	47 (21.3)
57012-703	(1) Standard Rack, 45U x 19" EIA, UL Listed, Black (1) Velocity® Double-Sided Vertical Cable Manager, 3.6"W (91 mm), Black (1) Rack Installation Kit for concrete floor, 1/2" hardware, Zinc	60 (27.2)
57013-703	(1) Standard Rack, 45U x 19" EIA, UL Listed, Black (1) Velocity® Single-Sided Vertical Cable Manager, 6"W (152 mm), Black (1) Rack Installation Kit for concrete floor, 1/2" hardware, Zinc	50 (22.7)
57014-703	(1) Standard Rack, 45U x 19" EIA, UL Listed, Black (1) Velocity® Double-Sided Vertical Cable Manager, 6"W (152 mm), Black (1) Rack Installation Kit for concrete floor, 1/2" hardware, Zinc	68 (30.8)

*Note: Standard Rack available in additional finishes.*

