

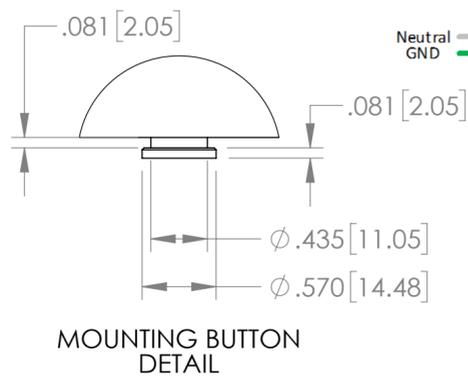


| Technical Specs: | |
|---|--|
| Input Ratings | |
| Nominal Voltage (VAC) | 220-240V/380-415V 3ph |
| Input Plug / Cord | 5100F6W(IP67) |
| Current Rating | 80A per phase |
| Power Rating (kW) | 57.5 |
| Output Ratings | |
| Nominal Voltage (VAC) | 220-240V |
| Current Rating | 240A |
| Outlet Rating | C13/C15 10A max, QuadLock 16A max |
| Max Current per Breaker | 20A Balanced; 24A Unbalanced |
| Outlet Combination | |
| Load Segment | Refer to Simplified Wire Schematic |
| PDU Total | (12) C13/C15, (24) QuadLock C13/C15/C19/C21 |
| Branch Circuit Protection | |
| Surge Suppression | (C) 30A, 5kAIC, Single Pole |
| Features: | |
| Branch Monitoring | Not Supported |
| Outlet Monitoring | Not Supported |
| Monitoring Accuracy | Not Supported |
| Ethernet Port | Not Supported |
| Remote Monitoring | Not Supported |
| Remote Control | GUI, SNMP v1-3, RS232, RESTful API, CLI, Power IQ, Redfish |
| IP Consolidation | Not Supported |
| USB Ports (2) | Not Supported |
| Controller Module | Not Supported |
| Auxiliary Port (2) | Not Supported |
| Cord Retention | Locking Receptacles |
| Mounting System | Multiple tool-less mounting button locations, A and B (see detail) |
| Dimensions & Weights: | |
| Width (In[mm]) | 2.2 [55] |
| Height (In[mm]) | 77.1 [1957.2] |
| Depth (In[mm]) | 3.15 [80] |
| Weight (lbs[kg]) | 22 [10] |
| Regulatory Compliance: | |
| NEMKO Listed to UL/IEC62368-1, CE, RoHS, FCC Part 15 Class A, EN 55022, TAA | |
| Regulatory Part Number: | |
| Black: K11-CY699-F1U-72A White: K11-CY699-F1U-E2A | |
| Environmental Conditions: | |
| Operating Temperature | 32°F to 149°F (0°C to 65°C) below 16A/breaker 32°F to 112°F (0°C to 50°C) 16A-24A/breaker |
| Operating Rel Humidity | 5-95% |
| Operating Elevation | 0-10000 ft (0-3000m) |
| Storage Temperature | -13°F to 149°F (-25°C to 65°C) |
| Storage Rel Humidity | 5-95% |
| Storage Elevation | 0-50000ft (0-15000m) |
| Hardware Included: | |
| (2) tool-less pre-installed mounting buttons (1) ground kit cable | |
| Warranty | |
| 3 yrs. Standard, 2 add'l yrs. Opt'l | |
| Optional Accessories: | |
| Not Supported | |

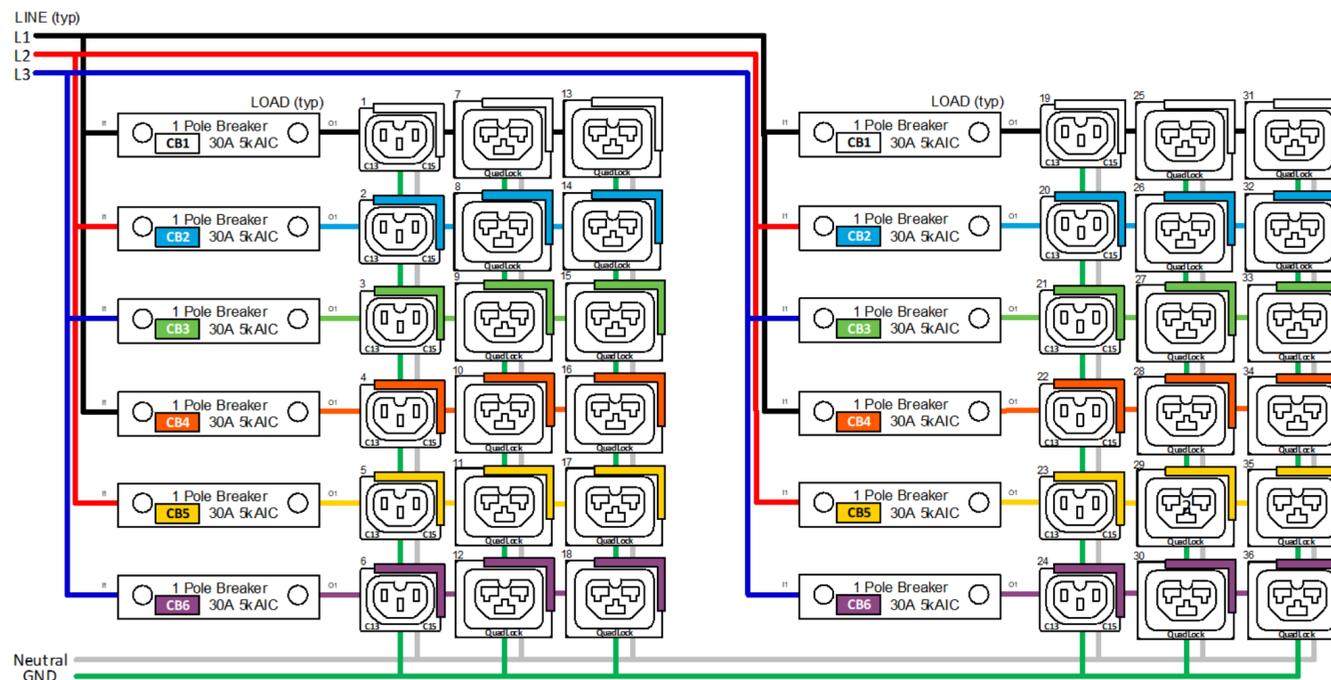

INPUT PLUG DETAIL
IEC 60309 6H
100A / 4P5W

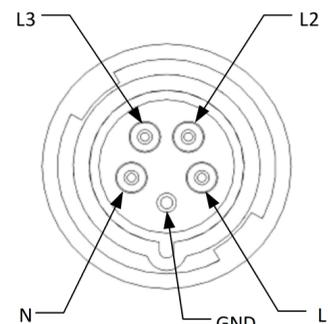

- Notes:
- All Dimension are in inches [millimeters] unless otherwise specified
 - Installation must conform with all related national and local codes
 - All Bracket kits are sold separately. Toolless mounting buttons are included for installation in CPI cabinets.
 - For more information, please contact Tech Support at techsupport@chatsworth.com

©2019 Chatsworth Products, Inc.
All rights reserved.

All products quoted are subject to availability based on manufacturing capacity and shipping dates should be considered estimates only.

While every effort has been made to ensure the accuracy of all information, CPI does not accept liability for any errors or omissions and reserves the right to change information and descriptions of listed services and products.



eConnect Vertical PDU, Basic,
IEC 60309 100A 3P+N+E, 10ft (3m),
220-240/380-415V Three Phase Input, 100A,
(12) C13/C15 (24) QuadLock C13/C15/C19/C21
Outlets, 220-240V Output



E0-1193W-X

SHEET 1 OF 1

ISS