


1047-LPDOME & 1047-LTDOME

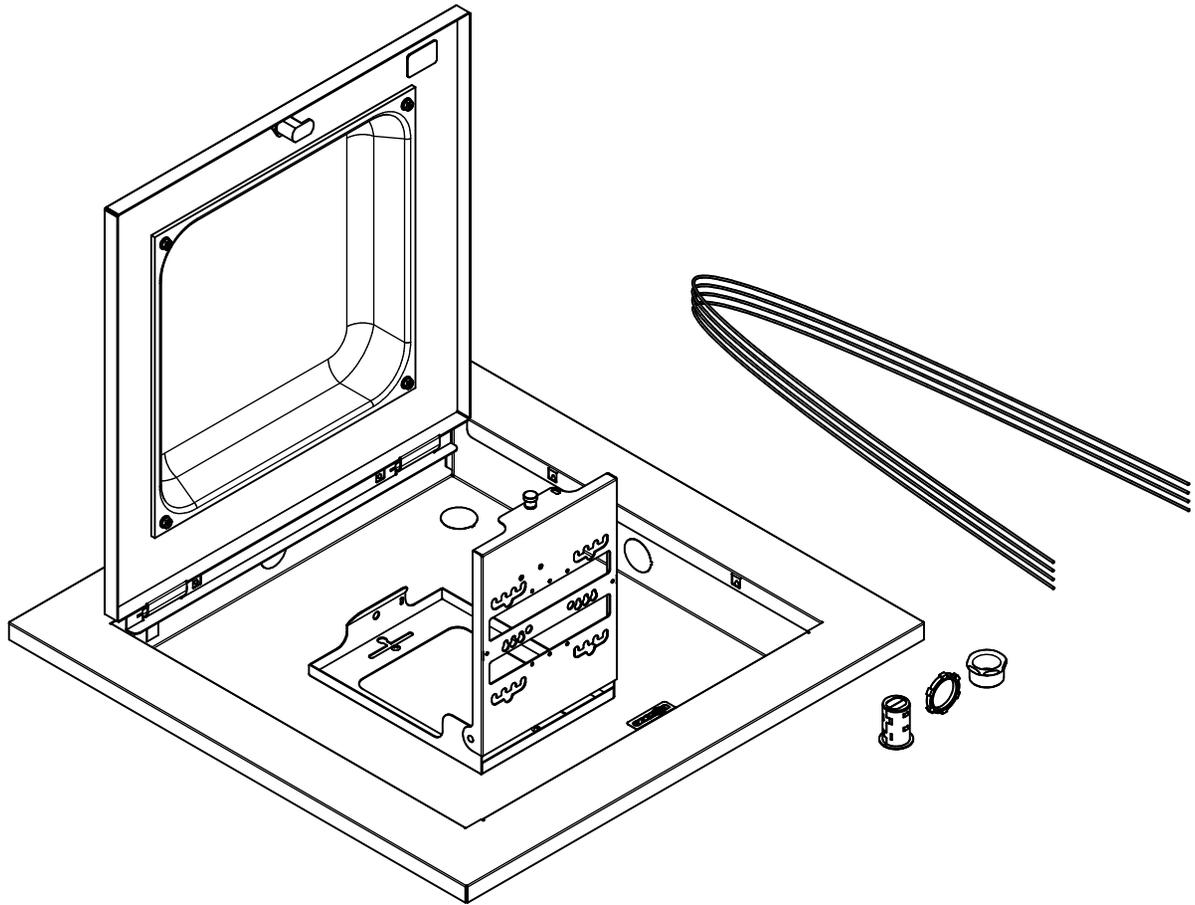

NOTES:

- Weight: 10.5 lbs. (4.8 kg.)
- Material: 16 Ga. Aluminum Backbox
18 Ga. White Powder Coated Steel Door
18 Ga. White Powder Coated Steel Flange
UL94-5VA Dome

Includes:

- (1) Enclosure and Interchangeable Door
- (1) Dual Cable Egress Firestop Grommet
- (1) 1 in. Trade Size Conduit Connector
- (4) Hanger Wires
- (2) Keys for Lock
- Access Point Attachment Hardware





UL Listed - File Number E348543

HCAI Approved - OPM-0110-22

DRAWN	3/5/2025	Oberon, Inc. - 1315 S. Allen St. - State College, PA 16801		
CHECKED	9/9/2024	TITLE		
QA		CUT-OB1047		
MFG	9/9/2024	SIZE	DWG NO	REV
RLC		C	1047-XXXX	
APPROVED	9/9/2024	SCALE	SHEET 1 OF 8	
RLC				
TOLERANCE:	.0 = +/- .030			
	.00 = +/- .015			
	.000 = +/- .005			

1047-LPDOME & 1047-LTDOME

D
C
B
A

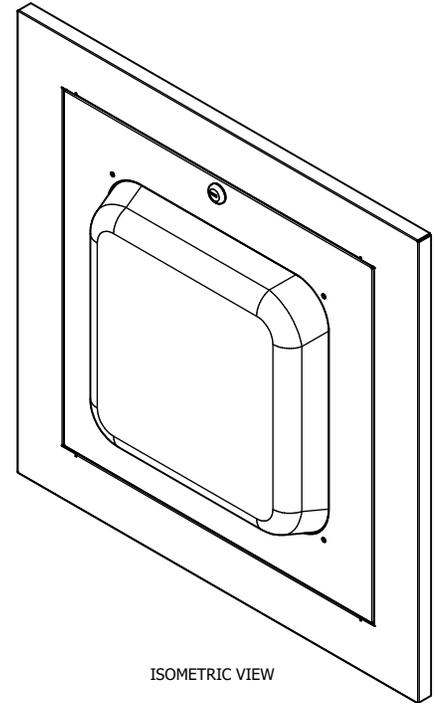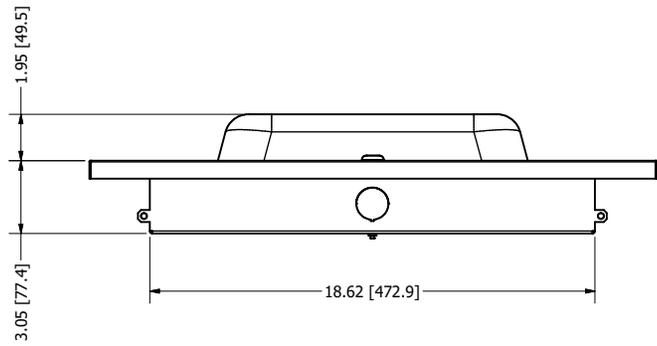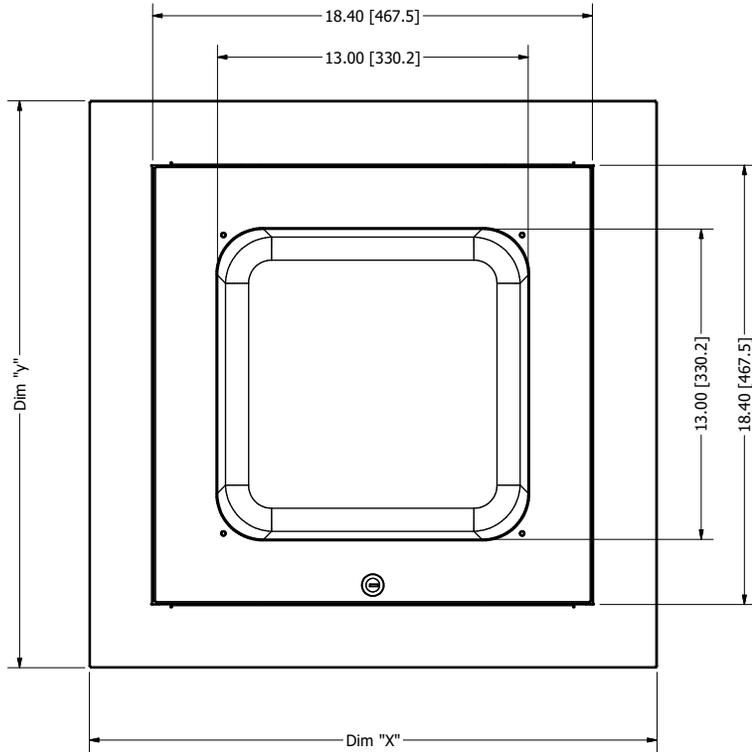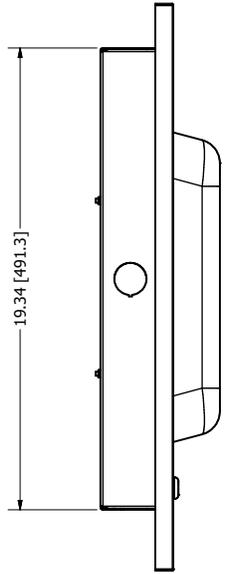

ISOMETRIC VIEW

FLANGE DIMENSIONS		
Flange Style	Dim X	Dim Y
1047-XXXX (U.S. Size)	23.75"	23.75"
1047-XXXX-T (U.S. Size)	23.75"	23.75"
1047-XXXX-600MM (Metric Size)	594 MM	594 MM

DRAWN RLC	3/5/2025	Oberon, Inc. - 1315 S. Allen St. - State College, PA 16801		
CHECKED RLC	9/9/2024	TITLE		
QA		CUT-OB1047		
MFG RLC	9/9/2024	SIZE C	DWG NO 1047-XXXX	REV
APPROVED RLC	9/9/2024	SCALE	SHEET 2 OF 8	
TOLERANCE:	.0 = +/- .030 .00 = +/- .015 .000 = +/- .005			

D
C
B
A


4
3
2
1

4
3
2
1

4
3
2
1

4
3
2
1

1047-LPDOME & 1047-LTDOME MOUNTING LEGEND

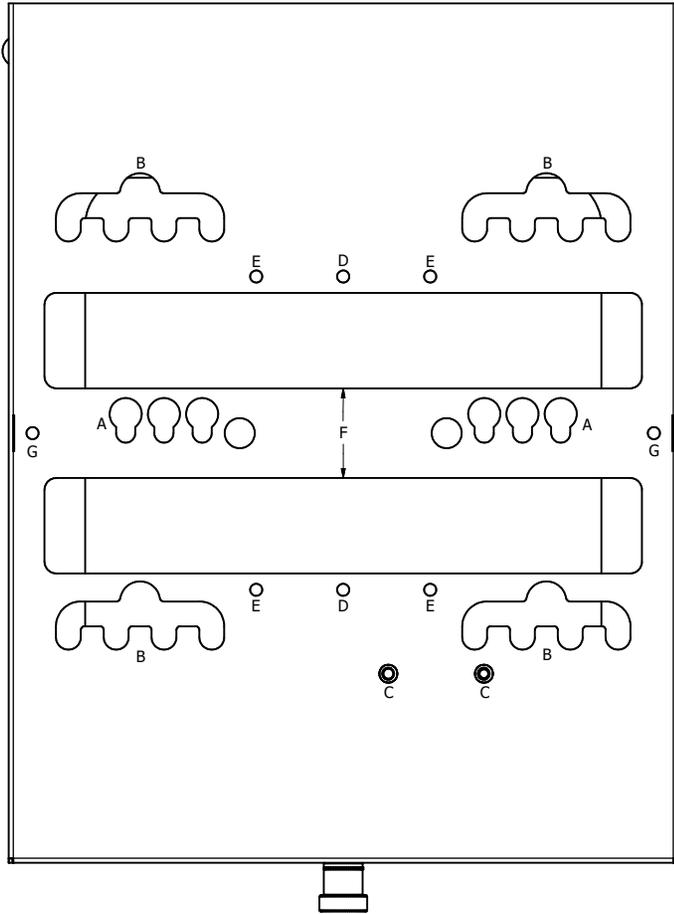


Mounting Legend:

- A - Aruba Direct Mount
- B - Cisco Direct Mount
- C - Cisco Adjustable Set Screws
- D - Single Gang Outlet Box
- E - Double Gang Outlet Box
- F - Direct T-Bar Mount
- G - Oberon T-Bar Accessory

DRAWN RLC	3/5/2025	Oberon, Inc. - 1315 S. Allen St. - State College, PA 16801		
CHECKED RLC	9/9/2024	TITLE		
QA		CUT-OB1047		
MFG RLC	9/9/2024	SIZE C	DWG NO 1047-XXXX	REV
APPROVED RLC	9/9/2024	SCALE	SHEET 3 OF 8	
TOLERANCE:	.0 = +/- .030 .00 = +/- .015 .000 = +/- .005			

1047 WITH AP FACED DOOR

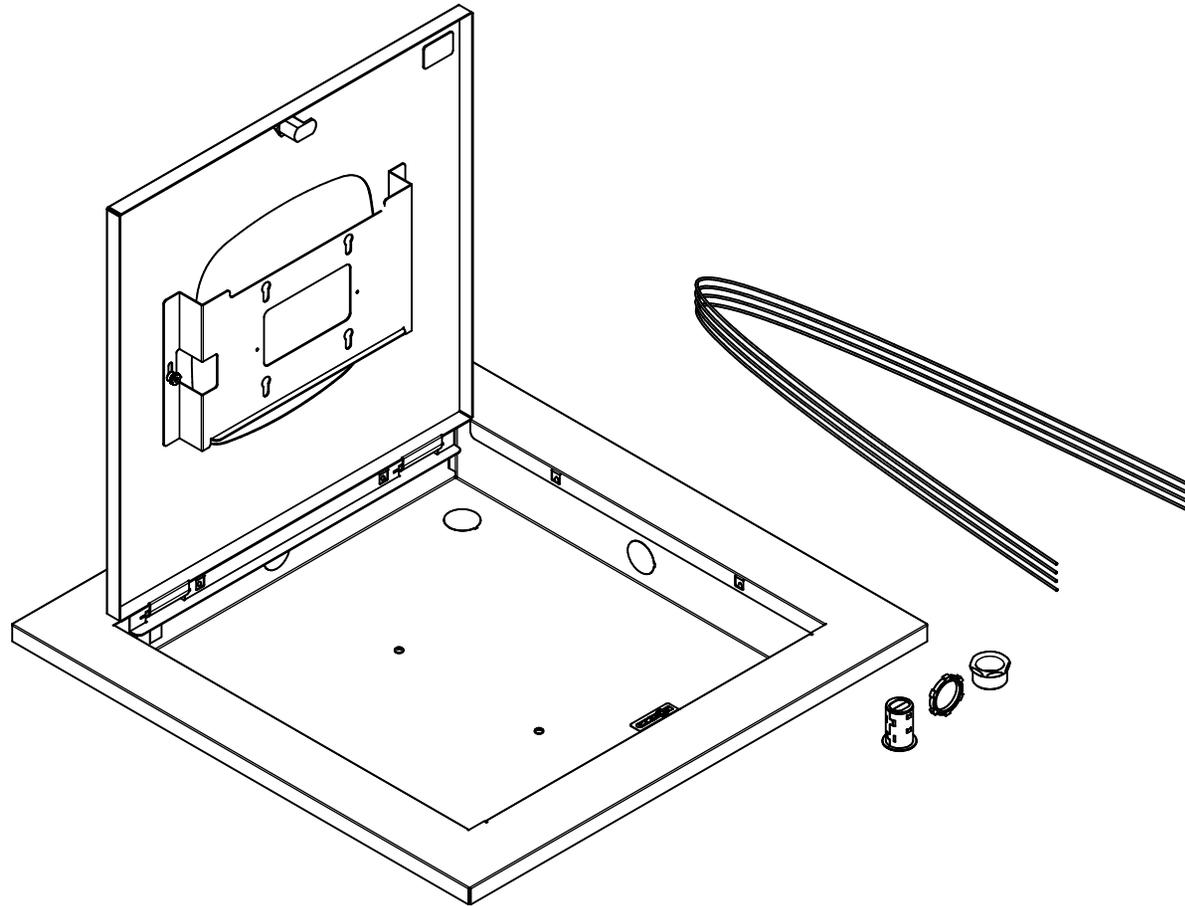

NOTES:

- Weight: 10.5 lbs. (4.8 kg.)
- Material: 16 Ga. Aluminum Backbox
18 Ga. White Powder Coated Steel Door
18 Ga. White Powder Coated Steel Flange

Includes:


- (1) Enclosure and Interchangeable Door
- (1) Dual Cable Egress Firestop Grommet
- (1) 1 in. Trade Size Conduit Connector
- (4) Hanger Wires
- (2) Keys for Lock
- Access Point Attachment Hardware

UL Listed - File Number E348543

HCAI Approved - OPM-0110-22

DRAWN	3/5/2025	Oberon, Inc. - 1315 S. Allen St. - State College, PA 16801		
CHECKED	9/9/2024	TITLE		
QA		CUT-OB1047		
MFG	9/9/2024	SIZE	DWG NO	REV
RLC		C	1047-XXXX	
APPROVED	9/9/2024	SCALE	SHEET 4 OF 8	
RLC				
TOLERANCE:	.0 = +/- .030 .00 = +/- .015 .000 = +/- .005			

1047 WITH ANTENNA MOUNTING DOOR

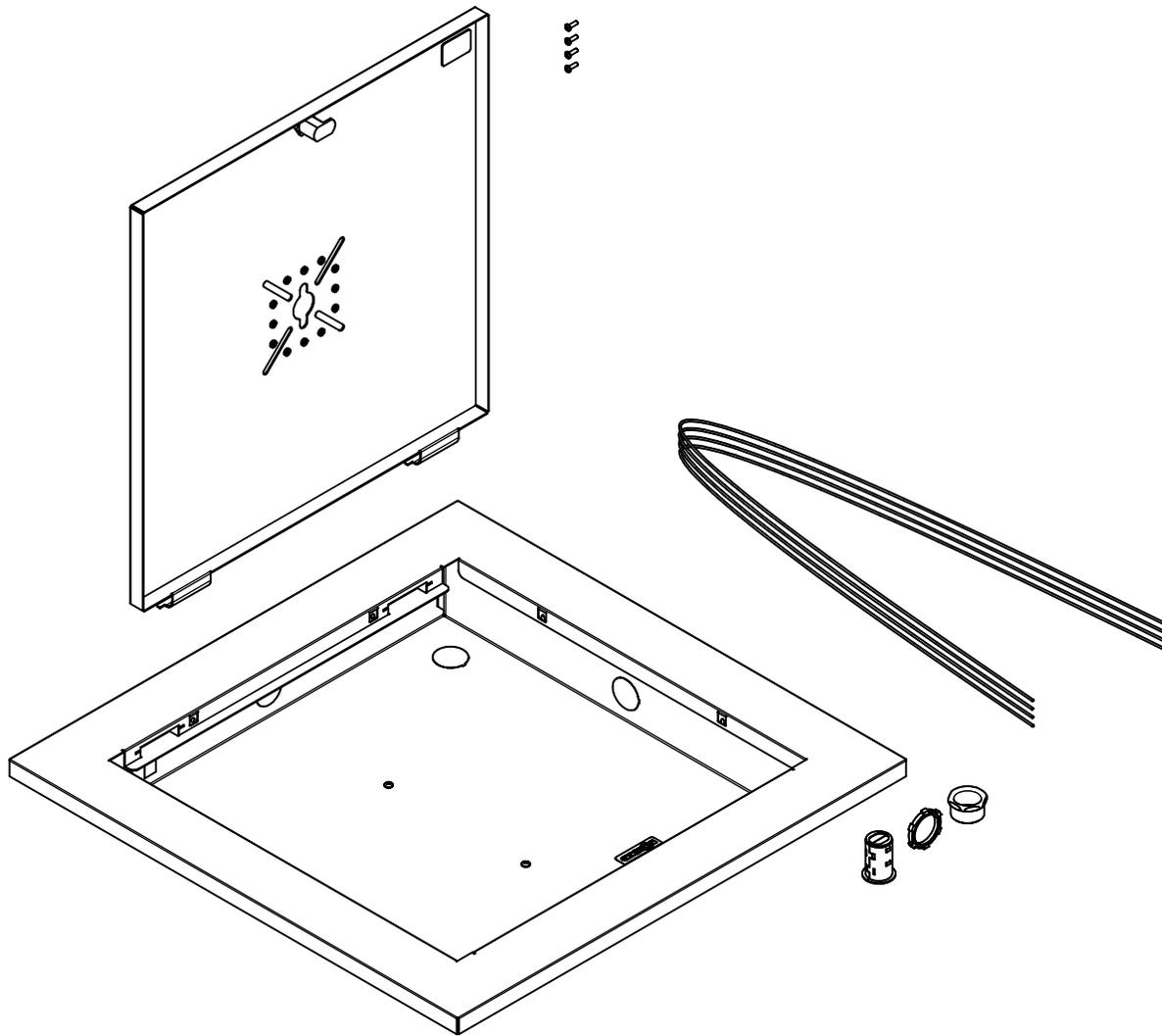

NOTES:

- Weight: 10.5 lbs. (4.8 kg.)
- Material: 16 Ga. Aluminum Backbox
18 Ga. White Powder Coated Steel Door
18 Ga. White Powder Coated Steel Flange





Includes:

- (1) Enclosure and Interchangeable Door
- (1) Dual Cable Egress Firestop Grommet
- (1) 1 in. Trade Size Conduit Connector
- (4) Hanger Wires
- (2) Keys for Lock
- Antenna Mounting Door Hardware

UL Listed - File Number E348543
HCAI Approved - OPM-0110-22

DRAWN	RLC	3/5/2025	Oberon, Inc. - 1315 S. Allen St. - State College, PA 16801		
CHECKED	RLC	9/9/2024	TITLE		
QA			CUT-OB1047		
MFG	RLC	9/9/2024	SIZE	DWG NO	REV
APPROVED	RLC	9/9/2024	C	1047-XXXX	
TOLERANCE:		.0 = +/- .030 .00 = +/- .015 .000 = +/- .005	SCALE	SHEET 6 OF 8	

1047 WITH ANTENNA MOUNTING DOOR

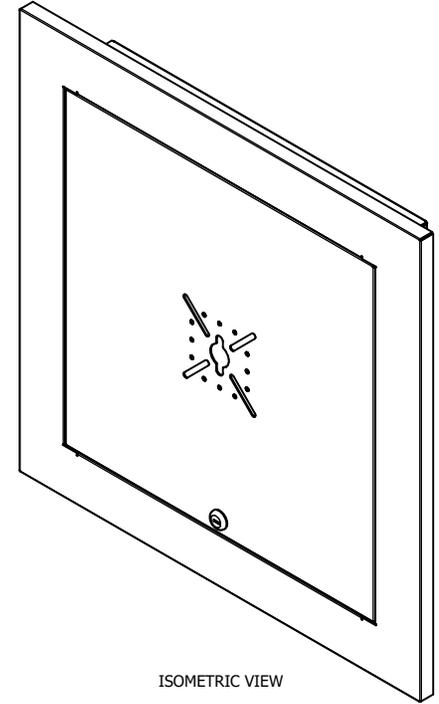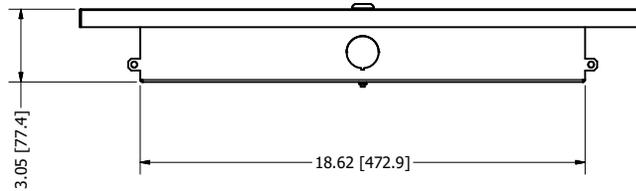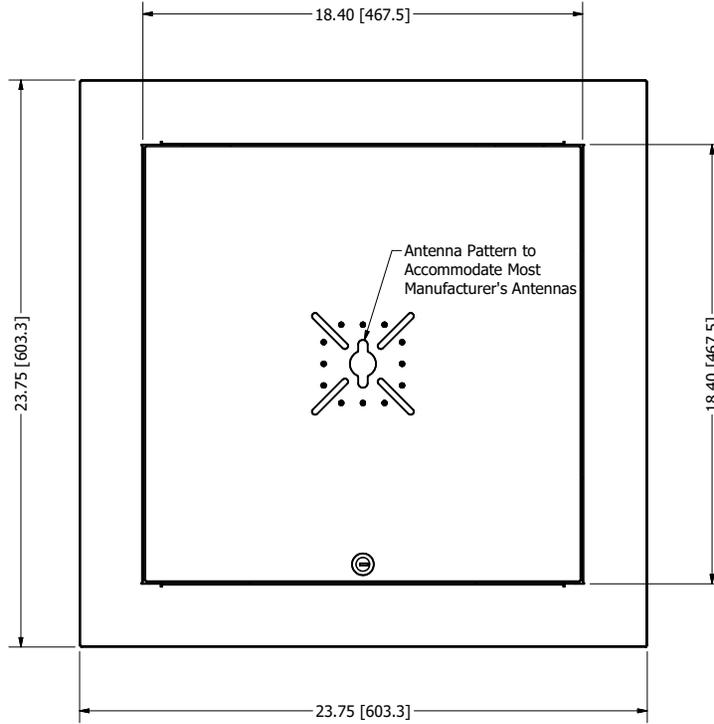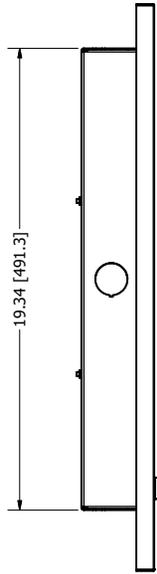

FLANGE DIMENSIONS		
Flange Style	Dim X	Dim Y
1047-XXXX (U.S. Size)	23.75"	23.75"
1047-XXXX-T (U.S. Size)	23.75"	23.75"
1047-XXXX-600MM (Metric Size)	594 MM	594 MM

DRAWN RLC	3/5/2025	Oberon, Inc. - 1315 S. Allen St. - State College, PA 16801		
CHECKED RLC	9/9/2024	TITLE		
QA		CUT-OB1047		
MFG RLC	9/9/2024	SIZE C	DWG NO 1047-XXXX	REV
APPROVED RLC	9/9/2024	SCALE	SHEET 7 OF 8	
TOLERANCE:	.0 = +/- .030 .00 = +/- .015 .000 = +/- .005			

Please specify configuration when ordering:

1047 - _____ - _____ - _____ - _____


ENCLOSURE - AP DOOR - FLANGE STYLE - TILE SIZE
 STYLE (See Configurations) (-T for Tegular Flange, leave blank for lay-in) (-600MM for European metric ceiling grid, leave blank for 24" ceiling grid)

Configuration Table


MODEL NUMBER	ENCLOSURE STYLE	AP DOOR	FLANGE STYLE	TILE SIZE	ACCESS POINT	TO ORDER DOOR SEPARATELY - USE DOOR P/N ONLY
1047-ANTMNT	1047	ANTMNT			Antenna Mounting Door	38-47-ANTMNT
1047-ARSC1535	1047	ARSC1535			Aruba APSC35	38-47-ARSC1535
1047-ASAV1500	1047	ARSV1500			Airspan AirVelocity 1500	38-47-ASAV1500
1047-3100	1047	3100			GE Healthcare ApexPro FHAP	38-47-3100
1047-ARAP505	1047	ARAP505			Aruba AP505	38-47-ARAP505
1047-ARAP515	1047	ARAP515			Aruba AP515	38-47-ARAP515
1047-ARAP535	1047	ARAP535			Aruba AP535	38-47-ARAP535
1047-ARAP555	1047	ARAP555			Aruba AP555	38-47-ARAP555
1047-ARAP615	1047	ARAP615			Aruba AP615	38-47-ARAP615
1047-ARAP635	1047	ARAP635			Aruba AP635	38-47-ARAP635
1047-ARAP725	1047	ARAP655			Aruba AP655	38-47-ARAP655
1047-ARAP735	1047	ARAP735			Aruba AP735	38-47-ARAP735
1047-ARAP755	1047	ARAP755			Aruba AP755	38-47-ARAP755
1047-ARSTC330	1047	ARSTC330			Arista C-330	38-47-ARST330
1047-ARSTC360	1047	ARSTC360			Arista C-360	38-47-ARSTC460
1047-ARSTC460	1047	ARSTC460			Arista C-460	38-47-ARSTC360
1047-BLANK	1047	None			Used as a cover / AP not been defined	38-47-BLANK
1047-CCOAP3800	1047	CCOAP3800			Cisco 2800, 3800 Series APs	38-47-CCOAP3800
1047-COAP4800	1047	COAP4800			Cisco 4800 Series APs	38-47-COAP4800
1047-COAP9115	1047	COAP9115			Cisco 9115 Series APs	38-47-COAP9115
1047-COAP9117	1047	COAP9117			Cisco 9117 Series APs	38-47-COAP9117
1047-COAP9120	1047	COAP9120			Cisco 9120 Series APs	38-47-COAP9120
1047-COAP9130	1047	COAP9130			Cisco 9130 Series APs	38-47-COAP9130
1047-COAP9136	1047	COAP9136			Cisco 9136 Series APs	38-47-COAP9136
1047-CW9166	1047	CW9166			Cisco 9166 Series APs	38-47-CW9166
1047-CW9172	1047	CW9172			Cisco 9172 Series APs	38-47-CW9172
1047-CW9176	1047	CW9176			Cisco 9176 Series APs	38-47-CW9176
1047-CW9178	1047	CW9178			Cisco 9178 Series APs	38-47-CW9178
1047-EXT510i	1047	EXT510i			Extreme Networks AP 510i	38-47-EXT510i
1047-EXAP4000	1047	EXAP4000			Extreme Networks AP 4000	38-47-EXAP4000
1047-EXAP5010	1047	EXAP5010			Extreme Networks AP 5010	38-47-EXAP5010
1047-EXAP5020	1047	EXAP5020			Extreme Networks AP 5020	38-47-EXAP5020
1047-LPDOME	1047	LPDOME			General Purpose, Works With Most APs	38-47-LPDOME
1047-LTDOME	1047	LTDOME			General Purpose, Works With Most APs	38-47-LTDOME
1047-MIST43	1047	MIST43			Mist AP 43	38-47-MIST43
1047-JNAP45	1047	JNAP45			Mist AP 45	38-47-JNAP45
1047-JNAP47	1047	JNAP47			Mist AP 47	38-47-JNAP47
1047-JNBT11	1047	JNBT11			Mist BT111	38-47-JNBT11
1047-MR45	1047	MR45			Meraki MR45	38-47-MR45
1047-MR56	1047	MR56			Meraki MR56	38-47-MR56
1047-MR57	1047	MR57			Meraki MR57	38-47-MR57
1047-ND	1047	ND			N/A (No Door Included)	ND

Examples:
 1047-LPDOME Model 1047 with LPDOME door, flange to match flat lay-in tile, flange size for North American ceiling systems
 1047-LPDOME-T Model 1047 with LPDOME door, flange to match tegular ceiling tiles for recessed grid, flange size for North American ceiling systems
 1047-COAP3800-600MM Model 1047 with door for Cisco 3800 Series AP, flange to match flat lay-in tile, European metric sized flange
 1047-ARAP335-T-600MM Model 1047 with door for Aruba AP335, flange to match tegular ceiling tiles for recessed grid, European metric sized flange
 1047-COAP9120-LW Model 1047 with door for Cisco 9120 AP, flange to match flat lay-in tile, flange size for North American ceiling systems, with light-weight back-box

STANDARD "LAY-IN" FLANGE STYLE

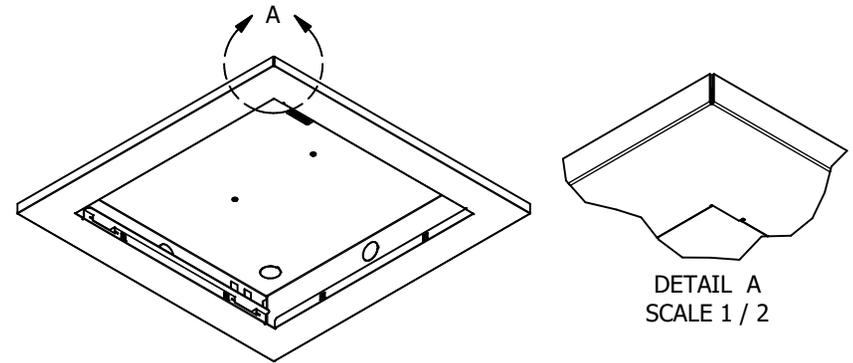

**"-T" TEGULAR FLANGE STYLE
(For Recessed Grid Ceilings)**

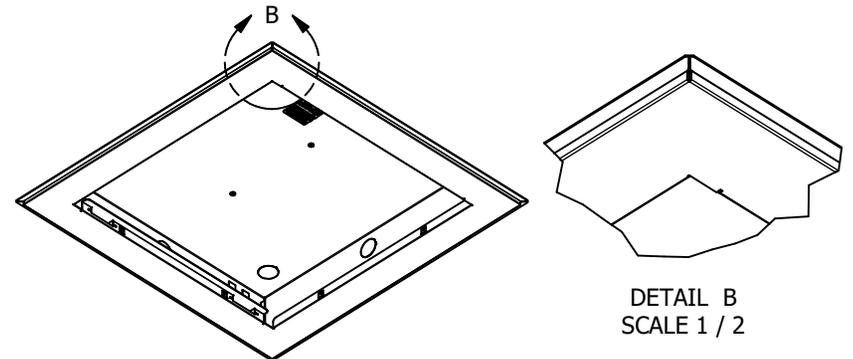

DRAWN	3/5/2025	Oberon, Inc. - 1315 S. Allen St. - State College, PA 16801		
CHECKED	9/9/2024	TITLE		
RLC		CUT-OB1047		
QA				
MFG	9/9/2024	SIZE	DWG NO	REV
RLC		C	1047-XXXX	
APPROVED	9/9/2024	SCALE		
RLC		SHEET 8 OF 8		
TOLERANCE:	.0 = +/- .030 .00 = +/- .015 .000 = +/- .005			