

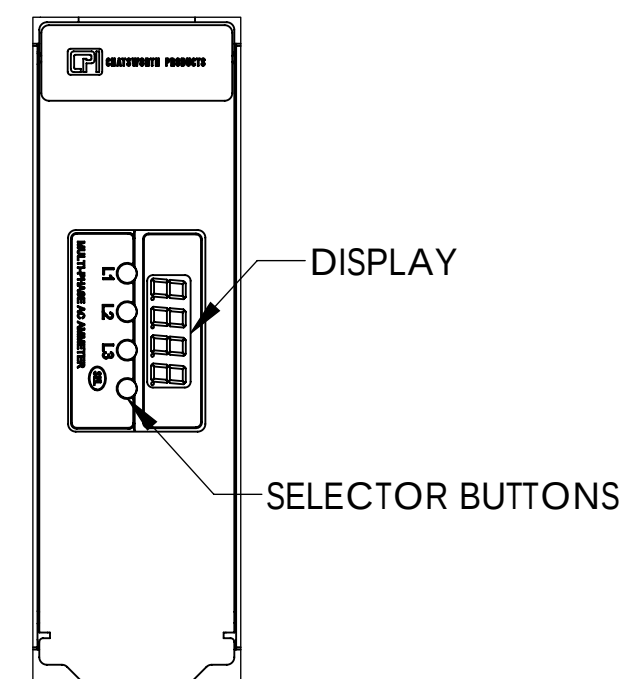


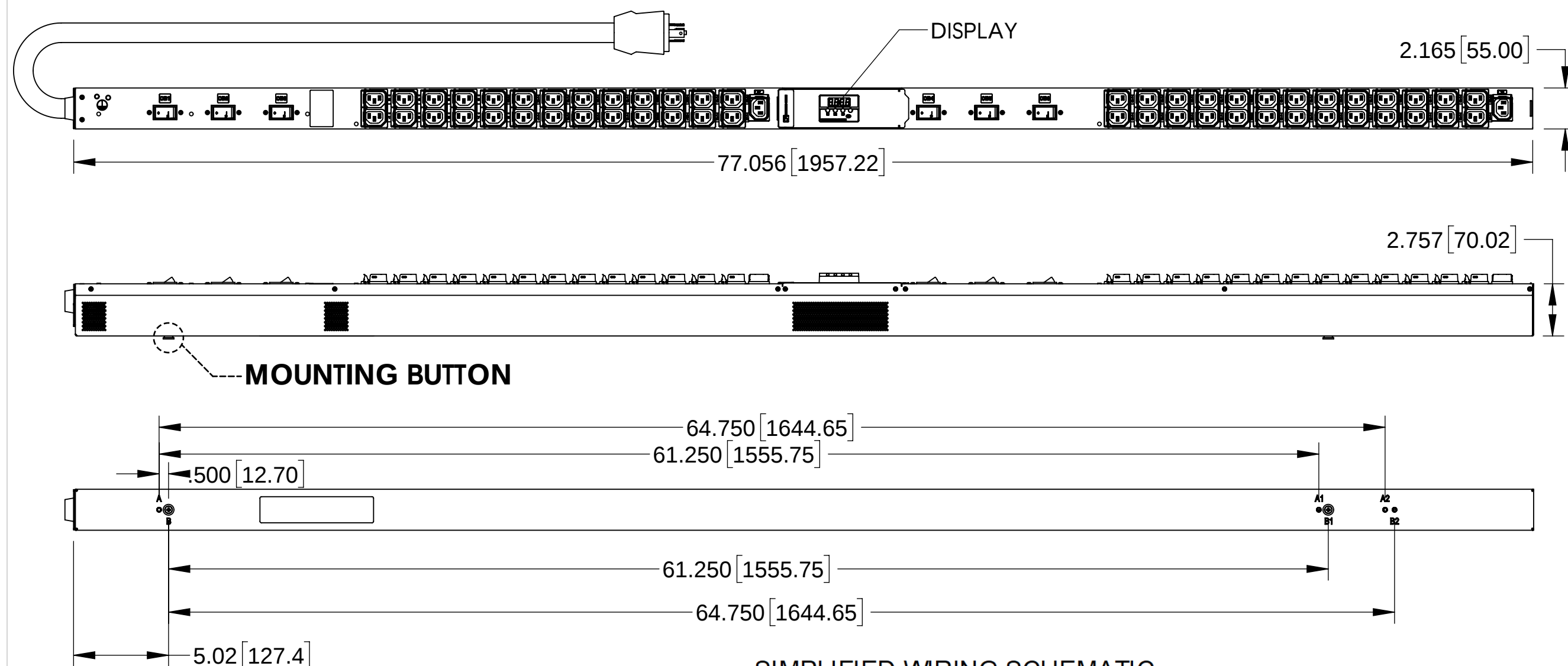


DISPLAY DETAIL

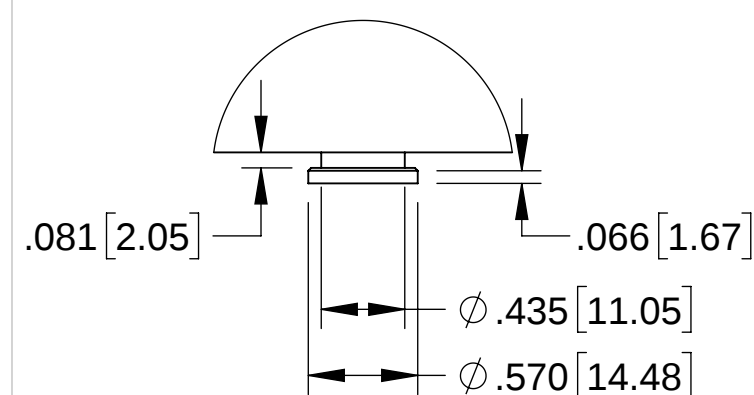


MOUNTING BUTTON  
DETAIL

- Notes:
- 1 All Dimension are in inches [millimeters] unless otherwise specified
  - 2 Installation must conform with all related national and local codes
  - 3 All Bracket kits are sold separately. Toolless mounting buttons are included for installation in CPI cabinets.
  - 4 For more information, please contact Tech Support at [techsupport@chatsworth.com](mailto:techsupport@chatsworth.com)

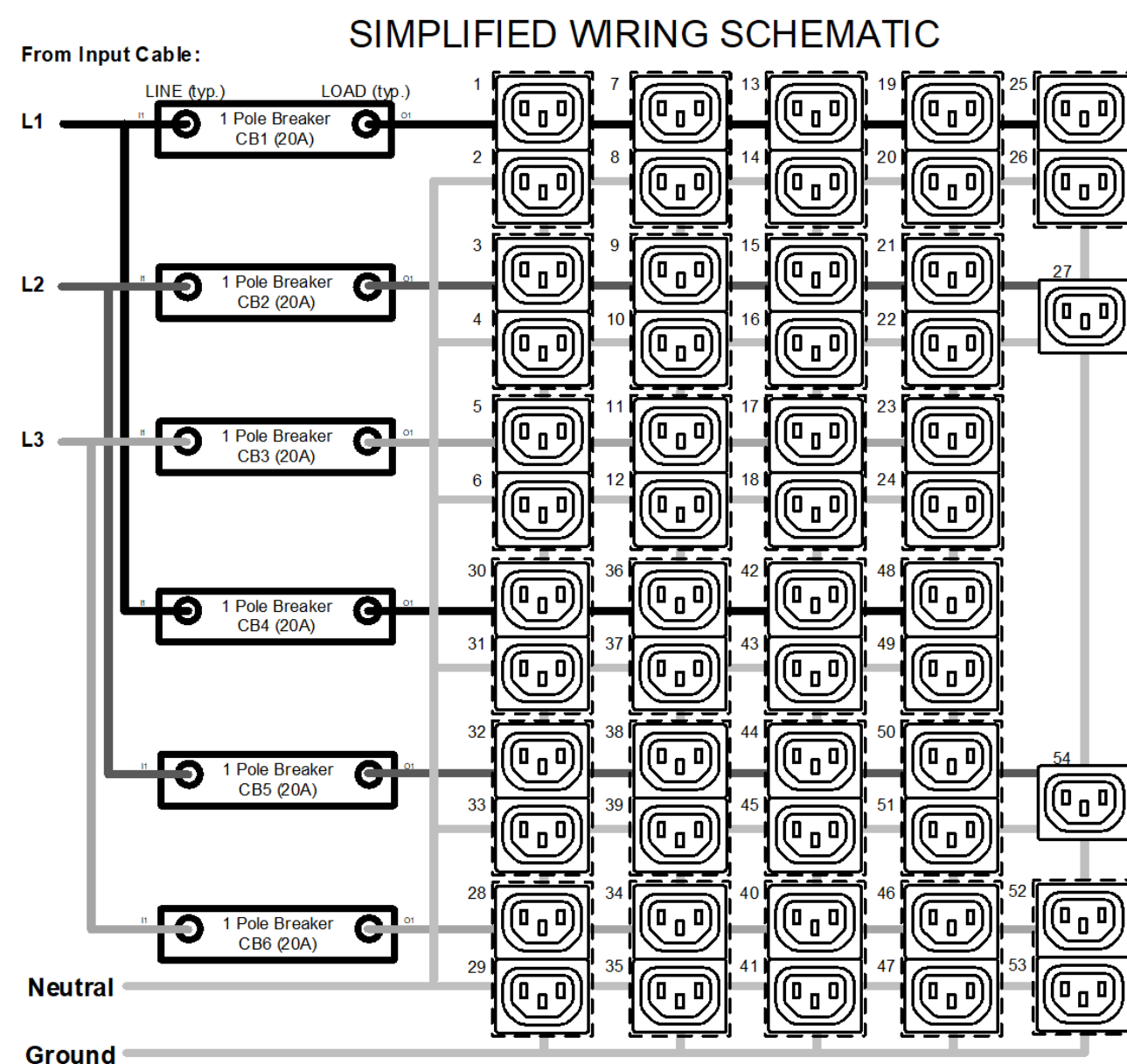

INPUT PLUG DETAIL  
NEMA L22-30  
30A / 4P5W

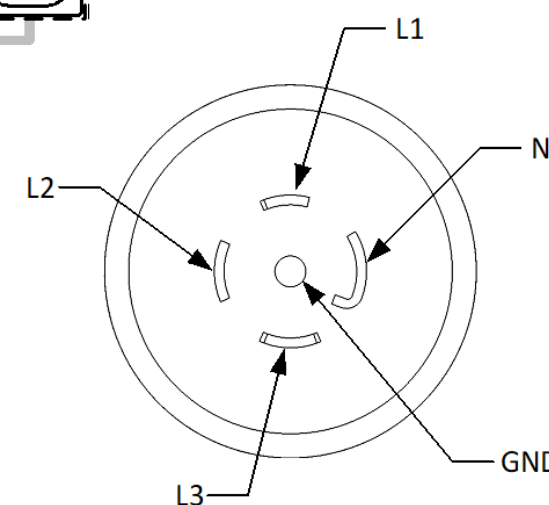

| Technical Specs:          |                                                                       |
|---------------------------|-----------------------------------------------------------------------|
| Input Ratings             |                                                                       |
| Nominal Voltage (VAC)     | 240/415V 3ph                                                          |
| Input Plug / Cord         | NEMA L22-30P (IP20), 10ft. Cord                                       |
| Current Rating            | 24A per phase                                                         |
| Power Rating (kW)         | 17.28                                                                 |
| Output Ratings            |                                                                       |
| Nominal Voltage (VAC)     | 240V                                                                  |
| Current Rating            | 72A                                                                   |
| Outlet Rating             | C13 10A max                                                           |
| Max Current per Breaker   | 12A Balanced; 16A Unbalanced                                          |
| Outlet Combination        |                                                                       |
| Load Segment              | Refer to Simplified Wire Schematic                                    |
| PDU Total                 | (54) C13                                                              |
| Branch Circuit Protection | (6) 1Pole 20A 10kAIC Breaker                                          |
| Features:                 |                                                                       |
| Local Display             | (1) 4 digit LED Display - Input Current Meter                         |
| Branch Monitoring         | Not Supported                                                         |
| Outlet Monitoring         | Not Supported                                                         |
| Monitoring Accuracy       | Not Supported                                                         |
| Ethernet Port             | Not Supported                                                         |
| Remote Monitoring         | Not Supported                                                         |
| Remote Control            | Not Supported                                                         |
| IP Consolidation          | Not Supported                                                         |
| USB Ports (2)             | Not Supported                                                         |
| Controller Module         | Not Supported                                                         |
| Auxiliary Port (2)        | Not Supported                                                         |
| Cord Retention            | Locking Receptacles                                                   |
| Mounting System           | Multiple tool-less mounting button locations, A and B (see detail)    |
| Dimensions & Weights:     |                                                                       |
| Width (In[mm])            | 2.2[55]                                                               |
| Height (In[mm])           | 77.1[1958.5]                                                          |
| Depth (In[mm])            | 2.8[70.1]                                                             |
| Weight (lbs[kg])          | 22[10]                                                                |
| Regulatory Information:   | UL & cUL Listed, IEC 62368-1, CE, RoHS, FCC Part 15 Class A, EN 55022 |
| Environmental Conditions: |                                                                       |
| Operating Temperature     | 32 - 149F (0 - 65C)@ Input Pwr Rating (kW)                            |
| Operating Rel Humidity    | 5 - 95%                                                               |
| Operating Elevation       | 0-10000 ft (0-3000 m)                                                 |
| Storage Temperature       | -13 - 149F (-25 - 65C)                                                |
| Storage Rel Humidity      | 5 - 95%                                                               |
| Storage Elevation         | 0-50000ft (0-15000m)                                                  |
| Hardware Included:        | (2) tool-less pre-installed mounting buttons<br>(1) ground kit cable  |
| Warranty:                 | 3 yrs. Standard, 2 add'l yrs Opt'l                                    |
| Optional Accessories:     | Not Supported                                                         |

 
©2019 Chatsworth Products, Inc.  
All rights reserved.

All products quoted are subject to availability based on manufacturing capacity and shipping dates should be considered estimates only.

While every effort has been made to ensure the accuracy of all information, CPI does not accept liability for any errors or omissions and reserves the right to change information and descriptions of listed services and products.



eConnect Vertical PDU, Metered,  
L22-30, 10ft (3m),  
220-240/380-415V Three Phase Input, 30A,  
(54) C13 Outlets, 240V Output



E1-2127-X

SHEET 1 OF 1

ISS