



CHATSWORTH
PRODUCTS

eConnect® Universal Input PDUs

Global Power. Simplified Deployment. Reliable Performance.

Engineered for today's data centers, eConnect® Universal Input PDUs deliver standardized, adaptable power solutions for organizations managing diverse data center and multi-tenant environments.

Why Choose eConnect® Universal Input PDUs?

One PDU for Every Setup

- Universal Input & Detachable Cord meets global AC standards (200–250V1P; 120/208V 3P; 220-240/380-415V 3P; up to 70A)
- Flexible capacities: 17.2kW or 34.5kW models
- QuadLock outlets act as C13/C15/C19/C21
- Scalable with simple input line cord changes

Deploy Faster, Deploy Smarter

- Certified for worldwide use: UL/IEC 62368, CB & CE, TAA-compliant, RoHS
- Reduce SKUs by replacing multiple region-specific units with one universal design
- Simplified rollout saves time on selection, procurement, and installation
- Lower inventory costs with fewer variations to stock and manage
- Two-foot whip with a universal connector simplifies PDU installation in dense cabinet environments

Built for Reliability


- Secure built-in locking mechanism prevents accidental disconnects
- Standard three-year warranty, extendable to five years

High-Power Ready

- Optimized for AI and high-performance computing workloads up to 34.5kW
- 30A branch circuit breakers support high-density IT gear in standard form factors

Quick Lead Times

- Fast customization: cord lengths, colors, outlet layouts, protection types, and more
- Made in the USA; TAA compliant; BAA COTS compliant – applicable only to standard configurations with Ex-xxxx-x or Ux-xxxx-x part numbers

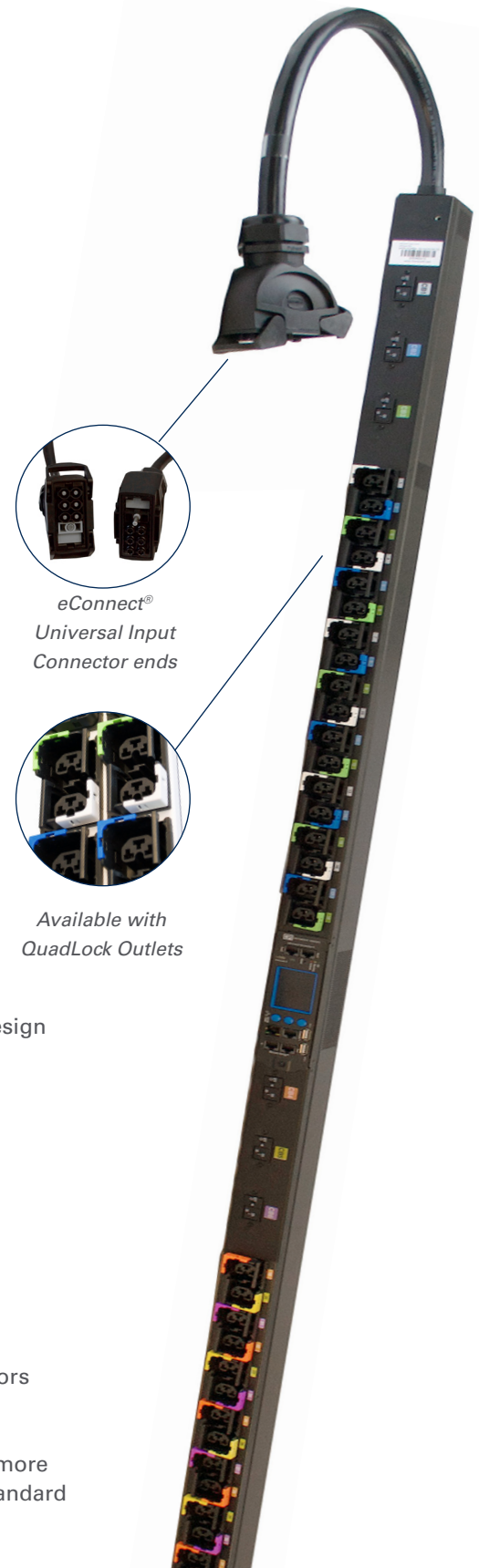

eConnect®
Universal Input
Connector ends

Available with
QuadLock Outlets

eConnect® Universal Input PDUs SKU List

eConnect Universal Input PDUs							
Part Number			Input Amperage	Input Plug	Outlets	kW Capacity (UL)	Cabinet Compatibility
Black	Glacier White	Redundancy Pack					
Basic							
U0-10B7W-C	U0-10B7W-E	U0-10B7W-CE	up to 60A	Universal Input Connector	(36) QuadLock	up to 172kW	42U or Higher
U0-11B8W-C	U0-11B8W-E	U0-11B8W-CE	up to 60A	Universal Input Connector	(42) QuadLock	up to 172kW	45U or Higher
U0-11B9W-C	U0-11B9W-E	U0-11B9W-CE	up to 60A	Universal Input Connector	(36) QuadLock	up to 34.5kW	45U or Higher
U0-14C0W-C	U0-14C0W-E	U0-14C0W-CE	up to 60A	Universal Input Connector	(18) QuadLock	up to 172kW	2U or Higher
U0-14C1W-C	U0-14C1W-E	U0-14C1W-CE	up to 60A	Universal Input Connector	(18) QuadLock	up to 34.5kW	2U or Higher
Monitored							
UA-30B7W-C	UA-30B7W-E	UA-30B7W-CE	up to 60A	Universal Input Connector	(36) QuadLock	up to 172kW	42U or Higher
UA-31B8W-C	UA-31B8W-E	UA-31B8W-CE	up to 60A	Universal Input Connector	(42) QuadLock	up to 172kW	45U or Higher
UA-31B9W-C	UA-31B9W-E	UA-31B9W-CE	up to 60A	Universal Input Connector	(36) QuadLock	up to 34.5kW	45U or Higher
UA-34C0W-C	UA-34C0W-E	UA-34C0W-CE	up to 60A	Universal Input Connector	(18) QuadLock	up to 172kW	2U or Higher
UA-34C1W-C	UA-34C1W-E	UA-34C1W-CE	up to 60A	Universal Input Connector	(18) QuadLock	up to 34.5kW	2U or Higher
Monitored Pro							
UA-40G7W-C	UA-40G7W-E	UA-40G7W-CE	up to 60A	Universal Input Connector	(12) C13/C15,(12) QuadLock	up to 172kW	42U or Higher
UA-40G8W-C	UA-40G8W-E	UA-40G8W-CE	up to 60A	Universal Input Connector	(18) C13/C15,(18) QuadLock	up to 172kW	42U or Higher
UA-47G9W-C	UA-47G9W-E	UA-47G9W-CE	up to 60A	Universal Input Connector	(24) C13/C15,(24) QuadLock	up to 172kW	45U or Higher
UA-41G5W-C	UA-41G5W-E	UA-41G5W-CE	up to 60A	Universal Input Connector	(18) C13/C15,(18) QuadLock	up to 34.5kW	45U or Higher
UA-47G6W-C	UA-47G6W-E	UA-47G6W-CE	up to 60A	Universal Input Connector	(24) C13/C15,(24) QuadLock	up to 34.5kW	45U or Higher
UA-44H4W-C	UA-44H4W-E	UA-44H4W-CE	up to 60A	Universal Input Connector	(18) QuadLock	up to 172kW	2U or Higher
UA-44H5W-C	UA-44H5W-E	UA-44H5W-CE	up to 60A	Universal Input Connector	(18) QuadLock	up to 34.5kW	2U or Higher
Switched Pro							
UA-60G7W-C	UA-60G7W-E	UA-60G7W-CE	up to 60A	Universal Input Connector	(12) C13/C15,(12) QuadLock	up to 172kW	42U or Higher
UA-60G8W-C	UA-60G8W-E	UA-60G8W-CE	up to 60A	Universal Input Connector	(18) C13/C15,(18) QuadLock	up to 172kW	42U or Higher
UA-67G9W-C	UA-67G9W-E	UA-67G9W-CE	up to 60A	Universal Input Connector	(24) C13/C15,(24) QuadLock	up to 172kW	45U or Higher
UA-61G5W-C	UA-61G5W-E	UA-61G5W-CE	up to 60A	Universal Input Connector	(18) C13/C15,(18) QuadLock	up to 34.5kW	45U or Higher
UA-67G6W-C	UA-67G6W-E	UA-67G6W-CE	up to 60A	Universal Input Connector	(24) C13/C15,(24) QuadLock	up to 34.5kW	45U or Higher
UA-64H4W-C	UA-64H4W-E	UA-64H4W-CE	up to 60A	Universal Input Connector	(18) QuadLock	up to 172kW	2U or Higher
UA-64H5W-C	UA-64H5W-E	UA-64H5W-CE	up to 60A	Universal Input Connector	(18) QuadLock	up to 34.5kW	2U or Higher

Universal Input Line Cords					
Single Phase					
Part Number	Color	Input Amperage	Nominal Input Voltage	Input Plug	kW Capacity
CU-09-D2-C8	Black	30A	208V	NEMA L6-30P	5kW
CU-42-Y1-C8	Black	32A	220-240V	IEC 60309 32A 1P+N+E	7.7kW
Three Phase					
CU-13-D3-C8	Black	30A	208V	NEMA L15-30P	8.6kW
CU-22-D3-C8	Black	30A	120/208V	NEMA L21-30P	8.6kW
CU-34-D3-C8	Black	50A	208V	CS8365C	14.4kW
CU-52-D3-C8	Black	60A	208V	IEC 60309 60A 3P+E	17.2kW
CU-62-Y3-C8	Black	32A	220-240V/380-415V	IEC 60309 32A 3P+N+E	23kW
CU-66-Y3-C8	Black	60A	220-240V/380-415V	IEC 60309 60A 3P+N+E	34.5kW



eConnect® Universal Input line cord
Cable length: 8 ft (2.4 m)