
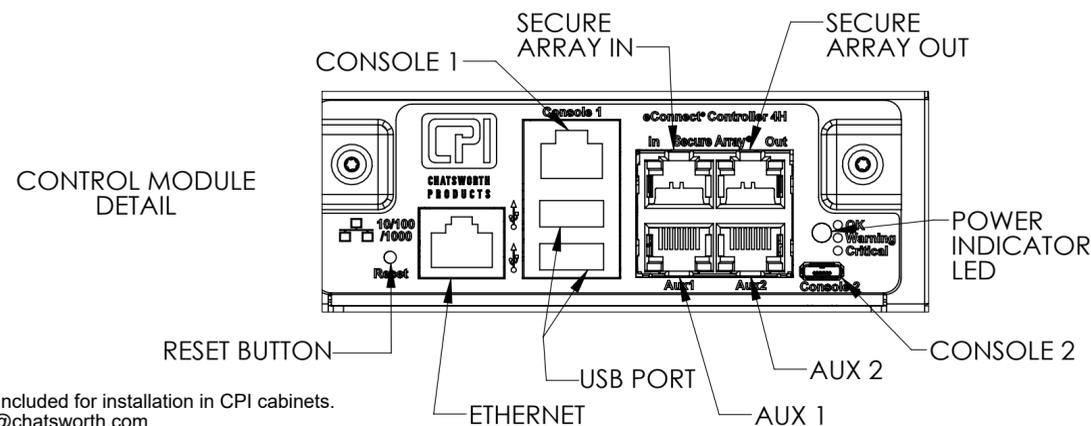


| Technical Specs: | |
|----------------------------------|---|
| Input Ratings | |
| Nominal Voltage (VAC) | 220 - 240V 1ph |
| Input Plug / Cord | 332P6W(IP67) |
| Current Rating | 25.6A (UL) / 32A (CE) |
| Power Rating (kW) | UL: 6.14 CE 7.68 |
| Output Ratings | |
| Nominal Voltage (VAC) | 220-240V |
| Current Rating | 25.6A (UL) / 32A (CE) |
| Outlet Rating | C13/C15 10A max, QuadLock 16A max |
| Max Current per Breaker | 12.8A (UL) / 16A (CE) Balanced; 16A Unbalanced |
| Outlet Combination | |
| Load Segment | Refer to Simplified Wire Schematic |
| PDU Total | (8)C13/C15, (4)QuadLock C13/C15/C19/C21 |
| Branch Circuit Protection | (2) 20A, 5kAIC, Single Pole |
| Surge Suppression | None |
| Features: | |
| Local Display | Not Supported |
| Branch Monitoring | Current, Voltage, Power, PF per Circuit |
| Outlet Monitoring | Not Supported |
| Monitoring Accuracy | +/- 1% True RMS |
| Ethernet Port | 10/100/1000 Mbps RJ45 |
| Remote Monitoring | GUI, SNMP v1-3, RS232, RESTful API, CLI, Power IQ, Redfish |
| Remote Control | Not Supported |
| IP Consolidation | Link 32/48 (with/without electronic locks) PDUs per IP address |
| USB Ports (2) | Update firmware, Opt'l Temp/Humidity Sensor |
| Controller Module | Field Replaceable |
| Auxiliary Port (2) | Optional Sensor Modules, Front & Rear Door Electronic Locks |
| Cord Retention | Locking Receptacles |
| Mounting System | Pre-installed mounting brackets |
| Dimensions & Weights: | |
| Width (In[mm]) | 17 [431.8] |
| Height (In[mm]) | 1.72 [43.7] |
| Depth (In[mm]) | 12 [304.8] |
| Weight (lbs[kg]) | 10 [4.5] |
| Regulatory Compliance: | NEVMO Listed to UL/IEC62368-1, CE, RoHS, FCC Part 15 Class A, EN 55022, TAA |
| Regulatory Part Number: | Black: K32-2Y425-F09-72A White: K32-2Y425-F09-E2A |
| Environmental Conditions: | |
| Operating Temperature | 32°F - 149°F (0°C - 65°C) |
| Operating Rel Humidity | 5 - 95% |
| Operating Elevation | 0-10000 ft (0-3000 m) |
| Storage Temperature | -13°F to 149°F (-25°C to 65°C) |
| Storage Rel Humidity | 5 - 95% |
| Storage Elevation | 0-50000ft (0-15000m) |
| Hardware Included: | (2) Pre-installed mounting brackets (1) ground kit cable |
| Warranty | 3 yrs. Standard, 2 add'l yrs. Opt'l |
| Optional Accessories: | Electronic Locks & Sensor Options |

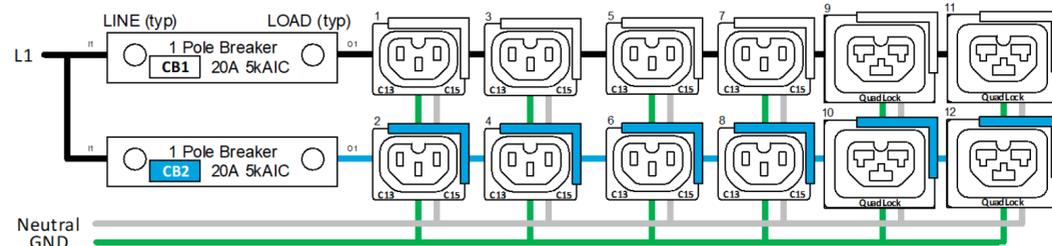

- Notes:
- 1 All Dimension are in inches [millimeters] unless otherwise specified
 - 2 Installation must conform with all related national and local codes
 - 3 All Bracket kits are sold separately. Toolless mounting buttons are included for installation in CPI cabinets.
 - 4 For more information, please contact Tech Support at techsupport@chatsworth.com

©2021 Chatsworth Products, Inc.
All rights reserved.

All products quoted are subject to availability based on manufacturing capacity and shipping dates should be considered estimates only.

While every effort has been made to ensure the accuracy of all information, CPI does not accept liability for any errors or omissions and reserves the right to change information and descriptions of listed services and products.



eConnect Horizontal 1U PDU, Monitored, IEC 60309 32A 1P+N+E, 10ft (3m), 220-240V Single Phase Input, 32A, (8) C13/C15 (4) QuadLock C13/C15/C19/C21 Outlets, 220-240V Output



EA-3277W-X

SHEET 1 OF 1

ISS