



INPUT LOCATION

From Input Cable:

**SIMPLIFIED WIRING SCHEMATIC**

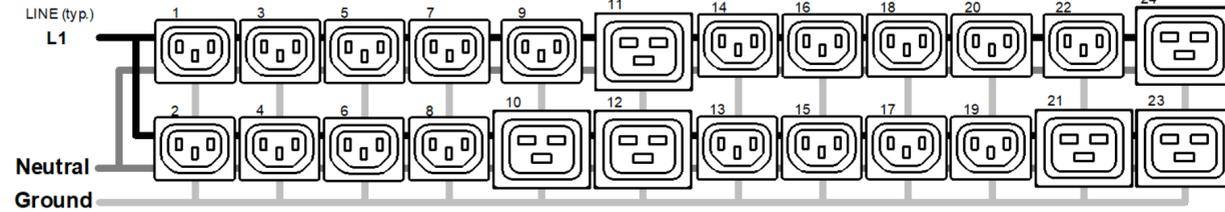

**CONTROL MODULE DETAIL**

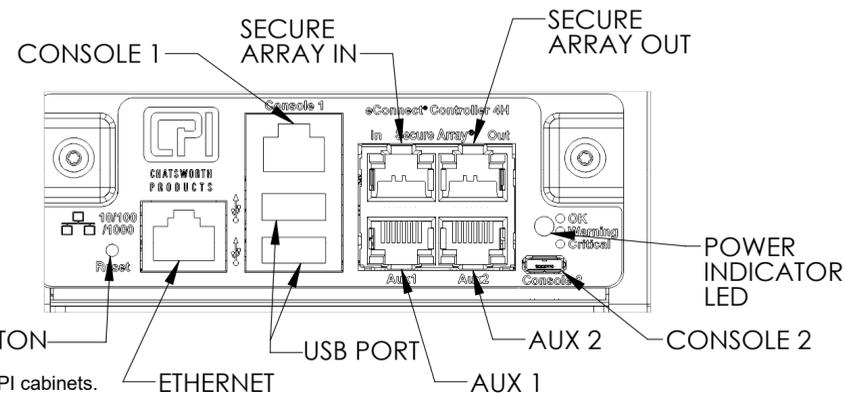

- Notes:
- 1 All Dimension are in inches [millimeters] unless otherwise specified
  - 2 Installation must conform with all related national and local codes
  - 3 All Bracket kits are sold separately. Toolless mounting buttons are included for installation in CPI cabinets.
  - 4 For more information, please contact Tech Support at [techsupport@chatsworth.com](mailto:techsupport@chatsworth.com)

| Technical Specs:  |   |
|---|---|
| <b>Input Ratings</b>  |   |
| Nominal Voltage (VAC)   | 220 - 240V 1ph  |
| Input Plug / Cord   | 316P6/320P6   |
| Current Rating  | 16A   |
| Power Rating (kW)   | 3.84  |
| <b>Output Ratings</b>   |   |
| Nominal Voltage (VAC)   | 220-240V  |
| Current Rating  | 16A   |
| Outlet Rating   | C13 10A max, C19 16A max  |
| Max Current per Phase   | 16A   |
| <b>Outlet Combination</b>   |   |
| Load Segment  | Refer to Simplified Wire Schematic                              |
| PDU Total   | (18)C13 (6)C19  |
| <b>Branch Circuit Protection</b>  |   |
| Surge Suppression   | (0) No Breaker  |
| <b>Features:</b>  |   |
| Branch Monitoring   | Current, Voltage, Power, PF per Circuit                         |
| Outlet Monitoring   | Not Supported   |
| Monitoring Accuracy   | +/- 1% True RMS   |
| Ethernet Port   | 10/100/1000 Mbps RJ45   |
| Remote Monitoring   | GUI,SNMP v1-3,RS232,RESTful API, CLI, Power IQ                  |
| Remote Control  | Not Supported   |
| IP Consolidation  | Link 32/48 (with/without electronic locks) PDU's per IP address |
| USB Ports (2)   | Update firmware, Opt'l Temp/Humidity Sensor                     |
| Controller Module   | Field Replaceable   |
| Auxiliary Port (2)  | Optional Front & Rear Door Electronic Locks                     |
| Cord Retention  | Locking Receptacles   |
| Mounting System   | Pre-installed Mounting brackets                                 |
| <b>Dimensions &amp; Weights:</b>  |   |
| Width (In[mm])  | 17[431.8]   |
| Height (In[mm])   | 3.47[88.74]   |
| Depth (In[mm])  | 12[304.8]   |
| Weight (lbs[kg])  | 23[10.4]  |
| <b>Regulatory Compliance:</b>   |   |
| NEMKO Listed to UL/IEC 62368-1, CE, RoHS, FCC Part 15 Class A, EN 55022 |   |
| <b>Regulatory Part Number:</b> K34-0Y410-40F-72A                        |   |
| <b>Environmental Conditions:</b>  |   |
| Operating Temperature   | 32 - 149F (0 - 65C)@ Input Pwr Rating (kW)                      |
| Operating Rel Humidity  | 5 - 95%   |
| Operating Elevation   | 0-10000 ft (0-3000 m)   |
| Storage Temperature   | -13 - 149F (-25 - 65C)  |
| Storage Rel Humidity  | 5 - 95%   |
| Storage Elevation   | 0-50000ft (0-15000m)  |
| <b>Hardware Included:</b>   |   |
| (2) Pre-installed mounting brackets<br>(1) ground kit cable             |   |
| <b>Warranty</b>   |   |
| 3 yrs. Standard, 2 add'l yrs. Opt'l                                     |   |
| <b>Optional Accessories:</b>  |   |
| Temp & Humidity Sensor, Electronic locks                                |   |

©2021 Chatsworth Products, Inc. All rights reserved.



All products quoted are subject to availability based on manufacturing capacity and shipping dates should be considered estimates only.

**eConnect Horizontal 2U PDU, Monitored, C20 inlet to IEC 60309 16A 1P+N+E, 10ft (3m), 220-240V Single Phase Input, 16A, (18) C13 (6) C19 Outlets, 220-240V Output**

While every effort has been made to ensure the accuracy of all information, CPI does not accept liability for any errors or omissions and reserves the right to change information and descriptions of listed services and products.



**EA-3460-X** ISS

SHEET 1 OF 1