



DISPLAY DETAIL

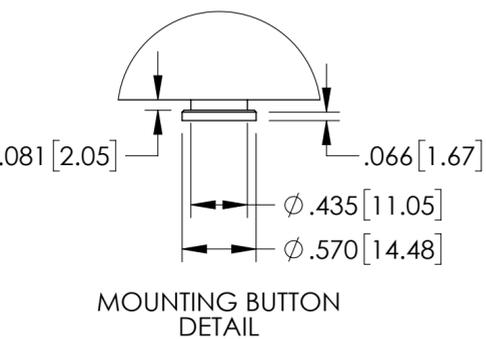

MOUNTING BUTTON DETAIL

INPUT PLUG DETAIL
NEMA L21-20
20A / 4P5W

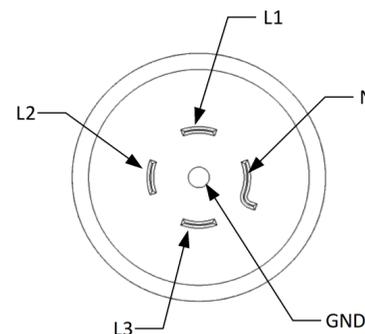

| Technical Specs: | |
|--|--|
| Input Ratings | |
| Nominal Voltage (VAC) | 120/208V 3ph |
| Input Plug / Cord | NEVAL21-20P |
| Current Rating | 16A per phase |
| Power Rating (kW) | 5.76 |
| Output Ratings | |
| Nominal Voltage (VAC) | 120/208V |
| Current Rating | 27.7A |
| Outlet Rating | C13/C15 10A max, QuadLock 16A max, 5-20 16A max |
| Max Current per Breaker | N/A |
| Outlet Combination | |
| Load Segment | Refer to Simplified Wire Schematic |
| PDU Total | (24) C13/C15, (12) QuadLock C13/C15/C19/C21, (6) 5-20 |
| Branch Circuit Protection | |
| Surge Suppression | (0) No Breaker |
| Features: | |
| Local Display | (1) 4 digit LED Display - Input Current Meter |
| Branch Monitoring | Not Supported |
| Outlet Monitoring | Not Supported |
| Monitoring Accuracy | Not Supported |
| Ethernet Port | Not Supported |
| Remote Monitoring | Not Supported |
| Remote Control | Not Supported |
| IP Consolidation | Not Supported |
| USB Ports (2) | Not Supported |
| Controller Module | Not Supported |
| Auxiliary Port (2) | Not Supported |
| Cord Retention | Locking Receptacles |
| Mounting System | Multiple tool-less mounting button locations, A and B (see detail) |
| Dimensions & Weights: | |
| Width (In[mm]) | 2.2 [55] |
| Height (In[mm]) | 71.9 [1825.7] |
| Depth (In[mm]) | 2.3 [57.6] |
| Weight (lbs[kg]) | 19 [8.6] |
| Regulatory Compliance: | |
| NEVICO Listed to UL/IEC62368-1, CE, RoHS, FCC Part 15 Class A, EN 55022, TAA | |
| Regulatory Part Number: | |
| Black: K20-0M210-H1M-72A White: K20-0Y210-H1M-E2A | |
| Environmental Conditions: | |
| Operating Temperature | 32°F - 149°F (0°C - 65°C) |
| Operating Rel Humidity | 5 - 95% |
| Operating Elevation | 0-10000 ft (0-3000m) |
| Storage Temperature | -13°F to 149°F (-25°C to 65°C) |
| Storage Rel Humidity | 5 - 95% |
| Storage Elevation | 0-50000ft (0-15000m) |
| Hardware Included: | |
| (2) tool-less pre-installed mounting buttons (1) ground kit cable | |
| Warranty | |
| 3 yrs. Standard, 2 add'l yrs. Opt'l | |
| Optional Accessories: | |
| Not Supported | |

- Notes:
- 1 All Dimension are in inches [millimeters] unless otherwise specified
 - 2 Installation must conform with all related national and local codes
 - 3 All Bracket kits are sold separately. Toolless mounting buttons are included for installation in CPI cabinets.
 - 4 For more information, please contact Tech Support at techsupport@chatsworth.com

 
©2019 Chatsworth Products, Inc.
All rights reserved.

All products quoted are subject to availability based on manufacturing capacity and shipping dates should be considered estimates only.

While every effort has been made to ensure the accuracy of all information, CPI does not accept liability for any errors or omissions and reserves the right to change information and descriptions of listed services and products.



eConnect Vertical PDU, Metered,
L21-20, 10ft (3m),
120/208V Three Phase Input, 20A,
(24) C13 (12) QuadLock C13/C15/C19/C21 (6) 5-20
Outlets, 120/208V Output



E1-2099W-X

SHEET 1 OF 1

ISS