


# Standard Busbars




CPI Standard Busbars are insulated ground bus mounting plates specifically designed for commercial applications. The Hard-Drawn Electrolytic Tough Pitch 110 Alloy solid copper bonding bars are 1/4" (6.4 mm) thick and stand off 2.75" (70 mm) from the backboard or wall. The 10" (254 mm) Busbar accepts 1/4" (6.4 mm) single bolt lugs. The 12" (304.8 mm) and 20" (508 mm) Busbars provide connection for nine or 17 lugs respectively, accepting lugs with either 3/4", 1" or 1-3/4" (19 mm, 25.4 mm or 44.5 mm) centers. Any lug with 3/8" (9.5 mm) bolts may be used.


- Each Busbar assembly consists of:
  - 1 Busbar
  - 2 insulators
  - 2 stand-off brackets
  - 4 stainless steel bolts
  - 4 lock washers
  - 4 flat washers
- All Busbars ship individually and preassembled
- Other configurations available on request
- UL® Listed

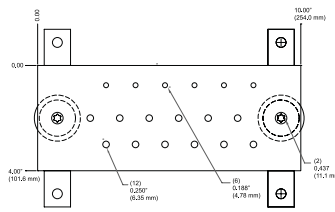

10622-010

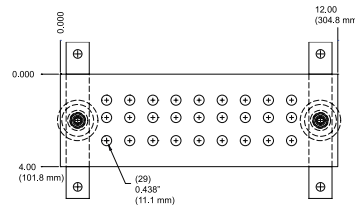

10622-012

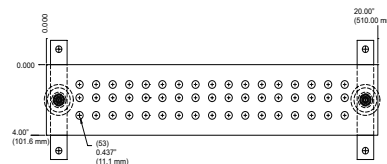

10622-020

## ORDERING INFORMATION

Part Number	Description	Shipping Weight lb (kg)
10622-010	4"W x 10"L (101.6 mm x 250 mm)	4 (1.8)
10622-012	4"W x 12"L (101.6 mm x 300 mm)	5 (2.3)
10622-020	4"W x 12"L (101.6 mm x 510 mm)	8 (3.6)

Note: Busbars are 1/4" (6.4 mm) thick.

### United States

Agoura Hills, CA  
800-834-4969

### Canada

Toronto, Ontario, Canada  
+905-850-7770

### Europe

Buckinghamshire, UK  
+441628524834

### Middle East & Africa

Dubai, UAE  
+971-4-2602125

Doha, Qatar  
+974-4-267422

### Latin America

+52-55-5203-7525  
Toll Free within Mexico  
800-201-7592  
chatsworth.com.co

### Asia Pacific

+86 21 6880-0266  
chatsworth.com.cn



CHATSWORTH  
PRODUCTS