

UPS – Web/SNMP Cards

Provide remote monitoring, management and control of UPS through a network connection from a web browser.

- Remote monitoring – Input voltage, output voltage, frequency, temperature, load, capacity
- Detailed log listing – through event, data and battery test logs
- Event notification – receive notifications via email, SMS or Traps
- UPS control – schedule UPS self tests, examine event/data logs, perform multi-server shutdown, examine battery performance, reboot UPS and equipment
- Environmental monitoring – optional sensor monitors external temperature and humidity
- Standard network connection – 10/100 MB Ethernet
- Strong authentication – centralized authentication by Radius
- Advanced encryption – supports HTTPs, SSL, SSH and SNMPv3 protocols

Additional Features:


- MIB supported: PPC MIB, RFC1628, SNMPv1/v2/v3
- LAN Protocols supported: TCP/IP, IPv4, IPv6, HTTP, HTTPS, SSL, SSH, SMTP, SNMP, DHCP, Telnet, BOOTP, DNS, DDNS, PPPoE, RADIUS
- Real-Time Clock



ORDERING INFORMATION

Part Number	Description	Shipping Weight lb (kg)
SNMP1	Internal SNMP/WEB Card For VD/VL/LD UPS Models; 10/100 MB; Management and Shutdown of Remote Clients Via LAN; Black.	2 (0.9)
SNMP1EXT	Environmental Monitoring Sensor; Attaches to SNMP1 Card; Monitors Temperature, Humidity; Black	2 (0.9)

SNMP Web management interface meter/chart

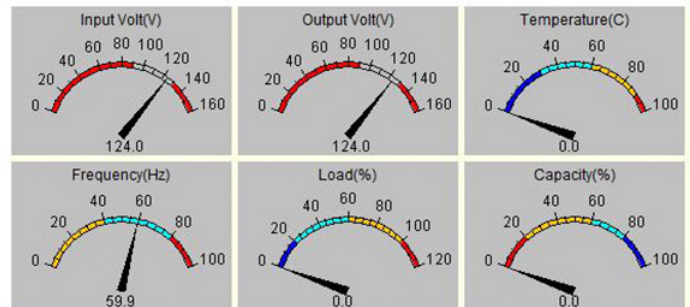

United States

Simi Valley, CA
800-834-4969

Canada

Toronto, Ontario, Canada
+905-850-7770

Europe

Buckinghamshire, UK
+441628 524834

Middle East & Africa

Dubai, UAE
+971-4-2602125

Doha, Qatar
+974-4-267422

Latin America

+52-55-5203-7525
Toll Free within Mexico
800-201-7592
chatsworth.com.co

Asia Pacific

+86 21 6880-0266
chatsworth.com.cn



CHATSWORTH
PRODUCTS