


# ZetaFrame™ Cabinet – Service Part Cut Sheet

This document lists service parts for the ZetaFrame™ Cabinet System. Service parts include top panels, side panels, doors and door lock kits, and are used as replacement parts.

To identify the correct size component, locate the product part number on the label on the bottom front corner of the frame, or take overall measurements of the frame. Please contact CPI Technical Support at 800-834-4969 or techsupport@chatsworth.com for assistance.

## Top Panel with Grommets

Solid single-piece top panel with large grommet-sealed cable openings in each corner contains airflow within the cabinet while allowing cables to enter/exit the top panel.

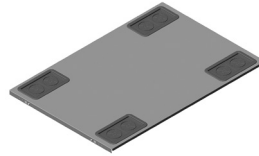


- Use in traditional hot/cold aisle environments or with aisle containment for front-to-rear airflow through the cabinet; not compatible with Vertical Exhaust Duct
- (4) cable openings, (1) per corner, are 4.5"W x 9"D (114 mm x 228 mm) without cover, sized for large power plugs
- Includes (4) plastic, snap-on grommets that seal cable openings and can be cut to pass cables
- Tool-less, drop-in design with integrated spring button secures top panel to the cabinet frame without additional installation hardware
- Features integral electrical bonding, no bonding strap required
- Material: Steel top panel
- Finish: Black or Glacier White; grommets are black
- Select part number to match the width, depth and color of the cabinet

Part Number - Cabinet Width				Depth in (mm)	Shipping Weight lb (kg)
23.6"W (600 mm)	27.6"W (700 mm)	29.5"W (750 mm)	31.5"W (800 mm)		
39746-X00	39746-X17	39746-X34	39746-X51	31.5 (800)	22 (10.0)
39746-X08	39746-X25	39746-X42	39746-X59	39.4 (1000)	18 (8.2)
39746-X10	39746-X27	39746-X44	39746-X61	41.3 (1050)	21 (9.5)
39746-X12	39746-X29	39746-X46	39746-X63	43.3 (1100)	21 (9.5)
39746-X16	39746-X33	39746-X50	39746-X67	47.2 (1200)	21.8 (9.4)

Note: X=Color: 7=Black, E=Glacier White. Shipping weights are for 800 mm Cabinets

## Vertical Exhaust Duct

Vertical Exhaust Duct attaches to the top of the cabinet to provide a sealed pathway for exhaust air from the top of the cabinet to an overhead drop ceiling as part of a closed hot air return.

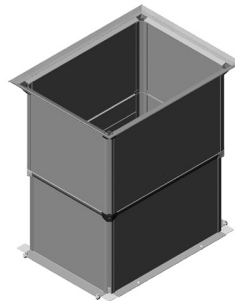

- Used with Solid Rear Door, Bottom Panel, Air Dam, Snap-In Filler Panels and Air Director for a complete and effective airflow containment strategy
- Fits cabinets that are 41.3"D (1050 mm) or deeper
- Two-piece duct adjusts in height to span the distance between the top of the cabinet and the overhead drop ceiling; available in three sizes (see description in order table)
- Features easy height adjustment, has a flexible seal at the top to accommodate variations in the drop ceiling
- Includes a brush-sealed cable opening on the back of the duct to allow power cords to enter the back of the cabinet when the duct is installed
- Includes: Vertical Exhaust Duct and installation hardware
- Material: Aluminum duct panels; top seal and duct corners are plastic
- Finish: Black or Glacier White; seal and corners are black
- Select part number to match the width and color of the cabinet

Part Number - Cabinet Width				Duct Height in (mm)	Shipping Weight lb (kg)
23.6"W (600 mm)	27.6"W (700 mm)	29.5"W (750 mm)	31.5"W (800 mm)		
39873-X00	39873-X01	39873-X02	39873-X03	15-20 (381-508)	20 (9.1)
39873-X04	39873-X05	39873-X06	39873-X07	20-34 (508-863)	29 (13.2)
39873-X08	39873-X09	39873-X10	39873-X11	34-60 (863-1523)	51 (23.2)

X=Color: 7=Black, E=Glacier White. Shipping Weights are for 800 mm ducts

### United States

Agoura Hills, CA  
800-834-4969

### Canada

Toronto, Ontario, Canada  
+905-850-7770

### Europe

Buckinghamshire, UK  
+441628524834

### Middle East & Africa

Dubai, UAE  
+971-4-2602125

Doha, Qatar  
+974-4-267422

### Latin America

+52-55-5203-7525  
Toll Free within Mexico  
800-201-7592  
chatsworth.com.co

### Asia Pacific

+86 21 6880-0266  
chatsworth.com.cn



CHATSWORTH  
PRODUCTS

# ZetaFrame™ Cabinet – Service Part Cut Sheet

## Single Perforated Front Door

- 78% perforation provides maximum airflow
- Universal mounting location allows use on the front or rear of cabinet frame
- Reversible to open from the right or left, must move hinges/latch
- Opens 120° when cabinets are bayed, 145° when stand alone
- Hinge pins allow quick and easy tool-less removal of the door for maintenance access
- Features integral bonding, no additional ground straps required
- Uses Single-Point Latch Kit (ordered separately)
- Includes door and hinges
- Material: Steel
- Finish: Black or Glacier White

 


Part Number - Cabinet Width				Height (U)	Shipping Weight lb (kg)
23.6"W (600 mm)	27.6"W (700 mm)	29.5"W (750 mm)	31.5"W (800 mm)		
39780-X00	39780-X11	39780-X33	39780-X22	42U	40.6 (18.6)
39780-X03	39780-X14	39780-X36	39780-X25	45U	41.4 (18.8)
39780-X06	39780-X17	39780-X39	39780-X28	48U	42.2 (19.2)
39780-X10	39780-X21	39780-X43	39780-X32	52U	43 (19.5)

Note: X=Color: 7=Black, E=Glacier White. Shipping weights are for 800 mm doors

## Double Perforated Rear Door

- 78% perforation provides maximum airflow compatible with Vertical Exhaust Duct
- Opens to 180° when bayed or not bayed
- Features integral bonding, no additional ground straps required
- Uses 3-Point Latch Kit (ordered separately)
- Includes door and hinges.
- Material: Steel
- Finish: Black or Glacier White



Part Number - Cabinet Width				Height (U)	Shipping Weight lb (kg)
23.6"W (600 mm)	27.6"W (700 mm)	29.5"W (750 mm)	31.5"W (800 mm)		
39861-X00	39861-X11	39861-X33	39861-X22	42U	41.4 (18.8)
39861-X03	39861-X14	39861-X36	39861-X25	45U	42.2 (19.2)
39861-X06	39861-X17	39861-X39	39861-X28	48U	43 (19.5)
39861-X10	39861-X21	39861-X43	39861-X32	52U	43.8 (19.9)

Note: X=Color: 7=Black, E=Glacier White. Shipping weights are for 800 mm doors

## Single Solid Rear Door

- Low profile, flat, solid metal door with perimeter seal
- Recommended for use as the rear door with Vertical Exhaust Duct, Bottom Panel and Air Dam, as part of the CPI Passive Cooling Solution to capture and guide exhaust air away from the cabinet
- Universal mounting location allows use on the front or rear of the cabinet
- Can be attached to the cabinet to swing open to the left or right
- Uses 3-Point Latch Kit (ordered separately)
- Opens beyond 180° when cabinets are bayed or standalone
- Hinge pins allow quick and easy tool-less removal of the door for maintenance access
- Includes door and hinges
- Features integral bonding, no additional ground straps required
- Material: Steel
- Finish: Black or Glacier White



Part Number - Cabinet Width				Height (U)	Shipping Weight lb (kg)
23.6"W (600 mm)	27.6"W (700 mm)	29.5"W (750 mm)	31.5"W (800 mm)		
39868-X00	39868-X11	39868-X33	39868-X22	42U	41.4 (18.8)
39868-X03	39868-X14	39868-X36	39868-X25	45U	42.2 (19.2)
39868-X06	39868-X17	39868-X39	39868-X28	48U	43 (19.5)
39868-X10	39868-X21	39868-X43	39868-X32	52U	43.8 (19.9)

Note: X=Color: 7=Black, E=Glacier White. Shipping weights are for 800 mm doors

For electronic lock upgrade, contact Technical Support at [techsupport@chatsworth.com](mailto:techsupport@chatsworth.com)

### United States

Agoura Hills, CA  
800-834-4969

### Canada

Toronto, Ontario, Canada  
+905-850-7770

### Europe

Buckinghamshire, UK  
+441628524834

### Middle East & Africa

Dubai, UAE  
+971-4-2602125

Doha, Qatar  
+974-4-267422

### Latin America

+52-55-5203-7525  
Toll Free within Mexico  
800-201-7592  
chatsworth.com.co

### Asia Pacific

+86 21 6880-0266  
chatsworth.com.cn



CHATSWORTH  
PRODUCTS

# ZetaFrame™ Cabinet – Service Part Cut Sheet

### Latch Kits

- Includes Keyed Latch swing handle lock and applicable hardware
- Select single-point, keyed latch for Single Perforated Front Door
- For other doors, select Latch Kit per cabinet height




Part Number	Description - Door Type	Cabinet Height	Shipping Weight lb (kg)
39970-710	Single-Point, Keyed, For Single Perforated Front Door	N/A	1.5 (0.7)
39976-71C	3-Point, Keyed, For Double Perforated Rear Doors	42U	4 (1.8)
39976-71F	3-Point, Keyed, For Double Perforated Rear Doors	45U	4.1 (1.9)
39976-71J	3-Point, Keyed, For Double Perforated Rear Doors	48U	4.3 (2)
39976-71N	3-Point, Keyed, For Double Perforated Rear Doors	52U	4.5 (2)
39975-71C	3-Point, Keyed, For Single Solid Rear Door	42U	4 (1.8)
39975-71F	3-Point, Keyed, For Single Solid Rear Door	45U	4.1 (1.9)
39975-71J	3-Point, Keyed, For Single Solid Rear Door	48U	4.3 (2)
39975-71N	3-Point, Keyed, For Single Solid Rear Door	52U	4.5 (2)

Note: Locks are black.

### Leveling Feet Kit


- Kit includes (4) leveling feet to support cabinet
- Must be installed before cabinet is loaded with equipment
- Material and Finish: Zinc-plated steel

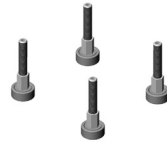

Part Number	Description	Shipping Weight lb (kg)
39983-001	Leveling Feet Kit, Four each, Zinc	2 (0.9)

### Floor Mounting Bracket Kit

- Includes (2) brackets used to secure a cabinet to the structural floor
- May also be used to bay adjacent cabinet frames
- Order floor attachment hardware separately
- Material: Steel
- Material: Zinc-plated steel

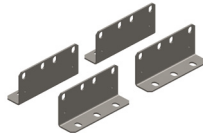

Part Number	Description	Shipping Weight lb (kg)
39998-001	Floor Mounting Bracket Kit, Two each	4 (1.8)

### Caster Kit

- Kit includes (2) Fixed Casters, (2) Swivel Casters and installation hardware, ideal for rack-and-roll applications
- Must be installed before cabinet is loaded with equipment



Part Number	Description	Shipping Weight lb (kg)
39982-001	Includes 2 Fixed Casters and 2 Swivel Casters	14 (6.4)

### Baying Bracket Kit

- Includes (2) brackets used to secure (2) cabinets side-by-side and installation hardware
- (2) sets of holes allow brackets to bay cabinets directly side-by-side or center 23.6"W (600 mm) cabinets over 24"W (610 mm) floor tiles
- Installation does not require removal of doors
- Material: Zinc-plated steel



Part Number	Description	Shipping Weight lb (kg)
39815-001	Baying Bracket Kit	3 (1.4)

### Ground Block Kit

- Includes (1) grounding block and installation hardware
- Installs in four possible locations: top/bottom, front/rear
- Material: Zinc



Part Number	Description	Shipping Weight lb (kg)
39730-000	Ground Block Kit	1 (0.5)

For complete ZetaFrame information, visit [chatsworth.com](http://chatsworth.com).

#### United States

Agoura Hills, CA  
800-834-4969

#### Canada

Toronto, Ontario, Canada  
+905-850-7770

#### Europe

Buckinghamshire, UK  
+441628524834

#### Middle East & Africa

Dubai, UAE  
+971-4-2602125

Doha, Qatar  
+974-4-267422

#### Latin America

+52-55-5203-7525  
Toll Free within Mexico  
800-201-7592  
[chatsworth.com.co](http://chatsworth.com.co)

#### Asia Pacific

+86 21 6880-0266  
[chatsworth.com.cn](http://chatsworth.com.cn)



CHATSWORTH  
PRODUCTS