


Horizontal Cable Management Accessories

Horizontal Cable Management Accessories


Patch Panel Wire Management Bar

19" rack-mountable bar provides the necessary wire management and strain relief recommended by ANSI/TIA/EIA. May be mounted inward for 6" (150 mm) channel or outward to standard 3" (80 mm) rack side channel; attaches to rack with standard #12-24 rack screws (not included). Wire tie holes maintain wire perpendicular relative to termination point; made of sturdy aluminum and sold individually.

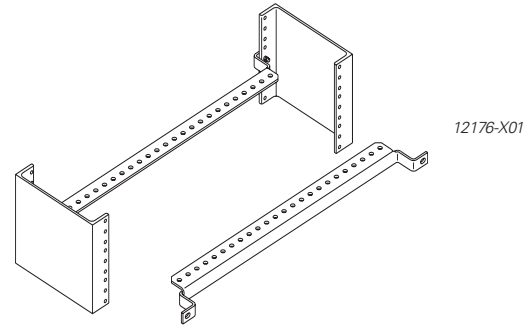


Horizontal Wire Management Panel for VCS

19" Wire Management Panel is offset 1.5" (38 mm) from the rack channel to ensure proper bending radii of patch cables, even hooded patch cables. Use in combination with VCS Vertical Cabling Sections. Unique offset design provides patch cable pathway from front-to-back or side-to-side. Available in single 1.75" (44.5 mm) or double 3.5" (89.0 mm) rack-mount unit designs. Mounts quickly and easily using threaded cable distribution spools; cable distribution spools maintain bend radius through the pass-through trough and across the front plane of the horizontal manager.

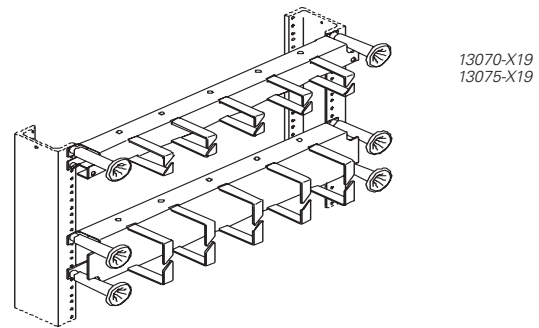

Horizontal Wire Management Panel for MCS and CCS

Use in combination with MCS Master Cabling Section and CCS Combination Cabling Section to provide open horizontal management for cables.

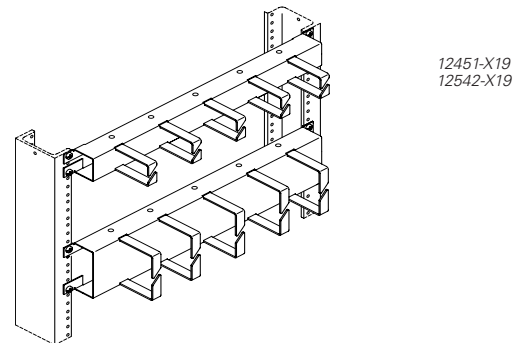

ORDERING INFORMATION

Part Number	Description	Shipping Weight lb (kg)
12176-X01	Patch Panel Wire Mangement Bar	1 (0.5)
13070-X19	Horizontal Wire Panel for VCS, 1U	2 (0.9)
13075-X19	Horizontal Wire Panel for VCS, 2U	2 (0.9)
12541-X19	Horizontal Wire Panel for MCS/CCS, 1U	2 (0.9)
12542-X19	Horizontal Wire Panel for MCS/CCS, 2U	2 (0.9)

X=color: 1=Gray, 5=Clear, 7=Black, E=Glacier White.