


Service Parts for RMR Wall-Mount Enclosures

Filter Fans

Replacement Filter Fans for wall-mount enclosures. Use Filter Fans in nonhazardous environments with outside temperature range that is lower than the temperature required in the enclosure.

- Side-mounting
 - Supports side-to-side airflow
 - Easy, tool-less installation
 - Maintains NEMA Type 12 protection ratings
 - Hinged grill for easy filter replacement
 - Optimized airflow and reduced energy consumption
 - Fluted filter mat allows 300% longer service time
- Standard size is:
 - Side mounted, 38 CFM (65 CMH) unimpeded airflow, 115V, with filter for 6" x 6" (153 mm x 153 mm) cutout

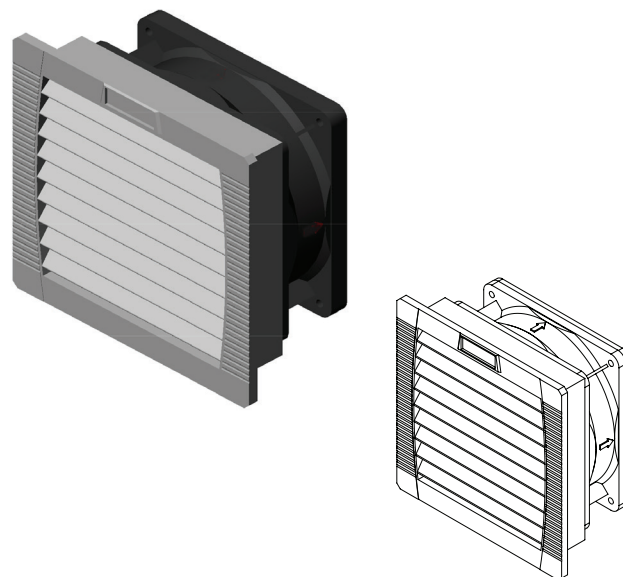

Consult Thermal Management Accessories for RMR Enclosure Systems data sheet for more detailed specifications. [RMR Thermal Accessories](#)

Part Number Fan Configuration		Cutout Size	Airflow	Voltage	Color	Shipping Weight lb (kg)
Intake	Exhaust	in (mm)	CFM (CMH)			
37101-001	37101-002	6 (153)	38 (65)	115	Hammer Gray	5 (2.3)
37101-003	37101-004	6 (153)	38 (65)	230	Hammer Gray	5 (2.3)
37101-005	37101-006	6 (153)	38 (65)	115	Black	5 (2.3)
37101-007	37101-008	6 (153)	38 (65)	230	Black	5 (2.3)

RMR Enclosure Power Cord for Filer Fan			
Part Number	Voltage	Cord Type	Shipping Weight lb (kg)
37902-001	125	NEMA 5-15P	2 (0.9)
37902-002	250	NEMA 6-15P	2 (0.9)
37902-003	250	IEC C14	2 (0.9)

Color is Black.

RMR Wall-Mount Enclosure Filter Kit		
Part Number	Filter Cutout in (mm)	Shipping Weight lb (kg)
37102-00X	6 (153)	4 (1.9)

X= Color; C=Black, G= Hammer Gray.

For more information on RMR Industrial Enclosures, visit www.chatsworth.com/industrial-enclosures

US & Canada

+1-800-834-4969
Toronto, Ontario, Canada
+905-850-7770
chatsworth.com
techsupport@chatsworth.com

Latin America

+52-55-5203-7525
Toll Free within Mexico
01-800-01-7592
chatsworth.com.co

Europe

+44-1628-524-834
chatsworthproducts.co.uk

Middle East & Africa

Dubai, UAE
+971-4-2602125
chatsworth.ae

Asia Pacific

+86 21 6880-0266
chatsworth.com.cn



CHATSWORTH
PRODUCTS