

RMR® Industrial Enclosure Systems and Solutions

Chatsworth Products (CPI) is a global manufacturer of products and solutions that power and protect your technology investment with expert consultation and product customization for a variety of applications.



- Wide range of high-quality, standard solutions
- Fast, easy configuration and ordering
- Kitting of accessories to simplify ordering
- Preinstallation of accessories to save you time
- Modified standard enclosures to match specific Human Machine Interface (HMI) requirements
- Competitive lead times to match your schedule

Contact Tech Support at techsupport@chatsworth.com

RMR Free-Standing Enclosures



- NEMA Type 4, 4X, 12, 3, 3R, 5, 2 and 1
- For indoor and outdoor use
- Available in stainless steel with brushed finish for corrosive environments
- Easy-to-use side channels for mounting
- Continuous foam gasket seal
- Wide range of sizes available
- Single- and double-door options
- 3-point latch with choice of lock
- Optional adjustable-depth mounting plate

RMR Wall-Mount Enclosures



Shown in painted Glacier White finish.

- UL® Listed Industrial Control Panel Enclosure, Type 12 and IP 55 ratings
- For indoor use, protects against the ingress of dust and dripping noncorrosive liquids
- Swing-out or fixed styles
- Continuous foam gasket seal
- Wide range of sizes available
- Solid or tempered glass door option
- 19" EIA mounting rails or adjustable mounting plate
- Optional cable and thermal management accessories

RMR Wall-Mount Enclosures



Shown in stainless steel finish.

- NEMA Type 4, 4X, 12, 3, 3R, 5, 2 and 1
- For indoor and outdoor use
- Continuous foam gasket seal
- Wide range of sizes available
- Single- and double-door options
- 3-point or 1/4-turn latch with choice of lock
- Optional rear mounting plate
- Available with solid metal or tempered glass door
- Available in mild and stainless steel options
- Disconnect Enclosures with standard cutout on the right flange are also available

RMR Modular Enclosures



Shown in painted Hammer Gray RAL7035 finish.

- UL Listed Industrial Control Panel Enclosure, Type 12 and IP 55 ratings
- For indoor use, protects against the ingress of dust and dripping noncorrosive liquids
- Continuous foam gasket seal
- High-strength, roll-formed steel frame
- Removable, bolt-on top, side, bottom and rear panels
- Wide range of sizes available
- 19" EIA mounting rails or adjustable mounting plate
- Optional cable and thermal management accessories

RMR Floor-Mount Enclosures



Shown in painted Gray ANSI 61 finish.

- NEMA Type 4, 4X, 12, 3, 3R, 5, 2 and 1
- For indoor and outdoor use
- Floor stands provide additional clearance and easy access to bottom of the enclosure
- Available in stainless steel with brushed finish for corrosive environments
- Continuous foam gasket seal
- Solid double door
- Three lock styles: keyed, double bit and square
- Wide range of sizes available

Thermal Management Accessories



- NEMA Type 12 Indoor Cooling Units; 900-1300 BTU/hr; 3000-4000 BTU/hr; 5000-7000 BTU/hr
- Closed-loop cooling eliminates the risk of contaminants entering the enclosure
- Cooling unit uses environmentally friendly HFC-free R134a refrigerant
- Forced convection with Filter Fans
- Filter Fans feature a high-performance seal and 300% longer service life
- NEMA Type 4/4X Cooling Units also available.

Accessories for RMR Industrial Enclosures



- Roxtec grommets are rated IP 55 and seal cable openings and support multiple cables of different diameters
- Polyvent Protective Vent Kit provides ventilation and equalizes air pressure; Use to meet NEMA Type 3R requirements
- Threaded Drain Plug Kit drains accumulated or condensed water out the bottom of the enclosure
- LED Light Kit provides additional lighting inside the enclosure; 100-240 Volts
- Drip Shield Assembly provides additional protection against ice and rain; Use to meet NEMA Type 3R requirements

US & Canada

+1-800-834-4969
Toronto, Ontario, Canada
+905-850-7770
chatsworth.com
techsupport@chatsworth.com

Latin America

+52-55-5203-7525
Toll Free within Mexico
800-201-7592
chatsworth.com

Europe

+Buckinghamshire, UK
+44-1628-524-834
chatsworth.com

Middle East & Africa


Dubai, UAE
+971-4-2602125
Doha, Qatar
+974-4-267422
chatsworth.com

Asia Pacific

Shanghai
+86 21 6880-0266
chatsworth.com



Pemsa® Rejiband® Wire Mesh Cable Tray

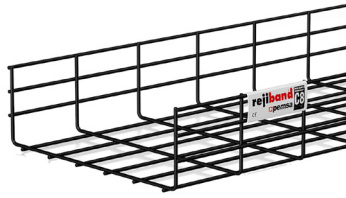

- UL® Certified
- BLACK C8® finish option meets resistance class IEC 61537 Class C8, delivering corrosion resistance almost equivalent to stainless steel.
- Available in 2 heights and 6 widths
- Tray can be cut and formed into turns and transitions using standard splices
- Tops of trays are rounded and smooth to protect installers and cables from cuts

eConnect® Power Distribution Units



- 6 progressive models allow local metering, remote monitoring and switching at the device level
 - Market-leading temperature ratings of up to 149°F (65°C)
 - Low-profile locking outlets prevent accidental disconnections
 - Integrated environmental monitoring
 - Vertical and horizontal configurations
 - Meets latest UL and IEC 62368 compliance
- selectapdu.com

Cellular Wireless Enclosures for Next-Generation Technologies

RMR Cellular Wireless Enclosures accommodate most vendors' small cells and access points, including:

- CommScope® ONECELL®
- Corning® SpiderCloud®
- Ericsson® Radio Dot
- Huawei® LampSite®
- Nokia® AirScale®
- Sunwave® CrossFire®

RMR Wall-Mount Enclosure



- NEMA Type 4 wall-mount enclosure for small cell radio nodes, access points, antennas and switches
- For indoor and outdoor use
- Prepunched 1" (25.4 mm) diameter hole centered on the top accepts customer antenna; includes sealed plug to maintain NEMA rating if not used
- Preinstalled, removable back plate
- Keyed Ch751 1/4 Turn Latch for added security
- 200 lb (90.7 kg) load rating

RMR Bollard



- Cylindrical fiberglass bollard protects radio nodes in outdoor public spaces; meets NEMA Type 3R
- 25 lb (11.4 kg) load rating
- Structural anchor base provides sturdy anchoring to concrete pads or slab
- Includes anchor base, equipment stand, hardware to fasten nodes and antennas, color-matched bolt cover and tamper-resistant hardware
- Available in 6 standard colors: Black, Brown, Forest Green, Gray, Light Gray, White

RMR Ceiling Enclosures



- Adjustable-depth, swing-down mounting panel accommodates up to 4 small cell radio nodes in suspended ceilings
- For indoor use only
- Flat, vented door or with dome insert options; replaces 2' x 2' (0.6 m x 0.6 m) ceiling tiles
- UL Listed and designed to meet National Electric Code for use in above-ceiling space; effective smoke and dust barrier to simplify Infection Control Risk Assessment (ICRA) procedure compliance in health care facilities

RMR Wall-Mount Right Angle



- Mounts up to 2 small cells in the preferred horizontal orientation for optimal wireless coverage
- For indoor use only
- Wedge shaped, right-angle mounting bracket with hinged, locking cover
- Knockouts for 1" (25.4 mm) conduit connectors
- 25 lb (11.4 kg) load rating



CPI now offers Extended Limited Warranties on CPI-Branded Electronic products, available for two additional years beyond the expiration of the Original Warranty Period (3 years).

Contact CPI Customer Service, or visit chatsworth.com/warranty for more information.

Interested in learning more about our RMR Industrial Enclosures? Call us at 800-834-4969, or email Technical Support at techsupport@chatsworth.com.